


## Heyco® Edge Clips

Edge Clips Unassembled or Assembled with 8" Cable Tie

- Ideal for use where holes cannot be used or where adhesives are unacceptable due to temperature issues.
- Applies easily to plastic and metal without the need for a mounting hole.
- Ideal for assembly usage. Clip provides low insertion force and high extraction.
- Two piece assembly allows the clip to slide along the strap ensuring proper orientation.

| UNASSEMBLED EDGE CLIP                                |                   |          | EDGE CLIP ASSEMBLED WITH CABLE TIE |                   |                 | ASSEMBLED NYTYE CABLE TIE |     |                         |      |                   |     |
|------------------------------------------------------|-------------------|----------|------------------------------------|-------------------|-----------------|---------------------------|-----|-------------------------|------|-------------------|-----|
| Fixing                                               | Part No.<br>Black | Desc.    | Cable Tie<br>Orientation           | Part No.<br>Black | Description     | Tensile<br>Strength       |     | Max. Bundle<br>Diameter |      | Overall<br>Length |     |
|                                                      |                   |          |                                    |                   |                 | Lbs.                      | N   | in.                     | mm.  | in.               | mm. |
| For Panels from .04~ (1,0 mm) to .12~ (3,0 mm) Thick |                   |          |                                    |                   |                 |                           |     |                         |      |                   |     |
| Top                                                  | 14267             | NTEC1-TB | Perpendicular                      | 14275             | NTEC1-TP-50-078 | 50                        | 222 | 1.77                    | 45,0 | 7.87              | 200 |
|                                                      |                   |          | Parallel                           | 14276             | NTEC1-TL-50-078 |                           |     |                         |      |                   |     |
| Side                                                 | 14268             | NTEC1-SB | Perpendicular                      | 14277             | NTEC1-SP-50-078 |                           |     |                         |      |                   |     |
|                                                      |                   |          | Parallel                           | 14278             | NTEC1-SL-50-078 |                           |     |                         |      |                   |     |
| For Panels from .12~ (3,0 mm) to .24~ (6,0 mm) Thick |                   |          |                                    |                   |                 |                           |     |                         |      |                   |     |
| Top                                                  | 14270             | NTEC2-TP | Perpendicular                      | 14280             | NTEC2-TP-50-078 | 50                        | 222 | 1.77                    | 45,0 | 7.87              | 200 |
|                                                      | 14271             | NTEC2-TL | Parallel                           | 14281             | NTEC2-TL-50-078 |                           |     |                         |      |                   |     |
| Side                                                 | 14272             | NTEC2-SP | Perpendicular                      | 14282             | NTEC2-SP-50-078 |                           |     |                         |      |                   |     |
|                                                      | 14273             | NTEC2-SL | Parallel                           | 14283             | NTEC2-SL-50-078 |                           |     |                         |      |                   |     |

Standard color black.

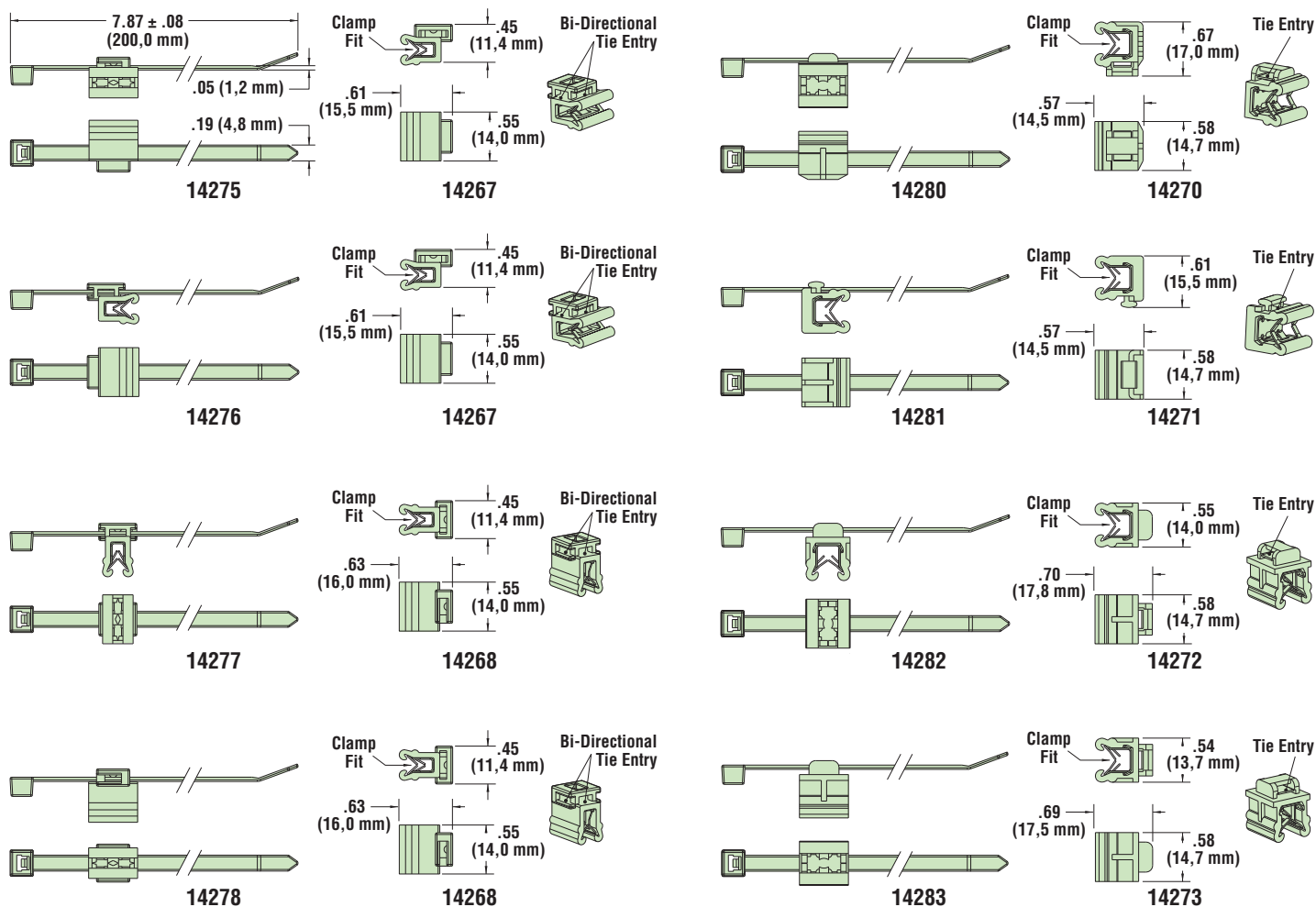

Material Nylon 6/6 high impact modified, heat and UV stabilized  
 Flammability Rating 94V-2  
 Temperature Range -40°F (-40°C) to 221°F (105°C)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[14280](#) [14281](#) [14282](#) [14276](#) [14277](#) [14275](#) [14283](#) [14272](#) [14273](#) [14270](#) [14271](#) [14278](#)