




Heyco® Feet of Strength

Feet with Push Rivet

PART DIMENSIONS						PANEL DIMENSIONS						PART NO. Black	DESCRIPTION
A Overall Height		B Top Diameter		C Bottom Diameter		Mounting Hole Diameter		Thickness Range Minimum		Maximum			
in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.		
FSR Series													
.16	4,0	.43	10,8	.39	10,0	.142	3,6	.02	0,5	.05	1,2	2519	FSR 16-14-05
								.05	1,2	.08	2,0	2520	FSR 16-14-08
								.06	1,5	.10	2,5	2521	FSR 16-14-10
								.10	2,5	.14	3,5	2550	FSR 16-14-14
.17	4,2	.83	21,0	.79	20,0	.165	4,2	.03	0,8	.07	1,8	2522	FSR 17-17-07
								.07	1,8	.11	2,8	2523	FSR 17-17-11
								.11	2,9	.15	3,7	2524	FSR 17-17-15
								.15	3,8	.19	4,8	2525	FSR 17-17-19
.22	5,5	.56	14,2	.53	13,5	.122	3,1	.03	0,8	.07	1,8	2517	FSR 22-12-07
								.07	1,8	.11	2,8	2518	FSR 22-12-11
.24	6,0	.59	15,0	.55	14,0	.165	4,2	.02	0,6	.04	1,0	2500	FSR 24-17-04
								.04	1,0	.08	2,0	2501	FSR 24-17-08
						.204	5,2	.08	2,0	.12	3,1	2502	FSR 24-17-12
								.03	0,8	.05	1,2	2506	FSR 24-21-05
.24	6,0	.83	21,0	.79	20,0	.165	4,2	.05	1,3	.09	2,3	2507	FSR 24-21-09
								.03	0,8	.07	1,8	2526	FSR 241-17-07
								.08	1,9	.11	2,8	2527	FSR 241-17-11
								.11	2,9	.16	4,0	2528	FSR 241-17-16
.31	8,0	.83	21,0	.79	20,0	.165	4,2	.01	0,3	.03	0,8	2575	FSR 31-17-03
								.03	0,8	.08	2,0	2529	FSR 31-17-08
								.08	2,1	.12	3,1	2530	FSR 31-17-12
.35	9,0	.59	15,0	.55	14,0	.165	4,2	.04	1,0	.08	2,0	2532	FSR 35-17-08
								.08	2,0	.12	3,1	2533	FSR 35-17-12

Standard color black.

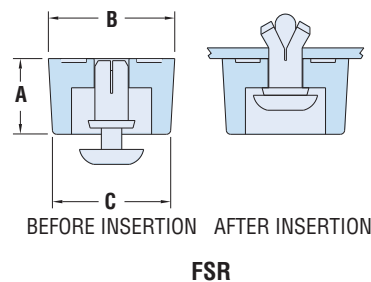

Material Thermoplastic Rubber (TPR)
 Flammability Rating 94-HB
 Temperature Range -30°F (-34°C) to 250°F (121°C)

*Quick
Specs*

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[2506](#) [2502](#) [2519](#) [2500](#) [2501](#) [2507](#) [2575](#) [2550](#) [2520](#) [2525](#) [2533](#) [2521](#) [2524](#) [2528](#) [2529](#) [2523](#) [2522](#) [2526](#)
[2518](#) [2530](#) [2527](#) [2517](#) [2532](#)