



- Grommet Strips protect against damage from sharp panel edges.
- Ideal for tight radii or irregular panel holes and cut-outs.



Unserrated



Serrated

Heyco® Continuous Grommet Rolls

Polyethylene 100' (30.5 M) Roll

FIT PANEL THICKNESS RANGE				PART NO.		DESCRIPTION	PART DIMENSIONS					
Minimum	Maximum	Minimum	Maximum	Natural	Black		A		B		C	
in.	mm.	in.	mm.				Overall Height		Bottom Thickness		Bottom Width	
in.	mm.	in.	mm.				in.	mm.	in.	mm.	in.	mm.
Unserrated												
.037	0,9	.071	1,8	12391	12391B	PGS-071-100'	.172	4,4	.031	0,8	.109	2,8
.072	1,8	.105	2,7	12392	12392B	PGS-105-100'						
.106	2,7	.164	4,2	12393	12393B	PGS-164-100'	.188	4,8	.047	1,2	.156	4,0
Unserrated, with Adhesive												
.037	0,9	.071	1,8	12395	12395B	PGSG-071-1-100'	.160	4,1	.025	0,6	.060	1,5
				12396	12396B	PGSG-071-2-100'	.172	4,4	.031	0,8	.109	2,8
.072	1,8	.105	2,7	12397	12397B	PGSG-105-100'	.172	4,4	.031	0,8	.109	2,8
.106	2,7	.164	4,2	12398	12398B	PGSG-164-100'	.188	4,8	.047	1,2	.156	4,0
Serrated												
.026	0,7	.036	0,9	12399	12399B	SPGS-036-100'	.125	3,2	.031	0,8	.031	0,8
.037	0,9	.071	1,8	12400	12400B	SPGS-071-100'	.172	4,4	.031	0,8	.109	2,8
.072	1,8	.105	2,7	12401	12401B	SPGS-105-100'						
.106	2,7	.164	4,2	12402	12402B	SPGS-164-100'	.188	4,8	.047	1,2	.156	4,0
Serrated, with Adhesive												
.037	0,9	.071	1,8	12405	12405B	SPGSG-071-1-100'	.160	4,1	.025	0,6	.060	1,5
				12406	12406B	SPGSG-071-2-100'	.172	4,4	.031	0,8	.109	2,8
.072	1,8	.105	2,7	12407	12407B	SPGSG-105-1-100'	.172	4,4	.031	0,8	.109	2,8

 
Nylon 100' (30.5 M) Roll

FIT PANEL THICKNESS RANGE				PART NO.		DESCRIPTION	PART DIMENSIONS					
Minimum	Maximum	Minimum	Maximum	Natural	Black		A		B		C	
in.	mm.	in.	mm.				Overall Height		Bottom Thickness		Bottom Width	
in.	mm.	in.	mm.				in.	mm.	in.	mm.	in.	mm.
Unserrated												
.026	0,7	.036	0,9	12411	12411B	NGS-036-100'	.13	3,2	.03	0,8	.03	0,8
.037	0,9	.071	1,8	12412	12412B	NGS-071-100'	.17	4,4	.03	0,8	.11	2,8
Unserrated, with Adhesive												
.037	0,9	.071	1,8	12416	12416B	NGSG-071-100'	.17	4,4	.03	0,8	.11	2,8
.072	1,8	.105	2,7	12417	12417B	NGSG-105-100'						
.106	2,7	.164	4,2	12418	12418B	NGSG-164-100'	.19	4,8	.05	1,2	.16	4,0
Serrated												
.026	0,7	.036	0,9	12419	12419B	SNGS-036-100'	.13	3,2	.03	0,8	.01	0,8
.037	0,9	.071	1,8	12420	12420B	SNGS-071-100'	.17	4,4	.03	0,8	.11	2,8
.072	1,8	.105	2,7	12421	12421B	SNGS-105-100'						
.106	2,7	.164	4,2	12422	12422B	SNGS-164-100'	.19	4,8	.05	1,2	.16	4,0
Serrated, with Adhesive												
.037	0,9	.071	1,8	12426	12426B	SNGSG-071-100'	.17	4,4	.03	0,8	.11	2,8
.072	1,8	.105	2,7	12427	12427B	SNGSG-105-100'						


Standard color natural. Black available by special order only.




UNSERRATED



SERRATED

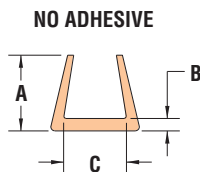

NO ADHESIVE

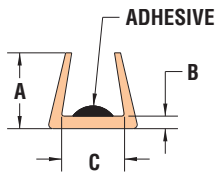

ADHESIVE

*Quick
Specs*

Material	Polyethylene or Nylon
Flammability Rating	94HB (Nylon only)
Temperature Range	-40°F (-40°C) to 149°F (65°C) (Polyethylene) -40°F (-40°C) to 185°F (85°C) (Nylon)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Heyco:

[12401](#) [12405](#) [12398](#) [12417](#) [12393](#) [12399](#) [12400](#) [12411](#) [12422](#) [12426](#) [12421](#) [12391](#) [12427](#) [12420](#) [12416](#)
[12402](#) [12395](#) [12392](#) [12406](#) [12412](#) [12397](#) [12419](#) [12396](#) [12418](#) [12407](#) [12399B](#) [12400B](#) [12402B](#) [12398B](#)
[12391B](#) [12418B](#) [12397B](#) [12419B](#) [12416B](#) [12417B](#) [12393B](#) [12396B](#) [12395B](#) [12422B](#) [12411B](#) [12426B](#) [12420B](#)
[12427B](#) [12412B](#) [12406B](#) [12421B](#) [12401B](#) [12405B](#) [12392B](#) [12407B](#) [12409B](#) [12403B](#) [12408](#) [12403](#) [12409](#)
[12408B](#)