



## HEYBite Mini's®

Unassembled or Assembled with 8" Cable Tie

### HEYBite Mini's® - Stainless Steel with Nylon 6/6 Cable Tie, 8" Long

UNASSEMBLED EDGE CLIP			EDGE CLIP ASSEMBLED WITH CABLE TIE			ASSEMBLED NYTYE CABLE TIE					
Fixing	Part No.	Description	Cable Tie	Part No.	Description	Tensile Strength		Max. Bundle Dia.		Overall Length	
	Stainless		Orientation	Stainless/Black		Lbs.	N	in.	mm.	in.	mm.
For Panels from .06~ (1,5mm) to .12~ (3,0mm) Thick											
Top	S6474	SunRunner CT	Perpendicular	S14275	S6474-TP-50-078	50	222	1.77	45,0	7.87	200
			Parallel	S14276	S6474-TL-50-078						
For Panels from .12~ (3,0mm) to .25~ (6,4mm) Thick											
Top	S6475	SunRunner CT-EZ	Perpendicular	S14280	S6475-TP-50-078	50	222	1.77	45,0	7.87	200
			Parallel	S14281	S6475-TL-50-078						


Standard color black.

- Stainless steel mini clip "bites" into panel, chassis or module edges.
- Ideal for use where holes cannot be used or where adhesives are unacceptable due to temperature issues.
- Applies easily to plastic and metal without the need for a mounting hole.
- Ideal for assembly usage. Clip provides low insertion force and high extraction.
- Two piece assembly allows the clip to slide along the strap ensuring proper orientation.


### HEYBite Mini's® - Stainless Steel with Nylon 12 Cable Tie, 8" Long

UNASSEMBLED EDGE CLIP			EDGE CLIP ASSEMBLED WITH CABLE TIE			ASSEMBLED NYTYE CABLE TIE					
Fixing	Part No.	Description	Cable Tie	Part No.	Description	Tensile Strength		Max. Bundle Dia.		Overall Length	
	Stainless		Orientation	Stainless/Black		Lbs.	N	in.	mm.	in.	mm
For Panels from .06”(1,5mm) to .12”(3,0mm) Thick											
Top	S6474	SunRunner CT	Perpendicular	S14275-12	S6474-TP-50-078-12	50	222	1.77	45,0	7.87	200
			Parallel	S14276-12	S6474-TL-50-078-12						
For Panels from .12”(3,0mm) to .25”(6,4mm) Thick											
Top	S6475	SunRunner CT-EZ	Perpendicular	S14280-12	S6475-TP-50-078-12	50	222	1.77	45,0	7.87	200
			Parallel	S14281-12	S6475-TL-50-078-12						

#### PERPENDICULAR

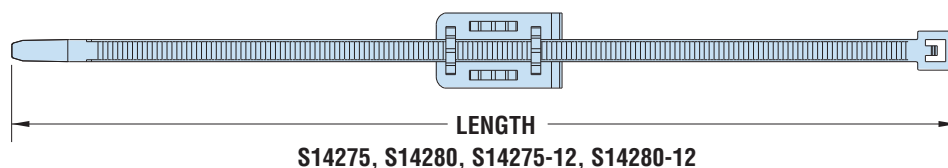

#### PARALLEL

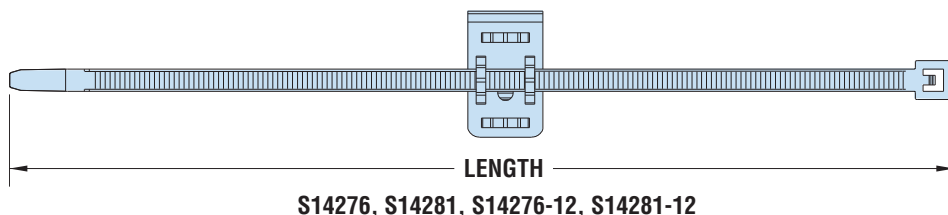

Material	S6474 & S6475 Clips: 304 stainless steel Cable Tie: Nylon 6/6 high impact modified, heat and UV stabilized or Nylon 12
Flammability Rating	94V-2
Temperature Range	-40°F (-40°C) to 221°F (105°C)

*Quick  
Specs*

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[S14280](#) [S14275](#) [S14281](#) [S14276](#) [S14275-12](#) [S14276-12](#) [S14281-12](#) [S14280-12](#)