

**HEYCO**



## Heyco® Open/Closed Bushings

Mounting Hole Diameter Range: .375" (9,5 mm) to 2.500" (63,5 mm)

| MOUNTING<br>HOLE<br>DIAMETER |     | PART NO. | DESCRIPTION | PART DIMENSIONS         |     |                       |     |                        |     |
|------------------------------|-----|----------|-------------|-------------------------|-----|-----------------------|-----|------------------------|-----|
|                              |     |          |             | A<br>Inside<br>Diameter |     | B<br>Head<br>Diameter |     | C<br>Overall<br>Height |     |
| in.                          | mm. | Black    |             | in.                     | mm. | in.                   | mm. | in.                    | mm. |

### Multiple Locking Steps for Panel Thickness up to .125" (3,2 mm)

|       |      |      |          |       |      |       |      |      |      |
|-------|------|------|----------|-------|------|-------|------|------|------|
| .375  | 9,5  | 2865 | OCB 375  | .265  | 6,7  | .421  | 10,7 | .390 | 9,9  |
| .437  | 11,1 | 2867 | OCB 437  | .330  | 8,4  | .500  | 12,7 |      |      |
| .500  | 12,7 | 2871 | OCB 500  | .312  | 7,9  | .562  | 14,3 |      |      |
| .562  | 14,3 | 2869 | OCB 562  | .390  | 9,9  | .640  | 16,3 |      |      |
| .625  | 15,9 | 2872 | OCB 625  | .453  | 11,1 | .687  | 17,5 |      |      |
| .750  | 19,1 | 2873 | OCB 750  | .546  | 12,7 | .782  | 19,8 | .406 | 10,3 |
| .875  | 22,2 | 2874 | OCB 875  | .671  | 14,3 | .921  | 23,4 |      |      |
| 1.000 | 25,4 | 2878 | OCB 1000 | .812  | 19,1 | 1.047 | 26,6 |      |      |
| 1.093 | 27,8 | 2879 | OCB 1093 | .875  | 20,6 | 1.156 | 29,4 |      |      |
| 1.250 | 31,8 | 2881 | OCB 1250 | 1.046 | 25,8 | 1.343 | 34,1 |      |      |
| 1.375 | 34,9 | 2882 | OCB 1375 | 1.171 | 25,4 | 1.468 | 37,3 |      |      |
| 1.500 | 38,1 | 2883 | OCB 1500 | 1.250 | 26,9 | 1.578 | 40,1 | .421 | 10,7 |
| 2.000 | 50,8 | 2900 | OCB 2000 | 1.730 | 43,9 | 2.120 | 53,9 |      |      |

### Multiple Locking Steps for Panel Thickness up to .250" (6,4 mm)


|       |      |      |         |       |      |       |      |      |      |
|-------|------|------|---------|-------|------|-------|------|------|------|
| 2.500 | 63,5 | 2909 | OCB 2.5 | 2.000 | 50,8 | 2.600 | 66,0 | .720 | 18,3 |
|-------|------|------|---------|-------|------|-------|------|------|------|

Standard color black. Consult Heyco for white and other colors.

**NEW!**

**NEW!**

- Split design allows side entry and encirclement of preassembled harnesses, capillary tubes, computer cables, power cords, or other assemblies that have segments larger than the bushing's I.D.
- May also be assembled into holes that already contain cable, wire or other filaments.
- Fingertip pressure snap-locks the bushing into its mounting hole.
- Locking fingers in fractional increments up to the maximum panel thickness.
- Multiple sizes for use in mounting holes from .375" (9,5 mm) to 2.500" (63,5 mm).

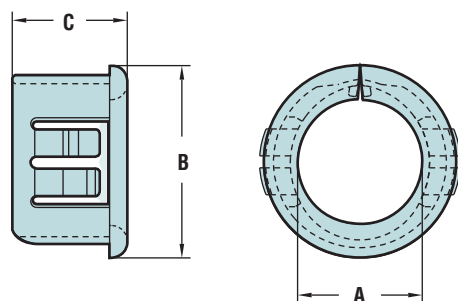

#### Material

Nylon 6/6

#### Certifications



Recognized under the Component Program of Underwriters' Laboratories File E15331



Certified by the Canadian Standards Association File 8919

#### Flammability Rating

94V-2

#### Material Temperature Index

257°F (125°C)—Maximum temperature on part not to exceed 221°F (105°C)

*Quick  
Specs*

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[2881](#) [2883](#) [2882](#) [2869](#) [2865](#) [2872](#) [2874](#) [2878](#) [2871](#) [2879](#) [2873](#) [2867](#) [2909](#) [2900](#)