

**ALL NEW
PRODUCTS!**


**STANDARD
PACK
1,000/BAG**



HEYClip™ Releasable Type T Rivets

WILL FIT THESE PANELS						PART NO.		DESCRIPTION	PART DIMENSIONS						STYLE	
MOUNTING HOLE DIA.	ASSEMBLED PANEL THICKNESS					Black	White		A Length		B Head Height		C Head Diameter			
	Min.		Max.						in.	mm.	in.	mm.	in.	mm.		
	in.	mm.	in.	mm.												
KR Series																
.122	3,1	.04	1,0	.08	2,0	9088	9089	KR 122-039	.14	3,5	.32	8,0	.39	10,0	1	
		.08	2,0	.12	3,0	9090	9091	KR 122-079	.18	4,5						
		.12	3,0	.16	4,0	9092	9093	KR 122-118	.22	5,5						
		.16	4,0	.20	5,0	9094	9095	KR 122-157	.26	6,5						
		.20	5,0	.24	6,0	9194	9195	KR 122-197	.30	7,5						
		.22	5,5	.26	6,5	9096	9097	KR 122-217	.32	8,0						
.142	3,6	.04	1,0	.08	2,0	9098	9099	KR 142-039	.14	3,5	.32	8,0	.39	10,0	2	
		.08	2,0	.12	3,0	9100	9101	KR 142-079	.18	4,5						
		.12	3,0	.16	4,0	9102	9103	KR 142-118	.22	5,5						
		.14	3,5	.18	4,5	9104	9105	KR 142-137	.24	6,0						
		.18	4,5	.22	5,5	9106	9107	KR 142-177	.28	7,0						
		.22	5,5	.26	6,5	9196	9197	KR 142-217	.32	8,0						
.161	4,1	.10	2,5	.14	3,5	9108	9109	KR 161-098	.20	5,0	.32	8,0	.47	12,0	2	
		.14	3,5	.18	4,5	9110	9111	KR 161-137	.24	6,0						
		.18	4,5	.22	5,5	9112	9113	KR 161-177	.28	7,0						
		.22	5,5	.26	6,5	9114	9115	KR 161-217	.32	8,0						
		.26	6,5	.30	7,5	9198	9199	KR 161-256	.35	9,0						
		.30	7,5	.34	8,5	9116	9117	KR 161-295	.39	10,0						

Standard colors black and white.

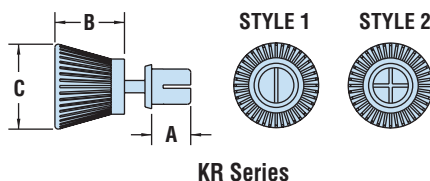

HEYClip™ Type P Snap Rivets



Polysulfone High Temperature Snap Rivets

**ALL NEW
PRODUCTS!**

WILL FIT THESE PANELS						PART NO.	DESCRIPTION	PART DIMENSIONS						STYLE	
MOUNTING HOLE DIA.	ASSEMBLED PANEL THICKNESS							Black	A Length		B Head Height		C Head Diameter		
	Min.		Max.												
	in.	mm.	in.	mm.											
PRP Series															
		.078	2.0	.118	3.0	9349	PRP 122-079	.18	4,5						
.122	3,1	.118	3.0	.157	4.0	9350	PRP 122-118	.22	5,6	.06	1,6	.25	6,4	1	
.161	4,1	.157	4.0	.197	5.0	9351	PRP 122-157	.26	6,5	.04	1,0	.28	7,0	2	

Standard color black.

	KR Series	PRP
Material	Nylon 6	Polysulfone (PSU)
Flammability Rating	94V-2	94-HB
Temperature Range	-.4°F (-18°C) to 185°F (85°C)	32°F (0°C) to 302°F (150°C)

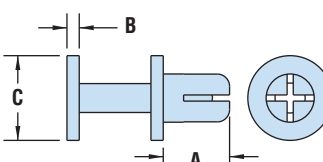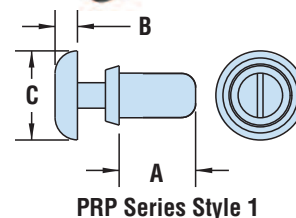

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[9114](#) [9116](#) [9090](#) [9094](#) [9106](#) [9110](#) [9108](#) [9194](#) [9092](#) [9104](#) [9102](#) [9198](#) [9112](#) [9100](#) [9098](#) [9096](#) [9088](#) [9196](#)
[9350](#) [9349](#) [9351](#)