




HEYClip™ Unscrewing Snap Rivets


| WILL FIT THESE PANELS | | | | | | PART NO. | DESCRIPTION | PART DIMENSIONS | | | | | | STYLE |
|-----------------------|-----|---------------------------|----------|----------|----------|-------------|--------------|-----------------|------|---------------|-----|-----------------|------|-------|
| MOUNTING HOLE DIA. | | ASSEMBLED PANEL THICKNESS | | | | | | A Length | | B Head Height | | C Head Diameter | | |
| in. | mm. | Min. in. | Max. in. | Min. mm. | Max. mm. | | | in. | mm. | in. | mm. | in. | mm. | |
| HUSR Series | | | | | | | | | | | | | | |
| .197 | 5,0 | .059 | 1,5 | .236 | 6,0 | 4330 | HUSR 197-158 | .43 | 11,0 | .15 | 3,9 | .47 | 12,0 | 1 |
| .236 | 6,0 | | | | | 4331 | HUSR 236-059 | .43 | 11,0 | .15 | 3,9 | .63 | 16,0 | |
| .315 | 8,0 | .118 | 3,0 | .394 | 10,0 | 4332 | HUSR 315-118 | .55 | 14,0 | .16 | 4,0 | .79 | 20,0 | 2 |
| | | .276 | 7,0 | .315 | 8,0 | 4333 | HUSR 315-276 | .80 | 20,3 | .14 | 3,6 | .79 | 20,0 | 3 |

Standard color black.


• Phillips head screw driver required for removal.

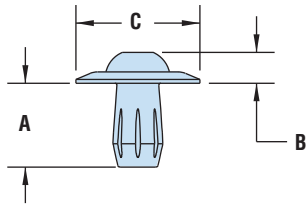

Style 1

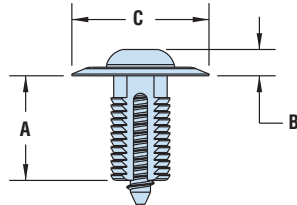

Style 2

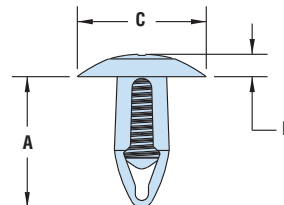


Style 3

HEYClip™ Tough Rivets

| WILL FIT THESE PANELS | | | | | | | | PART NO. | DESCRIPTION | PART DIMENSIONS | | | | | |
|------------------------|-------------|---------------------------|-------------|-------------|-------------|----------|-----|--------------|-------------|-----------------|------|-----------------|-----|-----|------|
| MOUNTING HOLE DIAMETER | | ASSEMBLED PANEL THICKNESS | | | | A Length | | | | B Head Height | | C Head Diameter | | | |
| Minimum in. | Maximum mm. | Minimum in. | Maximum in. | Minimum mm. | Maximum mm. | in. | mm. | | | in. | mm. | in. | mm. | | |
| Mini | | | | | | | | | | | | | | | |
| .122 | 3,1 | .128 | 3,3 | .155 | 3,9 | .180 | 4,6 | 12475 | MTR 180-125 | .37 | 9,4 | .05 | 1,3 | .22 | 5,5 |
| .144 | 3,7 | .154 | 3,9 | .265 | 6,7 | .290 | 7,4 | 12477 | MTR 290-150 | .47 | 11,9 | .05 | 1,3 | .30 | 7,6 |
| Standard | | | | | | | | | | | | | | | |
| .193 | 4,9 | .205 | 5,2 | .059 | 1,5 | .181 | 4,6 | 12466 | TR 181-199 | .45 | 11,3 | .04 | 1,0 | .28 | 7,2 |
| .250 | 6,4 | .276 | 7,0 | .098 | 2,5 | .315 | 8,0 | 12468 | TR 315-263 | .90 | 22,8 | .08 | 2,0 | .59 | 15,0 |
| .315 | 8,0 | .325 | 8,3 | .118 | 3,0 | .315 | 8,0 | 12469 | TR 315-320 | .79 | 20,0 | .11 | 2,7 | | |

ALL NEW!

Standard color black.

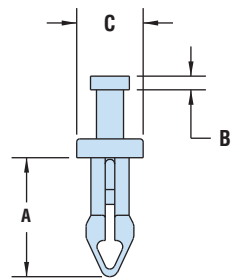

MTR Series

| | HUSR & HMP | MTR | TR |
|---------------------|----------------------------|-----------------------------|-----------------------------|
| Material | Nylon 6/6 | Heat stabilized Nylon 6 | Nylon 6/6 |
| Flammability Rating | 94V-2 | 94 V-2 | 94HB |
| Temperature Range | 32°F (0°C) to 185°F (85°C) | 32°F (0°C) to 230°F (110°C) | 32°F (0°C) to 230°F (110°C) |

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[4331](#) [4330](#) [12477](#) [12475](#) [4333](#) [4332](#) [12468](#) [12466](#) [12469](#)