




Heyco® Nylon PCB Supports - Threaded Male

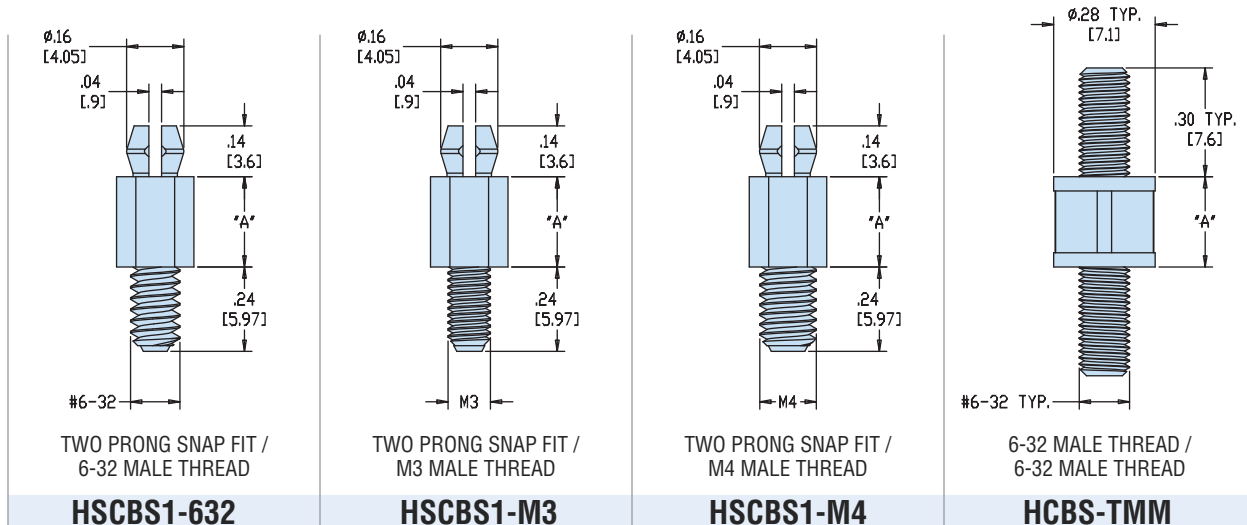

	Maximum Thread Lg †		Mounting Hole Diameter			Maximum Thread Lg †		Mounting Hole Diameter			Maximum Thread Lg †		Mounting Hole Diameter	
	in.	mm.	in.	mm.		in.	mm.	in.	mm.		in.	mm.	in.	mm.
PCB	.062	1,6	.153	3,9		.062	1,6	.153	3,9		.062	1,6	.153	3,9
Chassis	.236	6,0	6-32			.236	6,0		M3		.236	6,0		M4

A	in.	mm.	PART NO. Natural	DESCRIPTION	PART NO. Natural*	DESCRIPTION	PART NO. Natural*	DESCRIPTION	PART NO. Natural	DESCRIPTION
.125		3,2	10689	HSCBS1-632-02	10698	HSCBS1-M3-02	10707	HSCBS1-M4-02		
.187		4,8	10690	HSCBS1-632-03	10699	HSCBS1-M3-03	10708	HSCBS1-M4-03		
.250		6,4	10691	HSCBS1-632-04	10700	HSCBS1-M3-04	10709	HSCBS1-M4-04	10817	HCBS-TMM-04
.375		9,5	10692	HSCBS1-632-06	10701	HSCBS1-M3-06	10710	HSCBS1-M4-06	10818	HCBS-TMM-06
.500		12,7	10693	HSCBS1-632-08	10702	HSCBS1-M3-08	10711	HSCBS1-M4-08	10819	HCBS-TMM-08
.625		15,9	10694	HSCBS1-632-10	10703	HSCBS1-M3-10	10712	HSCBS1-M4-10	10820	HCBS-TMM-10
.750		19,1	10695	HSCBS1-632-12	10704	HSCBS1-M3-12	10713	HSCBS1-M4-12	10821	HCBS-TMM-12
.875		22,2	10696	HSCBS1-632-14	10705	HSCBS1-M3-14	10714	HSCBS1-M4-14	10822	HCBS-TMM-14
1.000		25,4							10823	HCBS-TMM-16

Standard color natural. For special order parts in UL 94V-0 natural material, add the suffix "F" to Part No.

*Consult Heyco for HSCBS1-M3 and HSCBS1-M4 in V-0 material.

†Thread length at Chassis (and at PCB for HCBS-TMM)

Material: Nylon 6/6
Flammability Rating: 94V-2
Temperature Range: .4°F (-18°C) to 185°F (85°C)

Quick Specs

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[10817](#) [10823](#) [10821](#) [10820](#) [10819](#) [10818](#) [10822](#) [10708](#) [10702](#) [10700](#) [10714](#) [10696](#) [10694](#) [10711](#) [10690](#)
[10710](#) [10712](#) [10703](#) [10695](#) [10705](#) [10692](#) [10707](#) [10713](#) [10691](#) [10689](#) [10709](#) [10699](#) [10701](#) [10693](#) [10704](#)
[10698](#)