



Heyco® Nylon PCB Supports

Tension Barb Style

- **Provide spacing** between the printed circuit board and the panel or between circuit boards.
- Wide, ribbed wings produce a secure fit with extra stability.
- Multiple spacing heights from .187" (4,7 mm) to .750" (19,0 mm).
- Two Styles:
 - 1) Panel barb end, plus tension barb end for PCB.
 - 2) Panel barb end, plus locking barb end for PCB.

PANEL DIMENSIONS		PCB DIMENSIONS		PART NO.	DESCRIPTION	PART DIMENSIONS					
Maximum Thickness	Mounting Hole Diameter	Maximum Thickness	Mounting Hole Diameter			A Spacing	B Head Length	C* Foot Length			
in. mm.	in. mm.	in. mm.	in. mm.	Natural		in. mm.	in. mm.	in. mm.	in. mm.	in. mm.	

SS T Series

.07	1,8	.187	4,7	.06	1,6	.156	4,0	3640	SS T 3/16	.19	4,8				
								3641	SS T 1/4	.25	6,4				
								3642	SS T 3/8	.38	9,5				
								3643	SS T 7/16	.44	11,1	.40	10,2	.20	5,1
								3644	SS T 1/2	.50	12,7				
								3645	SS T 5/8	.63	15,9				
								3646	SS T 3/4	.75	19,0				

Standard color natural.

*Extension beyond .070" (1,8 mm) thick panel.

Locking Barb Style


PANEL DIMENSIONS		PCB DIMENSIONS		PART NO.	DESCRIPTION	PART DIMENSIONS					
Maximum Thickness	Mounting Hole Diameter	Maximum Thickness	Mounting Hole Diameter			A Spacing	B Head Length	C* Foot Length			
in. mm.	in. mm.	in. mm.	in. mm.	Natural		in. mm.	in. mm.	in. mm.	in. mm.	in. mm.	

SS L Series


.07	1,8	.187	4,7	.06	1,6	.156	4,0	3670	SS L 3/16	.19	4,8				
								3671	SS L 1/4	.25	6,4				
								3672	SS L 3/8	.38	9,5				
								3673	SS L 7/16	.44	11,1	.35	8,9	.20	5,1
								3674	SS L 1/2	.50	12,7				
								3675	SS L 5/8	.63	15,9				
								3676	SS L 3/4	.75	19,0				

Standard color natural.

*Extension beyond .070" (1,8 mm) thick panel.

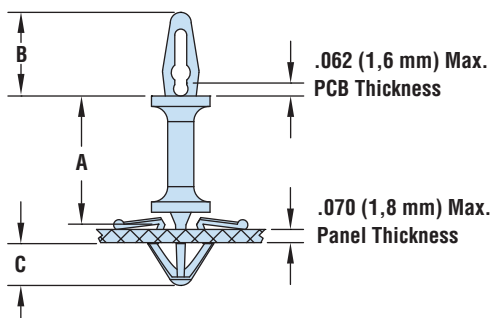

Tension Barb

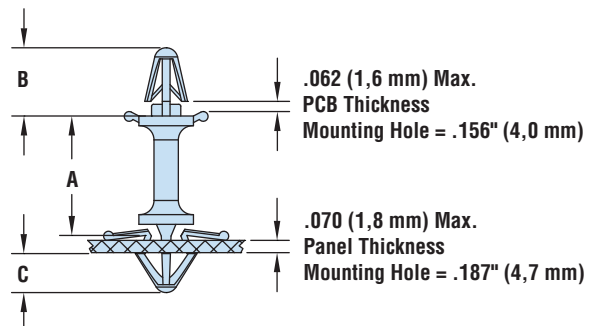

Locking Barb

Quick
Specs

Material
Certifications

Flammability Rating
Temperature Range

Nylon 6/6

Recognized under the Component Program of Underwriters' Laboratories File E197049

94V-2

32°F (0°C) to 185°F (85°C)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[3674](#) [3670](#) [3672](#) [3671](#) [3676](#) [3675](#) [3673](#)