




- Retaining fingers without locking steps provide friction fit and allow removal of bushing.
- Insulate and mechanically protect electrical and telecommunications cables, tubing, hose, rope, and utility lines.
- Convert raw-edged holes to smooth, neat, insulated holes.
- Available in polypropylene. Consult Heyco.
- Available in multiple sizes for use in .375" (9,5 mm) to 1.375" (34,9 mm) diameter holes.

Heyco® Pry Out Bushings



Mounting Hole Diameter Range: .375" (9,5 mm) to 1.375" (34,9 mm)

MOUNTING HOLE DIAMETER		PART NO.		DESCRIPTION	PART DIMENSIONS			
in.	mm.	Black	White		A Head Diameter		B Overall Height	
					in.	mm.	in.	mm.
Clearance Fit for Panel Thickness up to .172" (4,4 mm)								
.375	9,5	14059	14060	POB 375	.57	14,5	.41	10,4
.500	12,7	14065	14066	POB 500	.67	17,0		
.625	15,9	14071	14072	POB 625	.79	20,1		
.750	19,0	14077	14078	POB 750	.97	24,6		
.875	22,2	14083	14084	POB 875	1.05	26,7		
1.000	25,4	14086	14087	POB 1000	1.20	30,5		
1.093	27,8	14089	14090	POB 1093	1.30	33,0	.45	11,4
1.375	34,9	14098	14099	POB 1375	1.58	40,1		


Standard color black. Consult Heyco for other colors.

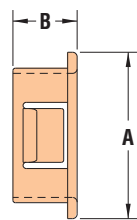

POB

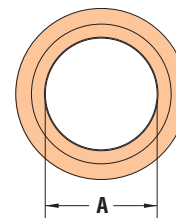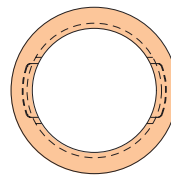

TRG

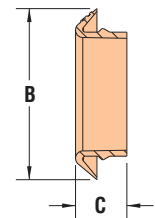

Heyco® UL Recognized Thermoplastic Rubber Grommets

Mounting Hole Diameter Range: .375" (9,5 mm) to 2.000" (50,8 mm)

MOUNTING HOLE DIAMETER		PART NO.	DESCRIPTION	PART DIMENSIONS					
		Black		A Inside Diameter		B Head Diameter		C Overall Height	
in.	mm.			in.	mm.	in.	mm.	in.	mm.
For Panel Thickness from .03" (0,8 mm) to .094" (2,4 mm)									
.375	9,5	13804	TRG 375-270	.28	7,1	.70	17,8	.36	9,1
.500	12,7	13808	TRG 500-395	.41	10,4	.83	21,1		
.625	15,9	13813	TRG 625-520	.53	13,5	.95	24,1		
For Panel Thickness from .03" (0,8 mm) to .125" (3,2 mm)									
.750	19,1	13817	TRG 750-645	.66	16,8	1.07	27,2	.36	9,1
.875	22,2	13821	TRG 875-770	.79	20,1	1.20	30,5		
1.000	25,4	13824	TRG 1000-890	.91	23,1	1.33	33,8		
1.093	27,8	13828	TRG 1093-1000	1.01	25,7	1.42	36,1		
1.250	31,8	13831	TRG 1250-1125	1.14	29,0	1.57	39,9		
1.375	34,9	13833	TRG 1375-1250	1.26	32,0	1.70	43,2		
1.500	38,1	13835	TRG 1500-1375	1.39	35,3	1.83	46,5		
2.000	50,8	13840	TRG 2000-1875	1.89	48,0	2.33	59,2		

Standard color black.

Quick Specs

	POB	TRG
Material	Nylon 6/6	Flex Temp (Thermoplastic Rubber)
Certifications		UL Recognized under the Component Program of Underwriters' Laboratories, File E15331
Flammability Rating	94V-2	94-HB
Temperature Range	-40°F (-40°C) to 221°F (105°C)	32°F (0°C) to 122°F (50°C)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[13831](#) [13824](#) [13828](#) [13835](#) [13813](#) [13817](#) [13840](#) [13804](#) [13808](#) [13833](#) [13821](#)