

## Heyco® Hinged Edge Strain Relief Bushings

Designed for Rectangular Edge Slot or Split Panel Mounting – suitable for retrofit applications

| WILL FIT THESE CABLES |                |                 | PANEL DIMENSIONS         |     |     |     |           |     | PART NO.<br>Black | DESCRIPTION | BODY LENGTH |     |
|-----------------------|----------------|-----------------|--------------------------|-----|-----|-----|-----------|-----|-------------------|-------------|-------------|-----|
| UL Type               | AWG/<br>Conds. | Approx.<br>Size | Edge Slot or Split Panel |     |     |     | Thickness |     |                   |             | in.         | mm. |
|                       |                |                 | X                        |     | Y   |     | in.       | mm. |                   |             |             |     |
|                       |                |                 | in.                      | mm. | in. | mm. |           |     |                   |             |             |     |


### ST 101A – For Round or Flat Cables

|          |      |      |     |      |      |      |      |     |     |      |         |     |      |
|----------|------|------|-----|------|------|------|------|-----|-----|------|---------|-----|------|
| SV & SVT | 18/2 | .220 | 5,6 | .512 | 13,0 | .453 | 11,5 | .06 | 1,6 | 1839 | ST 101A | .55 | 14,0 |
|          | 18/3 | .245 | 6,2 |      |      |      |      |     |     |      |         |     |      |
| HPD      | 18/2 | .250 | 6,4 | .512 | 13,0 | .453 | 11,5 | .06 | 1,6 | 1839 | ST 101A | .55 | 14,0 |
|          | 16/2 | .255 | 6,5 |      |      |      |      |     |     |      |         |     |      |
| HPD      | 18/2 | .270 | 6,9 | .512 | 13,0 | .453 | 11,5 | .06 | 1,6 | 1839 | ST 101A | .55 | 14,0 |
|          | 16/2 | .290 | 7,4 |      |      |      |      |     |     |      |         |     |      |

### SR 8R-200 – For Round, Flat or Multiple Cables

|                         |            |            |      |      |      |      |     |     |      |           |     |      |
|-------------------------|------------|------------|------|------|------|------|-----|-----|------|-----------|-----|------|
| Round, Flat or Multiple | up to .600 | up to 15,2 | .875 | 22,2 | .875 | 22,2 | .10 | 2,5 | 1266 | SR 8R-200 | .80 | 20,3 |
|-------------------------|------------|------------|------|------|------|------|-----|-----|------|-----------|-----|------|

Standard color black. Consult Heyco for white and other colors

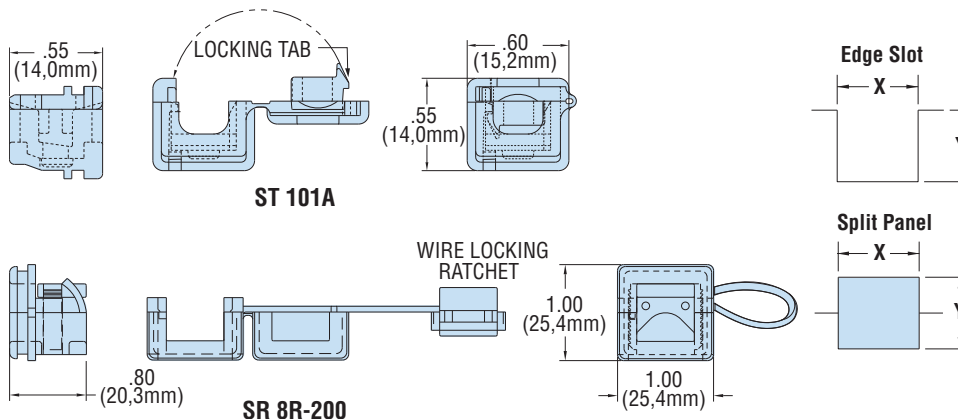

- Designed for rectangular edge slot or split panel mounting - suitable for retrofit applications.
- Independent of final mounting, Hinged Edge Strain Reliefs self-lock onto the cable and may be preassembled "off line" for final assembly at a later time or remote location.
- Rectangular design eliminates the possibility of part rotation under forces of twist.
- SR 8R-200's unique wire locking ratchet allows for a generous wire range of .25" (6,4 mm) to .60" (15,2 mm).
- Heyco's automated Pre-Assembly Equipment (for ST 101A only) speeds assembly onto the cable, reducing both cost and the risk of carpal tunnel syndrome. See pages 4-15 & 4-16 in the Heyco Catalog.
- For our complete line of Strain Relief Bushings, see Section 4 in the Heyco Catalog.




## HEYClip™ Edge Cable Holders

Designed for Rectangular Edge Slot Mounting - suitable for retrofit applications

| WIRE<br>CAPACITY |                | PANEL DIMENSIONS |      |       |      |      |     | Thickness      |              | PART<br>NO. | DESC.   | PART DIMENSIONS |      |      |      |
|------------------|----------------|------------------|------|-------|------|------|-----|----------------|--------------|-------------|---------|-----------------|------|------|------|
|                  |                | Edge Slot Size   |      | X     |      | Y    |     |                |              |             |         | W               |      | A    |      |
| in.              | mm.            | in.              | mm.  | in.   | mm.  | in.  | mm. | in.            | mm.          |             |         | in.             | mm.  | in.  | mm.  |
| .46 x<br>.29     | 11,6 x<br>7,4  | .551             | 14,0 | .484  | 12,4 | .106 | 2,7 | .031 -<br>.063 | 0,8 -<br>1,6 | 4246        | CH E-14 | .78             | 19,8 | .64  | 16,3 |
| .66 x<br>.59     | 16,7 x<br>15,0 | .756             | 19,2 | .831  | 21,1 | .098 | 2,5 | .031 -<br>.063 | 0,8 -<br>1,6 | 4247        | CH E-19 | 1.06            | 26,8 | .98  | 24,9 |
| .66 x<br>.58     | 16,8 x<br>14,7 | .827             | 21,0 | .827  | 21,0 | .094 | 2,4 | .031 -<br>.063 | 0,8 -<br>1,6 | 4248        | CH E-21 | 1.13            | 28,8 | .98  | 24,9 |
| .90 x<br>.91     | 22,8 x<br>23,1 | 1.063            | 27,0 | 1.140 | 29,0 | .118 | 3,0 | .031 -<br>.063 | 0,8 -<br>1,6 | 4249        | CH E-27 | 1.37            | 34,8 | 1.31 | 33,3 |

Standard color natural.

|                     |                                                                                                                                                                                              |
|---------------------|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Material            | Nylon 6/6                                                                                                                                                                                    |
| Certifications      | Recognized under the Component Program of Underwriters' Laboratories File E15331 (ST & SR Parts only)<br>Canadian Certified by Canadian Standards Association File 8919 (ST & SR Parts only) |
| Flammability Rating | 94V-2                                                                                                                                                                                        |
| Temperature Range   | 32°F (0°C) to 221°F (105°C) - (ST & SR Parts)<br>32°F (0°C) to 185°F (85°C) - (CH E Parts)                                                                                                   |

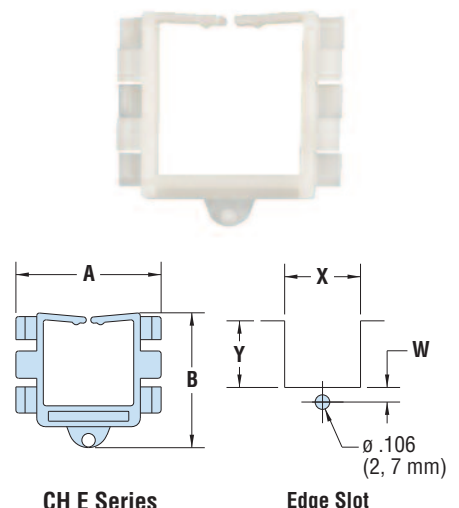

CH E Series

Edge Slot

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[1839](#) [1266](#) [4249](#) [4248](#) [4246](#) [4247](#) [4235](#) [1267](#) [1840](#)