



Heyco® TPE Liquid Tight Hole Plugs

Standard 85 Durometer Plugs

Maximum Panel Thickness .125" (3,2 mm)

Mounting Hole Diameter Range: .500" (12,7 mm) to 1.375" (34,9 mm)

- Oil tight, rain tight, submersible.
- UL certified for outdoor applications.
- Install with fingertip pressure (no tool required).
- Multiple nominal sizes fit .500" (12,7 mm) to 1.000" (25,4 mm) true size mounting holes.
- Three trade sizes fit 1/2" to 1" knock-out holes.
- Lock firmly in boxes from .03" (0,8 mm) to .13" (3,2 mm) thick.
- True sizes are UL recognized under Underwriters' Laboratories File E51579 and CSA certified by Canadian Standard Association File 8919.
- Trade sizes are UL listed under Underwriters' Laboratories File E51579 and CSA certified by Canadian Standard Association File 081067C. Now certified for **NEMA 4 and 4X applications.**

MOUNTING HOLE DIAMETER		PART NO. Black	DESCRIPTION	UL or 	PART DIMENSIONS					
in.	mm.				A Head Diameter		B Overall Height		C Head Thickness	
					in.	mm.	in.	mm.	in.	mm.
.500	12,7	3830	KOS LT 500		.91	23,1	.45	11,4	.29	7,4
.625	15,9	3834	KOS LT 625		1.03	26,2	.47	11,9	.31	7,9
.750	19,1	3831	KOS LT 750		1.15	29,2	.51	13,0	.35	8,9
.875	22,2	3833	KOS LT 1/2		1.23	32,5	.50	13,5	.36	9,1
1.000	25,4	3832	KOS LT 1000		1.41	35,8	.56	14,2	.40	10,2
1.093	27,8	3835	KOS LT 3/4		1.53	38,6	.55	14,0		
1.375	34,9	3837	KOS LT 1		1.78	45,2	.57	14,5	.42	10,7

Available in black only.

Low 75 Durometer Plugs


Maximum Panel Thickness .125" (3,2 mm)

Mounting Hole Diameter Range: .875" (22,2 mm) to 1.375" (34,9 mm)

MOUNTING HOLE DIAMETER*		PART NO.		DESCRIPTION	UL or 	PART DIMENSIONS*					
		Black	Gray			A Head Diameter		B Overall Height		C Head Thickness	
in.	mm.					in.	mm.	in.	mm.	in.	mm.
.875	22,2	3833FN	3833FP	KOS LT 1/2 LD		1.23	32,5	.53	13,5	.36	9,1
1.093	27,8	3835FN	3835FP	KOS LT 3/4 LD		1.53	38,6	.55	14,0	.40	10,2
1.375	34,9	3837FN	3837FP	KOS LT 1 LD		1.80	45,2	.56	14,3	.42	10,7

Standard colors black and gray.

*Consult Heyco for other Liquid Tight Hole Plug sizes in Low Durometer material.

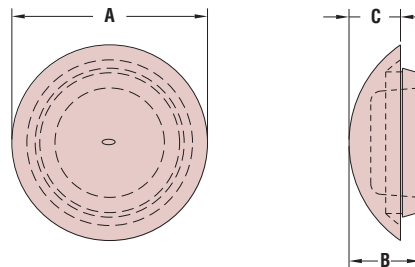

Quick Specs

Material	85 Durometer 75 Durometer	TPE-Hardness 85 Shore A TPE-Hardness 75 Shore A
Certifications	Trade Sizes (1/2, 3/4, 1)	 Listed under Underwriters' Laboratories File E51579
	True Sizes (all others)	 Certified by Canadian Standard Association File 081067C
		 Recognized under Underwriters' Laboratories File E51579
Flammability Rating	94V-0	
Temperature Range	-81°F (-60°C) to 275°F (135°C)	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[3835](#) [3833](#) [3837](#) [3834](#) [3830](#) [3831](#) [3832](#) [3835FN](#) [3833FN](#) [3837FP](#) [3837FN](#) [3835FP](#) [3833FP](#) [3832-P](#) [3833EU](#)