













## Heyco®-Tite Liquid Tight Cordgrips


### Straight-Thru, NPT Hubs with Integral Sealing Ring

*The Ultimate in Liquid Tight Strain Relief Protection*

- Integral Sealing Ring ensures a superior seal at the clearance or threaded mounting hole location, every time.
- Widest range of approved cable diameters. Cable ranges listed are for the maximum IP68 sealing range. Contact Heyco for UL approved 514B cable ranges.
- IP 68 rated.
- Approved for **NEMA 4, 4X, 6 and 6P** applications.
- Ratchet design of sealing nut assembly provides superior anti-vibration protection and ensures a firm grip on the cable.
- Acme threads on body prevent skipping and speed installation.
- All nylon construction with Buna N or TPE sealing gland resists salt water, weak acids, gasoline, alcohol, oil, grease, and common solvents. (This feature is not assessed by UL.)
- Multiple sizes for flexible cord diameters ranging from .065" (1,7 mm) to 1.730" (44,0 mm).
- We recommend using the fitting with the smallest maximum diameter that will fit your application.
- **Locknuts not included.** For nylon locknut specifications or to order locknuts separately, see page 3-47.
- For Heyco Liquid Tight Threaded Plugs, see page 3-51.
- Consult Heyco for cordgrips molded in other colors.

CABLE DIA. RANGE				PART NO.		DESCRIPTION		PART DIMENSIONS									
Minimum		Maximum		Black	Gray			A	B	C	D	E					
Clearance Hole Dia.		Max. O.A. Length		Thread Length				Wrenching Thk.		Nut Flat Size							
in.	mm.	in.	mm.					in.	mm.	in.	mm.	in.	mm.	in.	mm.		
.065	1,7	.210	5,3	M4514	M4515	RLTCG 1/4		.540	13,7	1.29	32,8	.45	11,4	.21	5,3	.63	16,0
.115	2,9	.250	6,4	M4516	M4517	LTCG 1/4		.680	17,3	1.41	35,8	.49	12,4	.21	5,3	.82	20,8
.065	1,7	.230	5,8	M3458	M3459	RLTCG 3/8		.680	17,3	1.41	35,8	.49	12,4	.21	5,3	.82	20,8
.105	2,7	.315	8,0	M3228	M3229	LTCG 3/8		.875	22,2	1.70	43,2	.61	15,5	.21	5,3	.98	24,9
.095	2,4	.290	7,4	M4518	M4519	RLTCG 1/2		.875	22,2	1.70	43,2	.61	15,5	.21	5,3	.98	24,9
.170	4,3	.450	11,4	M3231	M3232	LTCG 1/2		.875	22,2	1.68	42,7	.44	11,2	.25	6,4	1.06	26,9
.180	4,6	.400	10,2	M4520	M4521	RLTCG LL 1/2		.875	22,2	1.68	42,7	.44	11,2	.25	6,4	1.06	26,9
.270	6,9	.545	13,8	M3200	M3201	LTCG LL 1/2		.875	22,2	2.00	50,8	.62	15,7	.25	6,4	1.30	33,0
.250	6,4	.490	12,4	M3460	M3461	RLTCG 3/4		1.109	28,2	2.00	50,8	.62	15,7	.25	6,4	1.30	33,0
.420	10,7	.630	16,0	M3234GA	M3235GA	LTCG 3/4		1.326	33,7	2.41	61,2	.76	19,3	.30	7,6	1.73	43,9
.435	11,0	.705	17,9	M3234	M3235	LTCG 3/4		1.326	33,7	2.41	61,2	.76	19,3	.30	7,6	1.73	43,9
.490	12,4	.785	19,9	M8439	M8440	RLTCG 1		1.680	42,7	2.69	68,3	.78	19,8	.30	7,6	2.05	52,1
.590	15,0	1.000	25,4	M8437	M8438	LTCG 1		1.680	42,7	2.69	68,3	.78	19,8	.30	7,6	2.05	52,1
.787	20,0	1.020	25,9	M4522	M4523	RLTCG 1-1/4		1.920	48,8	2.81	71,3	.77	19,6	.36	9,1	2.46	62,5
.875	22,2	1.260	32,0	M4524	M4525	LTCG 1-1/4		1.920	48,8	2.81	71,3	.77	19,6	.36	9,1	2.46	62,5
1.000	25,4	1.240	31,5	M3319	M3320	RLTCG 1-1/2		2.400	60,8	2.93	74,3	.79	20,1	.42	10,7	2.73	69,3
1.230	31,2	1.560	39,6	M3317	M3318	LTCG 1-1/2		2.400	60,8	2.93	74,3	.79	20,1	.42	10,7	2.73	69,3
1.160	29,5	1.350	34,3	M3323	M3324	RLTCG 2		2.400	60,8	2.93	74,3	.79	20,1	.42	10,7	2.73	69,3
1.450	36,8	1.730	43,9	M3321	M3322	LTCG 2											

Standard colors black and gray.

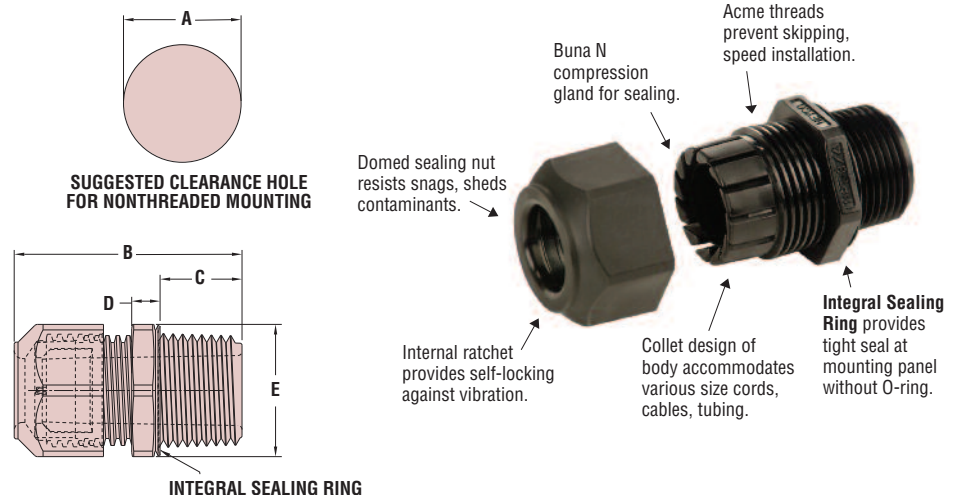

Material	Nylon 6/6 w/Buna N or TPE Sealing Gland
Certifications	<ul style="list-style-type: none"> <li>UL Listed under Underwriters' Laboratories File E51579</li> <li>Recognized under the Component Program of Underwriters' Laboratories File E51579</li> <li>CS Certified By Canadian Standard Association File 93876C</li> </ul>
Flammability Rating	94V-2-Consult factory for V0 material
Temperature Range	Static -40°F (-40°C) to 239°F (115°C) Dynamic -4°F (-20°C) to 212°F (100°C)
IP Rating	IP 68 (70 PSI, 5 BAR)

*Quick  
Specs*

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[M3460](#) [M3461](#) [M3235](#) [M3231](#) [M3232](#) [M3234](#) [M3228](#) [M3229](#) [M3459](#) [M3458](#) [M8438](#) [M8439](#) [M8437](#) [M8440](#)  
[M4518](#) [M4519](#) [M3200](#) [M3317](#) [M3318](#) [M3319](#) [M3320](#) [M3321](#) [M3322](#) [M3323](#) [M3324](#) [M4516](#) [M4524](#) [M4522](#)  
[M4514](#) [M4520](#) [M3201](#) [M4521](#) [M3234GA](#) [M4515](#) [M4523](#) [M3235GA](#) [M4517](#) [M4525](#) [M8437GCY](#) [M3231CB](#)  
[M8437GBL](#) [M3200CB](#) [M4516CB](#)