



- Integral sealing ring ensures a **superior seal** at mounting hole location, every time; **IP 65, 67 and 68 Rated**.
- Allow the passage of air for pressure equalization, yet prevent moisture intrusion, remain liquid tight.
- UL Rated for Type NEMA 3R, 4, and 4X applications.
- Filter membrane is both hydrophobic and oleophobic and prevents moisture and particulate contamination in electronic enclosures.
- Pressure compensating seal prevents buildup of pressure inside of electronic enclosures due to environmental temperature cycling.
- Quick and easy installation into Threaded (LTTVP) and Clearance (LTSV) holes.
- Membrane seal is ultrasonically welded to nylon body.
- Lower cost option over metal or steel plugs.
- Approximate Head Thickness: .21" (5,3 mm). Thickness may vary.
- Hex shaped head for wrench installation (LTTVP only).
- Electrically non-conductive Nylon 6/6.
- Quick and easy **Snap-in** installation into Clearance Holes.
- All sizes and types feature 6 (six) vent holes.
- **Snap-In** plugs for panel and housing applications.
- Lower cost option over brass or steel plugs.
- Snap into a range of panel thicknesses up to .125" (3,2 mm) with no tools (LTSV only).


HEYClean™ Liquid Tight Threaded Vent Plugs

With Integral Sealing Ring and Liquid Tight Filter



THREAD Type/Size	PART NO.		DESCRIPTION	PART DIMENSIONS				CALCULATED FLOW VOLUME LPM @ 13.5 psi
	Black	Gray		A Wrenching Flats in. mm.		B Overall Length in. mm.		
NPT								
NPT 1/4	3544VB	3544V	LTTVP NPT 1/4	.63	16,0	.66	16,8	0.341
NPT 3/8	3545VB	3545V	LTTVP NPT 3/8	.83	21,0	.69	17,5	0.341
NPT 1/2	3546VB	3546V	LTTVP NPT 1/2	.98	24,9	.81	20,6	0.668
NPT 3/4	3547VB*	3547V*	LTTVP NPT 3/4	1.29	32,8	.86	21,8	0.668
PG - For PG Thread specifications, see page 3-49								
Pg 7	3574VB	3574V	LTTVP Pg 7	.63	16,0	.53	13,5	0.341
Pg 9	3575VB	3575V	LTTVP Pg 9	.83	21,0			0.341
Pg 13.5	3576VB	3576V	LTTVP Pg 13.5	.98	24,9	.62	15,8	0.668
Pg 21	3401VB	3401V	LTTVP Pg 21	1.29	32,8	.76	19,3	0.668
Metric								
M12	3582VB	3582V	LTTVP M12	.63	16,0	.53	13,5	0.341
M16	3583VB	3583V	LTTVP M16	.83	21,0			0.341
M20	3584VB	3584V	LTTVP M20	.98	24,9	.62	15,8	0.668

Standard color Black. Consult Heyco for other colors.


*IP 65 rated.

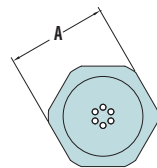

Threaded Vent Plug

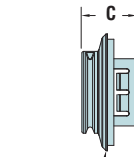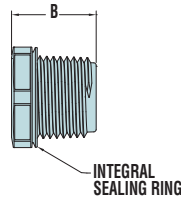

Snap-In Vent Plug

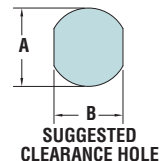

HEYClean™ Liquid Tight Snap-In Vent Plugs

With Integral Sealing Flange/Washer and Liquid Tight Filter

Mounting Hole Diameter Range: .500" (12,7 mm) to 1.125" (28,6 mm)

A		PART NO.	DESCRIPTION	PART DIMENSIONS				CALCULATED FLOW VOLUME LPM @ 13.5 psi
Mounting Hole Dia*				B		C		
Black				To Prevent Rotation		Max. O.A. Length		
in.	mm.			in.	mm.	in.	mm.	
.500	12,7	3481VB	LTSV 500	.45	11,4	.600	15,2	0.301
.875	22,2	3486VB	LTSV 875	.77	19,6	.620	15,7	0.301
1.125	28,6	3488VB	LTSV 1125	1.00	25,4	.660	16,8	0.524

Standard color black. Consult Heyco for other colors.

* Consult Heyco for additional sizes.

Quick
Specs

Material	Nylon 6/6 bodies with an Acrylic Copolymer Filter
Certifications	Recognized under the Component Program of Underwriters' Laboratories, File E330194 to both Canadian and U.S. Requirements
Flammability Rating	94V-2
Temperature Range	-40°F (-40°C) to 221°F (105°C)
IP Rating	IP 65/67/68

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[3544VB](#) [3575VB](#) [3488VB](#) [3486VB](#) [3584VB](#) [3545VB](#) [3574VB](#) [3582VB](#) [3547VB](#) [3583VB](#) [3546VB](#) [3576VB](#)
[3401VB](#) [3582V](#) [3575V](#) [3576V](#) [3583V](#) [3584V](#) [3401V](#) [3546V](#) [3547V](#) [3574V](#) [3584VL](#)