



- Ideal for securing, insulating, and routing cable and tubing.
- Cable and wire can be installed or removed for repair without removing clamp.
- Mounts with screws, mounting buttons or rivets.

Available in Small Packs

NEW

PART NO.	DESCRIPTION	QTY
4149-P	WHC 125 NATURAL 50PK	50
4150-P	WHC 250 NATURAL 50PK	
4151-P	WHC 375 NATURAL 50PK	
4152-P	WHC 500 NATURAL 50PK	
4153-P	WHC 625 NATURAL 50PK	
4154-P	WHC 750 NATURAL 50PK	
4210-P	WHC 1000 NATURAL 25PK	25
4211-P	WHC 1500 NATURAL 10PK	10



- Retainer clip allows clamp to be pre-positioned on hose before final installation.
- Double row of teeth for more secure grip.
- Quick and easy installation. Tighten instantly with hand pliers or Air Tool (on page 7-39).
- Reusable. Can be removed without cutting.
- Supertough nylon clamps offer additional clamping strength.
- Outlast tubing under pressure.
- Non-conductive and non-magnetic.
- No moving pieces to seize or vibrate loose.
- Maximum Pressure Rating: 200 PSI.

Quick Specs


Heyco® Nylon Wire Harness Clamps

MOUNTING HOLE DIAMETER		SCREW SIZE	PART DIMENSIONS						PART NO.	DESCRIPTION	STYLE
			A Bundle Dia.		B Overall Length		C Width				
in.	mm.		in.	mm.	in.	mm.	in.	mm.	Natural		
Snap Mouth *											
.157	4,0	#8	.50 .71	12,7 18,0	1.18 1.38	30,0 35,1	.39 .50	10,0 12,7	4127 4148	WHCX 500 WHCX 750	1 
Open Mouth											
.157	4,0	#8	.13	3,2	.77	19,5	.34	8,5	4149	WHC 125	2
			.25	6,4	.83	21,0	.39	10,0	4126	WHCX 250	3† 
.205	5,2	#10	.25	6,4	.86	21,8	.41	10,4	4150	WHC 250	3
			.38	9,0	.83	21,0	.40	10,2	4151	WHC 375	
			.50	12,5	1.16	29,4	.40	10,2	4152	WHC 500	
			.63	15,9	1.13	28,6	.50	12,7	4153	WHC 625	
			.75	19,1	1.28	32,5	.50	12,7	4154	WHC 750	
			.95	25,1	1.50	38,1	.50	12,7	4210	WHC 1000	
			1.50	38,1	2.12	53,9	.50	12,7	4211	WHC 1500	


Standard color natural.

*Bundle Diameter in closed position.


†No reinforcing ribs on Part No. 4126.

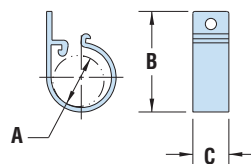

Style 1

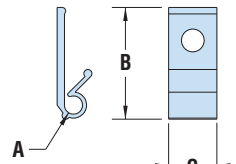

Style 2


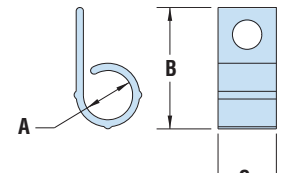


Style 3

Heyco® Nylon Lockit™ Hose Clamps

EFFECTIVE CLAMP RANGE				PART NO.	DESCRIPTION	PART DIMENSIONS				
Minimum Diameter		Maximum Diameter				Black	A Clamp Thickness		B Strap Thickness	
in.	mm.	in.	mm.				in.	mm.	in.	mm.
LHC Series										
.34	8,7	.41	10,3	2388	LHC 344	.25	6,4	.08	2,0	
.53	13,5	.59	15,1	2391	LHC 531					
.67	17,0	.81	20,6	2393	LHC 672					

 Standard color black.

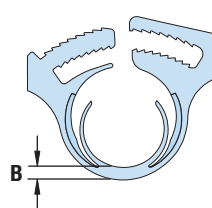

	WHCX & WHC	LHC
Material	Nylon 6/6	Nylon 6/6 Supertough
Flammability Rating	94V-2	94HB
Temperature Range	32°F (0°C) to 185°F (85°C)	32°F (0°C) to 185°F (85°C)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[4153-P](#) [4152-P](#) [4150-P](#) [4149-P](#) [4151-P](#) [4154-P](#) [4210-P](#) [4211-P](#)