

## Heyco® RDD Lockit™ Strain Relief Bushings – Straight-Thru

Snap onto **Round Cables** for Faster Assembly into **Double D Mounting Holes** –  
Semi-Automatic Equipment Available  
Fit 1/2" Electrical Knock-out Hole




WILL FIT THESE CABLES				PANEL DIMENSIONS				RDD LOCKIT STRAIN RELIEF for Faster Assembly			Corresponding Mounting Hole Plug	
UL Type	AWG/ Conductors	Approximate Size		Mounting Hole Size		Thickness		PART NO. Black	PART NO. White	DESC.	PART NO.	DESC.
See table on page 4-10	various	.290- .385	7,4- 9,8	.875 w/ .770 flats	22,2 w/ 19,6 flats	.032 .063 .099 .126 .157	0,8 1,6 2,5 3,2 4,0	<b>1857</b>	<b>1858</b>	RDD 201	2509	DD 875-770
Same as RDD 201 above except →						.078 .140	2,0 3,4	<b>1855</b>	<b>1856</b>	RDD 201-2*	2509	DD 875-770
See table on page 4-10	various	.340- .430	8,6- 10,9	.875 w/ .770 flats	22,2 w/ 19,6 flats	.032 .063 .099 .126 .157	0,8 1,6 2,5 3,2 4,0	<b>1861</b>	<b>1862</b>	RDD 301	2509	DD 875-770
Same as RDD 301 above except →						.078 .140	2,0 3,4	<b>1859</b>	<b>1860</b>	RDD 301-2*	2509	DD 875-770
See table on page 4-10	various	.420- .450	10,7- 11,4	.875 w/ .770 flats	22,2 w/ 19,6 flats	.032 .063 .099 .126 .157	0,8 1,6 2,5 3,2 4,0	<b>1865</b>	<b>1866</b>	RDD 401	2509	DD 875-770
Same as RDD 401 above except →						.078 .140	2,0 3,4	<b>1882</b>	<b>1883</b>	RDD 401-2*	2509	DD 875-770

Standard color black. Consult Heyco for white and other colors.

\*Designed for cast or other mounting holes with rounded edges.

- **Assembly friendly!** Independent of insertion into the panel, RDD Lockit™ Strain Reliefs **self-lock** onto the cable. Preassemble RDD Lockits off line for final assembly at a later time or remote location, for lower installed cost!
- Install easily with fingertip pressure into a standard round or Double D hole. No tools required, even for hand assembly.
- Protect the lifeline of your electric/electronic products by absorbing the forces of push and pull that may be exerted on the flexible power cord. Double D design eliminates the possibility of part rotation under forces of twist.
- Multiple panel locking steps secure Lockit Strain Reliefs into a wide range of panel thicknesses for a **flush, finished fit**.
- Heyco's automated Pre-Assembly Equipment speeds assembly of the RDD onto the cable and thus lowers costs while greatly reducing risk of carpal tunnel syndrome. See pages 4-15 & 4-16.
- Consult Heyco for other wire types and sizes.
- See page 4-38 for corresponding **Mounting Hole Plugs** which can be used to fill blank/unused Mounting Holes and thus allow for a single panel design for multiple applications.
- For Double D Mounting Hole Punches, see page 4-30.

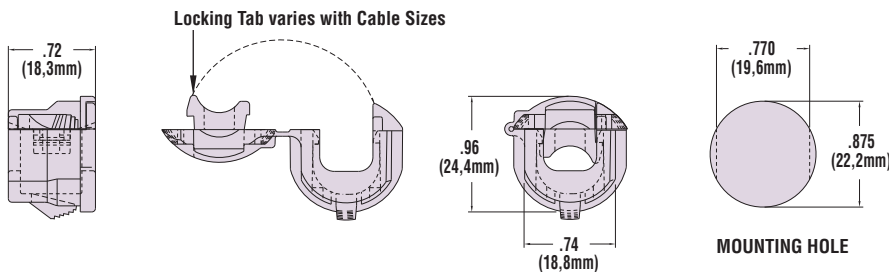

RDD 201, RDD 201-2, RDD 301, RDD 301-2, RDD 401, RDD 401-2

Material	Nylon 6/6
Certifications	Recognized under UL File E15331 Certified by the Canadian Standards Association File 8919
Flammability Rating	94V-2
Temperature Range	-04°F (-18°C) to 221°F (105°C)

*Quick  
Specs*

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Heyco:

[1855](#) [1856](#) [1857](#) [1858](#) [1859](#) [1860](#) [1861](#) [1862](#) [1865](#) [1866](#) [1882](#) [1883](#) [1857JK](#) [1866AB](#)