



- Ideal for securing, insulating, and routing cable and tubing.
- Cable and wire can be installed or removed for repair without removing clamp.
- Mounts with screws, mounting buttons or rivets.

Available in Small Packs

NEW

PART NO.	DESCRIPTION	QTY
4149-P	WHC 125 NATURAL 50PK	50
4150-P	WHC 250 NATURAL 50PK	
4151-P	WHC 375 NATURAL 50PK	
4152-P	WHC 500 NATURAL 50PK	
4153-P	WHC 625 NATURAL 50PK	
4154-P	WHC 750 NATURAL 50PK	
4210-P	WHC 1000 NATURAL 25PK	25
4211-P	WHC 1500 NATURAL 10PK	10



- Retainer clip allows clamp to be pre-positioned on hose before final installation.
- Double row of teeth for more secure grip.
- Quick and easy installation. Tighten instantly with hand pliers or Air Tool (on page 7-39).
- Reusable. Can be removed without cutting.
- Supertough nylon clamps offer additional clamping strength.
- Outlast tubing under pressure.
- Non-conductive and non-magnetic.
- No moving pieces to seize or vibrate loose.
- Maximum Pressure Rating: 200 PSI.


Heyco® Nylon Wire Harness Clamps

MOUNTING HOLE DIAMETER			SCREW SIZE	PART DIMENSIONS						PART NO.			DESCRIPTION	STYLE
		A Bundle Diameter		B Overall Length		C Width		Natural	Black	VO Natural				
in.	mm.		in.	mm.	in.	mm.	in.	mm.						
Snap Mouth *														
.157	4,0	#8	.50 .71	12,7 18,0	1.18 1.38	30,0 35,1	.39 .50	10,0 12,7	4127 4148	4127B 4148B	4127F 4148F	WHCX 500 WHCX 750	1	NEW!
Open Mouth														
.157	4,0	#8	.13	3,2	.77	19,5	.34	8,5	4149	4149B	4149F	WHC 125	2	NEW!
			.25	6,4	.83	21,0	.39	10,0	4126	4126B	4126F	WHCX 250	3†	
.205	5,2	#10	.25	6,4	.86	21,8	.41	10,4	4150	4150B	4150F	WHC 250	3	
			.38	9,0	.83	21,0	.40	10,2	4151	4151B	4151F	WHC 375		
			.50	12,5	1.16	29,4	.40	10,2	4152	4152B	4152F	WHC 500		
			.63	15,9	1.13	28,6	.50	12,7	4153	4153B	4153F	WHC 625		
			.75	19,1	1.28	32,5	.50	12,7	4154	4154B	4154F	WHC 750		
			.95	25,1	1.50	38,1	.50	12,7	4210	4210B	4210F	WHC 1000		
			1.50	38,1	2.12	53,9	.50	12,7	4211	4211B	4211F	WHC 1500		


Standard color natural.

*Bundle Diameter in closed position.


†No reinforcing ribs on Part No. 4126.

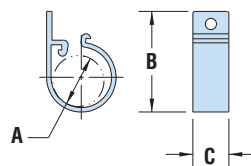

Style 1

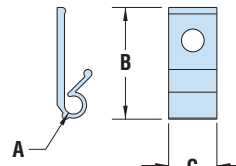

Style 2


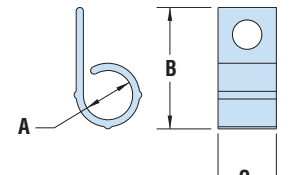


Style 3

Heyco® Nylon Lockit™ Hose Clamps

EFFECTIVE CLAMP RANGE				PART NO.	DESCRIPTION	PART DIMENSIONS			
Minimum Diameter		Maximum Diameter				A Clamp Thickness		B Strap Thickness	
in.	mm.	in.	mm.	Black		in.	mm.	in.	mm.
LHC Series									
.34	8,7	.41	10,3	2388	LHC 344	.25	6,4	.08	2,0
.53	13,5	.59	15,1	2391	LHC 531				
.67	17,0	.81	20,6	2393	LHC 672				

 Standard color black.

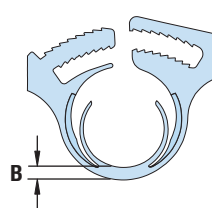

WHCX & WHC				LHC	
Material	Nylon 6/6	Nylon 6/6		Nylon 6/6 Supertough	
Flammability Rating	94V-2	94V-0		94HB	
Temperature Range	32°F (0°C) to 185°F (85°C)	-40°F (-040°C) to 185°F (85°C)		32°F (0°C) to 185°F (85°C)	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[4153-P](#) [4152-P](#) [4150-P](#) [4149-P](#) [4151-P](#) [4154-P](#) [4210-P](#) [4211-P](#)