


Heyco® RDD Lockit™ Strain Relief Bushings – Straight-Thru

Snap onto **Round Cables** for Faster Assembly into **Double D Mounting Holes** –
Semi-Automatic Equipment Available
Fit 3/4" Electrical Knock-out Hole

- **Assembly friendly!** Independent of insertion into the panel, RDD Lockit™ Strain Reliefs **self-lock** onto the cable. Preassemble RDD Lockits off line for final assembly at a later time or remote location, for lower installed cost!
- Install easily with fingertip pressure into a standard round or Double D hole. No tools required, even for hand assembly.
- Protect the lifeline of your electric/electronic products by absorbing the forces of push and pull that may be exerted on the flexible power cord. Double D design eliminates the possibility of part rotation under forces of twist.
- Multiple panel locking steps secure Lockit Strain Reliefs into a wide range of panel thicknesses for a **flush, finished fit**.
- Heyco's automated Pre-Assembly Equipment speeds assembly of the RDD onto the cable and thus lowers costs while greatly reducing risk of carpal tunnel syndrome. See pages 4-15 & 4-16.
- Consult Heyco for other wire types and sizes.
- See page 4-38 for corresponding **Mounting Hole Plugs** which can be used to fill blank/unused Mounting Holes and thus allow for a single panel design for multiple applications.
- For Double D Mounting Hole Punches, see page 4-30.

WILL FIT THESE CABLES			PANEL DIMENSIONS				RDD LOCKIT STRAIN RELIEF for Faster Assembly			Corresponding Mounting Hole Plug	
UL Type	AWG/Conductors	Approximate Size in. mm.	Mounting Hole Size in. mm.	Thickness in. mm.	Part No.	Desc.	Black	White	Desc.	Part No.	Desc.
See table on page 4-10	various	.525-.600	13.5-15.2	1.109 w/ 1.000 flats	28.2 w/ 25.4 flats	.063 .099 .126 .157 .187	1,6 2,5 3,2 4,0 4,8	1868	1869	RDD 501	2717 DD 1109-1000
See table on page 4-10	various	.600-.700	15.2-17,8	1.109 w/ 1.000 flats	28.2 w/ 25.4 flats	.063 .099 .126 .157 .187	1,6 2,5 3,2 4,0 4,8	1802	1803	RDD 601	
See table on page 4-10	various	.720-.830	18.3-21,1	1.250 w/ 1.125 flats	31.8 w/ 28,6 flats	.063 .099 .126 .157 .187	1,6 2,5 3,2 4,0 4,8	1880	1881	RDD 701	- consult Heyco

Standard color black. Consult Heyco for white and other colors.

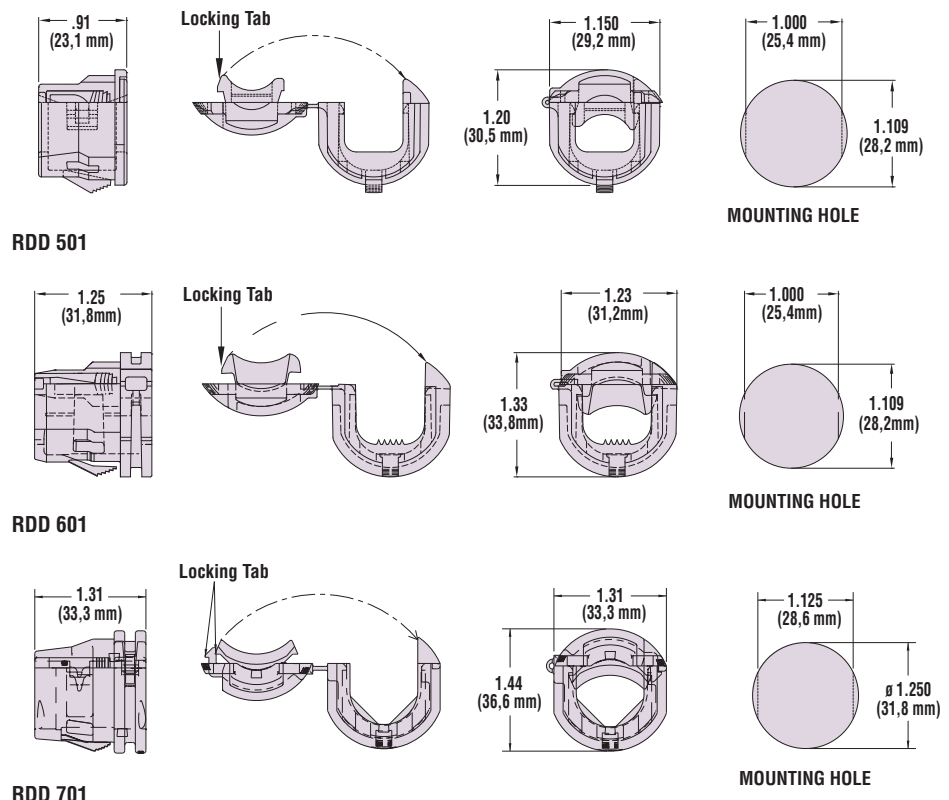

*Quick
Specs*

Material
Certifications

Flammability Rating
Temperature Range

Nylon 6/6

Recognized under UL File E15331

Certified by the Canadian Standards Association File 8919

94V-2

-04°F (-18°C) to 221°F (105°C)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[1868](#) [1869](#) [1802](#) [1803](#) [1880](#) [1881](#) [1868AA](#)