



**NO O-RING
REQUIRED!**



Heyco® -Tite Liquid Tight Cordgrips

Multi-Hole with Integral Sealing Ring

Sequenced by Conductor Size

The Ultimate in Liquid Tight Strain Relief Protection

- Heyco® **Multi-hole glands** provide the widest range of conductor through-hole size and number configurations, many of which are agency approved. See the tabular charts for specific approvals for specific parts. These approvals are not "global" or implied approvals; they are both real and part specific.
- Integral Sealing Ring ensures a superior seal at the clearance or threaded mounting hole location, every time.
- IP 68 rated.
- Cordgrips are made of nylon construction with TPE sealing glands that resist salt water, weak acids, gasoline, alcohol, oil, grease, and common solvents.
- For body part dimensions see page 3-1, 3-3, and 3-4.
- Multi-hole glands are only to be used with Heyco Liquid Tight Cordgrips and are not sold separately.
- Consult Heyco for Cordgrips molded in other colors.


CONDUCTORS		 or 	NPT HUB*		PG HUB**		METRIC HUB**	
Hole Size mm.	No.		specifications on page 3-1		specifications on page 3-3		specifications on page 3-4	
			Black Part No.	Desc.	Black Part No.	Desc.	Black Part No.	Desc.
Round, Open Holes – consult Heyco for Snap-in-2 Hub versions								
1,4	4		M3228GAP	LTCG 3/8	M3210GAP	LTCG 9	M4336GAP	LTCG M16
	6		M3228GAZ	LTCG 3/8	M3210GAZ	LTCG 9	M4336GAZ	LTCG M16
	10		M3228GE	LTCG 3/8	M3210GE	LTCG 9	M4336GE	LTCG M16
1,5	2		M4516GBA	LTCG 1/4	M3207GBA	LTCG 7	M4332GBA	LTCG M12
	3		—	—	M3213GF	LTCG 11	—	—
1,6	5		M3228GG	LTCG 3/8	M3210GG	LTCG 9	M4336GG	LTCG M16
1,7	2		M3228GH	LTCG 3/8	M3210GH	LTCG 9	M4336GH	LTCG M16
	3		M3228GJ	LTCG 3/8	M3210GJ	LTCG 9	M4336GJ	LTCG M16
	4		M3228GK	LTCG 3/8	M3210GK	LTCG 9	M4336GK	LTCG M16
2,0	3		M3231GL	LTCG 1/2	M3216GL	LTCG 13	M4340GL	LTCG M20
2,3	4		M3228GM	LTCG 3/8	M3210GM	LTCG 9	M4336GM	LTCG M16
2,5	2		M3231GN	LTCG 1/2	M3216GN	LTCG 13	M4340GN	LTCG M20
2,8	4		—	—	M3213GAY	LTCG 11	—	—
3,0	2		M3228GP	LTCG 3/8	M3210GP	LTCG 9	M4336GP	LTCG M16
			—	—	M3213GB	LTCG 11***	—	—
			—	—	M3213GP	LTCG 11	—	—
	3		—	—	M3213GQ	LTCG 11	—	—
			M3231GQ	LTCG 1/2	M3216GQ	LTCG 13	M4340GQ	LTCG M20
			M3200GQ	LTCG LL 1/2	M3219GQ	LTCG 16	—	—
	4		M3200GR	LTCG LL 1/2	M3219GR	LTCG 16	—	—
		6		M3231GS	LTCG 1/2	M3216GS	LTCG 13	M4340GS
		M3200GS	LTCG LL 1/2	M3219GS	LTCG 16	—	—	
3,8	2		M3231GT	LTCG 1/2	M3216GT	LTCG 13	M4340GT	LTCG M20
	6		M3200GW	LTCG LL 1/2	M3219GW	LTCG 16	—	—
4,0	2		—	—	M3213GAK	LTCG 11	—	—
	3		M3231GX	LTCG 1/2	M3216GX	LTCG 13	M4340GX	LTCG M20
			M3200GX	LTCG LL 1/2	M3219GX	LTCG 16	—	—
	4		M3200GY	LTCG LL 1/2	M3219GY	LTCG 16	—	—
	5		M3200GZ	LTCG LL 1/2	M3219GZ	LTCG 16	—	—
6		M3200GBB	LTCG LL 1/2	M3219GBB	LTCG 16	—	—	

Standard color black.

*Locknuts not included. For Locknut specifications or to order Locknuts separately, see pages 3-47 & 3-48.

**Unassembled Nylon Locknuts INCLUDED.

***Short Thread

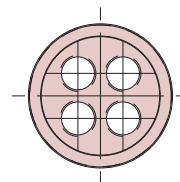

Multi-hole Gland (typical)

*Quick
Specs*

Material	Nylon 6/6 with TPE Sealing Gland
Flammability Rating	94V-2 Standard
Temperature Range	Static -40°F (-40°C) to 239°F (115°C) Dynamic -4°F (-20°C) to 212°F (100°C)
IP Rating	IP 68

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Heyco:

[M3200GBB](#) [M3200GQ](#) [M3200GR](#) [M3200GS](#) [M3200GW](#) [M3200GX](#) [M3200GY](#) [M3200GZ](#) [M3216GX](#) [M3228GAP](#)
[M3228GAZ](#) [M3228GE](#) [M3228GG](#) [M3228GH](#) [M3228GJ](#) [M3228GK](#) [M3228GM](#) [M3228GP](#) [M3231GAB](#) [M3231GAC](#)
[M3231GL](#) [M3231GN](#) [M3231GQ](#) [M3231GS](#) [M3231GT](#) [M3231GX](#) [M3231GZA](#) [M3231GZB](#) [M4344GAD](#) [M3210GH](#)
[M3213GP](#) [M4332GBA](#) [M3207GBA](#) [M4336GP](#) [M4336GH](#) [M4336GK](#) [M4336GAP](#) [M4336GG](#) [M4336GAZ](#)
[M4336GJ](#) [M4336GE](#) [M4336GM](#) [M3210GG](#) [M3210GAP](#) [M3210GJ](#) [M3210GP](#) [M3210GM](#) [M3210GE](#) [M3210GK](#)
[M3210GAZ](#) [M3213GAK](#) [M4516GBA](#) [M3213GQ](#) [M3216GQ](#) [M3213GAY](#) [M3216GS](#) [M4340GX](#) [M4340GS](#) [M3213GB](#)
[M3216GAC](#) [M4344GAQ](#) [M4348GAX](#) [M4352GAR](#) [M4340GAE](#) [M3219GAH](#) [M3216GAE](#) [M4340GN](#) [M3213GF](#)
[M3216GL](#) [M4340GL](#) [M3216GT](#) [M4340GT](#) [M4340GQ](#) [M3216GN](#) [M3216GAB](#) [M4344GAG](#) [M4348GAS](#) [M4340GAC](#)
[M4344GAF](#) [M4344GAM](#) [M4352GAW](#) [M4344GBC](#) [M4352GAT](#) [M4352GAL](#) [M4348GAL](#) [M4344GAN](#) [M4340GAB](#)