


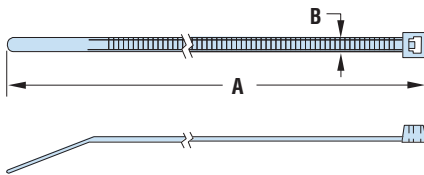

- Smooth, radiused edges ensure that Nytyes won't cut into the cable's insulation—or the installer's hand.
- One-piece design reduces cost and installation time.
- Nytyes feature a bent tip for ease of pickup and insertion around small bundles. V-shaped raised ridges on the tip provide a sure grip.
- Nylon 12 cable ties are weather/UV resistant and suitable for high moisture, corrosive and low temperature indoor or outdoor applications.
- Close, evenly spaced teeth permit fine adjustment—from .025" (0,6 mm) on the smallest Nytyes to .063" (1,6 mm) on the largest.
- Standard UV Black Nytyes are available in 100 packs; add -P to Part No.; eg. 13140B-P
- Compliant with MS3367 and MIL-S-23190E



Heyco® Cable Tie Tensioning Tool



Part No. 0998 (for Nylon) and **0996** (for Stainless Steel) fits all standard duty Nytyes. Metal construction, has three tension settings, and automatically trims excess.

Heyco® Nytye® Nylon Cable Ties

PART SPECIFICATIONS				PART NO.		DESCRIPTION	PART DIMENSIONS			
Tensile Strength		Max. Bundle Diameter		Natural	UV Black		A Length		B Width	
Lbs.	N	in.	mm.				in.	mm.	in.	mm.
Miniature										
18	80	.63	16,0	13100	13100B	NT-18-031	3.15	80	.10	2,5
		.87	22,0	13102	13102B	NT-18-039	3.94	100		
		1.18	30,0	13105	13105B	NT-18-047	4.72	120		
		1.38	35,0	13107	13107B	NT-18-059	5.91	150		
		1.57	40,0	13108	13108B	NT-18-063	6.30	180		
		2.36	60,0	13111	13111B	NT-18-078	7.87	200		
Intermediate										
40	178	.87	22,0	13120	13120B	NT-40-039	3.94	100	.14	3,6
		1.18	30,0	13121	13121B	NT-40-047	4.72	120		
		1.30	33,0	13122	13122B	NT-40-055	5.51	140		
		1.38	35,0	13123	13123B	NT-40-059	5.91	150		
		1.65	42,0	13124	13124B	NT-40-070	7.09	180		
		1.97	50,0	13126	13126B	NT-40-078	7.87	200		
		2.56	65,0	13128	13128B	NT-40-099	9.92	252		
		3.15	80,0	13129	13129B	NT-40-110	11.02	280		
		3.35	85,0	13130	13130B	NT-40-118	11.81	300		
		4.02	102,0	13134	13134B	NT-40-145	14.57	370		
Standard										
50	222	.94	24,0	13140	13140B	NT-50-047	4.72	120	.19	4,8
		1.57	40,0	13142	13142B	NT-50-063	6.30	160		
		1.65	42,0	13143	13143B	NT-50-072	7.20	183		
		1.97	50,0	13145	13145B	NT-50-078	7.87	200		
		2.56	65,0	13147	13147B	NT-50-098	9.84	250		
		2.76	70,0	13149	13149B	NT-50-110	11.02	280		
		3.23	82,0	13151	13151B	NT-50-118	11.81	300		
		3.54	90,0	13153	13153B	NT-50-137	13.78	350		
		4.02	102,0	13155	13155B	NT-50-145	14.57	370		
		4.13	105,0	13156	13156B	NT-50-157	15.75	400		
		5.12	130,0	13158	13158B	NT-50-177	17.72	450		
		5.91	150,0	13160	13160B	NT-50-196	19.68	500		

Standard colors natural and UV Black. Consult Heyco for heat-stabilized material and colors. Standard UV Black Nytyes available in 100 packs; add -P to Part No.; eg. 13140B-P

Heyco® Nytye® Nylon 12 Cable Ties



PART SPECIFICATIONS				PART NO.		DESCRIPTION	PART DIMENSIONS			
Tensile Strength		Max. Bundle Diameter		UV Black Bulk	UV Black 100 Packs		A Length		B Width	
Lbs.	N	in.	mm.				in.	mm.	in.	mm.
40	178	1.44	36,6	13340B	13340B-P	NT-40-058-12	5.84	148,3	.14	3,6
50	222	1.87	47,5	13342B	13342B-P	NT-50-076-12	7.56	192,0		
		3.06	77,7	13343B	13343B-P	NT-50-112-12	11.25	285,7	.18	4,6
		4.00	101,6	13344B	13344B-P	NT-50-145-12	14.50	368,3		
100	444	2.06	52,3	13346B	13346B-P	NT-100-087-12	8.70	220,1	.30	7,6

Standard color UV Black.

Material
Certifications



Nylon 6/6 or Nylon 12

Certified by UL for Compliance with both Canadian and U.S. requirements under File E54523 (Nylon 6/6 only)

Flammability Rating
Temperature Range

94V-2

-40°F (-40°C) to 185°F (85°C) (Nylon 6/6)
-58°F (-50°C) to 302°F (150°C) (Nylon 12)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Heyco:

[13346B-P](#) [13346B](#) [13343B](#) [13345B-P](#) [13343B-P](#) [13345B](#) [13340B](#) [13342B](#) [13344B-P](#) [13342B-P](#) [13344B](#)
[13340B-P](#) [13145B-P](#) [13147B-P](#) [13155-P](#) [13153-P](#) [13143-P](#) [13145-P](#) [13143B-P](#) [13142B-P](#) [13155B-P](#) [13151B-P](#)
[13149B-P](#) [13151-P](#) [13147-P](#) [13153B-P](#) [13149-P](#) [13160B-P](#) [13145F](#) [13160-P](#) [13158-P](#) [13156-P](#) [13158B-P](#)
[13156B-P](#)