




Heyco® "Standard Plus" Nylon Washers and Spacers

		PART NOS.								
Outside Dia. ➤		.187" (4,7 mm)		.250" (6,4 mm)				.312" (7,9 mm)		
Inside Dia. D ➤		.091" (2,3 mm)	.115" (2,9 mm)	.091" (2,3 mm)	.115" (2,9 mm)	.140" (3,6 mm)	.171" (4,3 mm)	.115" (2,9 mm)	.140" (3,6 mm)	.171" (4,3 mm)
A		#2	#4	#2	#4	#6	#8	#4	#6	#8
in.	mm.									
.032	0,8			RS-2509-0032	RS-2511-0032				RS-3114-0032	
.063	1,6	RS-1809-0063	RS-1811-0063	RS-2509-0063	RS-2511-0063	RS-2514-0063			RS-3114-0063	
.093	2,4			RS-2509-0093	RS-2511-0093				RS-3114-0093	
.125	3,2	RS-1809-0125	RS-1811-0125	RS-2509-0125	RS-2511-0125	RS-2514-0125	RS-2517-0125	RS-3111-0125	RS-3114-0125	RS-3117-0125
.156	4,0		RS-1811-0156*		RS-2511-0155*		RS-2517-0156*			
.187	4,7	RS-1809-0187	RS-1811-0187	RS-2509-0187	RS-2511-0187	RS-2514-0187	RS-2517-0187	RS-3111-0187	RS-3114-0187	RS-3117-0187
.250	6,4	RS-1809-0250	RS-1811-0250	RS-2509-0250	RS-2511-0250	RS-2514-0250	RS-2517-0250	RS-3111-0250	RS-3114-0250	RS-3117-0250
.312	7,9	RS-1809-0312	RS-1811-0312	RS-2509-0312	RS-2511-0312	RS-2514-0312	RS-2517-0312	RS-3111-0312	RS-3114-0312	RS-3117-0312
.375	9,5	RS-1809-0375	RS-1811-0375	RS-2509-0375	RS-2511-0375	RS-2514-0375	RS-2517-0375	RS-3111-0375	RS-3114-0375	RS-3117-0375
.405	10,3			RS-2509-0405*	RS-2511-0405*	RS-2514-0405*	RS-2517-0405*			
.437	11,1	RS-1809-0437	RS-1811-0437	RS-2509-0437	RS-2511-0437	RS-2514-0437	RS-2517-0437	RS-3111-0437	RS-3114-0437	RS-3117-0437
.500	12,7	RS-1809-0500	RS-1811-0500	RS-2509-0500	RS-2511-0500	RS-2514-0500	RS-2517-0500	RS-3111-0500	RS-3114-0500	RS-3117-0500
.562	14,3	RS-1809-0562	RS-1811-0562	RS-2509-0562	RS-2511-0562	RS-2514-0562	RS-2517-0562	RS-3111-0562	RS-3114-0562	RS-3117-0562
.625	15,9	RS-1809-0625	RS-1811-0625	RS-2509-0625	RS-2511-0625	RS-2514-0625	RS-2517-0625	RS-3111-0625	RS-3114-0625	RS-3117-0625
.687	17,4	RS-1809-0687	RS-1811-0687	RS-2509-0687	RS-2511-0687	RS-2514-0687	RS-2517-0687	RS-3111-0687	RS-3114-0687	RS-3117-0687
.750	19,1	RS-1809-0750	RS-1811-0750	RS-2509-0750	RS-2511-0750	RS-2514-0750	RS-2517-0750	RS-3111-0750	RS-3114-0750	RS-3117-0750
.812	20,6	RS-1809-0812	RS-1811-0812	RS-2509-0812	RS-2511-0812	RS-2514-0812	RS-2517-0812	RS-3111-0812	RS-3114-0812	RS-3117-0812
.875	22,2	RS-1809-0875	RS-1811-0875	RS-2509-0875	RS-2511-0875	RS-2514-0875	RS-2517-0875	RS-3111-0875	RS-3114-0875	RS-3117-0875
.937	23,8	RS-1809-0937	RS-1811-0937	RS-2509-0937	RS-2511-0937	RS-2514-0937	RS-2517-0937	RS-3111-0937	RS-3114-0937	RS-3117-0937
1.000	25,4	RS-1809-1000	RS-1811-1000	RS-2509-1000	RS-2511-1000	RS-2514-1000	RS-2517-1000	RS-3111-1000	RS-3114-1000	RS-3117-1000

Standard color natural

* "Plus" Length

- Ideal for use in electrical and electronic assemblies.
- Tough and resilient.
- Can also be used as bushings, bearings, rollers, and glides.
- Special sizes and lengths available. Consult Heyco.
- Tolerances: O.D. ± 0.015 , I.D. ± 0.005 , Length ± 0.015
- Part number key: RS-XXYY-ZZZZ, where XX = first two digits of the OD, YY = first two digits of the ID, and ZZZZ = length x 1000 (up to 9.999")

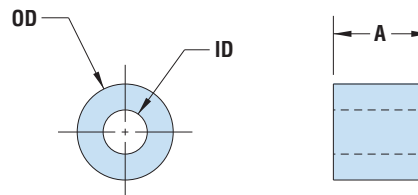

Quick Specs

Material: Nylon 6/6
 Flammability Rating: 94V-2
 Temperature Range: -40°F (-40°C) to 149°F (65°C)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Heyco:

[RS-3114-0687](#) [RS-2511-0625](#) [RS-2514-1000](#) [RS-2514-0437](#) [RS-2514-0160](#) [RS-3114-0500](#) [RS-2511-0562](#) [RS-2511-0530](#) [RS-3114-0750](#) [RS-2509-0562](#) [RS-1811-0625](#) [RS-3111-0687](#) [RS-2511-0155](#) [RS-2509-0500](#) [RS-3111-0875](#) [RS-2514-0562](#) [RS-3117-0812](#) [RS-1809-0625](#) [RS-3114-0562](#) [RS-2511-0750](#) [RS-1811-0225](#) [RS-2514-0937](#) [RS-2509-0375](#) [RS-3117-0937](#) [RS-2511-0687](#) [RS-1811-0812](#) [RS-2509-0937](#) [RS-3111-0812](#) [RS-1809-0687](#) [RS-1811-0562](#) [RS-3117-0625](#) [RS-2517-0312](#) [RS-3111-0500](#) [RS-1811-0375](#) [RS-1809-0500](#) [RS-2517-0687](#) [RS-1811-0750](#) [RS-2517-0405](#) [RS-2517-0437](#) [RS-3111-0312](#) [RS-2514-0375](#) [RS-3114-0937](#) [RS-3111-0625](#) [RS-2517-0625](#) [RS-2517-1000](#) [RS-2517-0176](#) [RS-2517-0125](#) [RS-2514-0063](#) [RS-2517-0187](#) [RS-3117-0250](#) [RS-2509-0063](#) [RS-1809-0125](#) [RS-1809-0375](#) [RS-1809-0812](#) [RS-2514-0405](#) [RS-3111-0125](#) [RS-3114-0437](#) [RS-2511-0187](#) [RS-3117-1000](#) [RS-3111-0750](#) [RS-2511-0437](#) [RS-2517-0650](#) [RS-3114-0093](#) [RS-3117-0437](#) [RS-2509-0187](#) [RS-1811-0250](#) [RS-3114-0250](#) [RS-3117-0187](#) [RS-2509-0812](#) [RS-3114-0625](#) [RS-1811-0937](#) [RS-2514-0125](#) [RS-2517-0375](#) [RS-2517-1250](#) [RS-2509-1000](#) [RS-2514-0875](#) [RS-1809-0187](#) [RS-2517-0875](#) [RS-2511-0875](#) [RS-2509-0687](#) [RS-2509-0032](#) [RS-2509-0125](#) [RS-2511-0032](#) [RS-3114-0812](#) [RS-2517-0562](#) [RS-2517-0500](#) [RS-2509-0875](#) [RS-3114-0125](#) [RS-3117-0375](#) [RS-2511-0063](#) [RS-1811-0187](#) [RS-3117-0500](#) [RS-2514-0687](#) [RS-3111-0937](#) [RS-1809-0250](#) [RS-2511-1000](#) [RS-2511-0312](#) [RS-3111-0250](#) [RS-2517-1500](#) [RS-2514-0150](#)