 




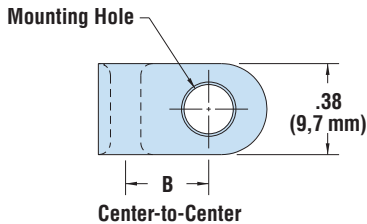

- For clamping cable or tubing securely into place.
- Resist corrosion, salt water, weak acids, gasoline, alcohol, oil, grease, and common solvents.
- All parts are size marked in inches and millimeters.
- Standard material Nylon 6/6. 94V-0 available, consult Heyco.
- For Snap Rivets compatible with Heyco Cable Clamps, see the table on page 7-37.

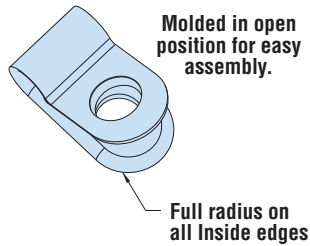

Heyco® Nylon Cable Clamps

MOUNTING HOLE DIAMETER		SCREW SIZE	PART DIMENSION A		PART NO. V-2*		DESCRIPTION	CENTER-TO-CENTER DIMENSION B		
in.	mm.		in.	mm.	Black	Natural		in.	mm.	
Light Duty - 3/8" (9,5 mm) wide, .05" (1,3 mm) thick										
.170	4,3	8	.125	3,2	3362	3312	CCL 125-170	.36	9,1	
			.187	4,7	3363	3313	CCL 187-170	.39	9,9	
			.250	6,3	3364	3314	CCL 250-170	.42	10,7	
			.312	7,9	3365	3315	CCL 312-170	.46	11,7	
			.375	9,5	3366	3316	CCL 375-170	.49	12,4	
			.437	11,1	3367	3317	CCL 437-170	.53	13,5	
			.500	12,7	3368	3318	CCL 500-170	.55	14,0	
.203	5,2	10	.125	3,2	3352	3302	CCL 1/8	.34	8,6	
			.187	4,7	3353	3303	CCL 3/16	.38	9,7	
			.250	6,3	3354	3304	CCL 1/4	.41	10,4	
			.312	7,9	3355	3305	CCL 5/16	.44	11,2	
			.375	9,5	3356	3306	CCL 3/8	.48	12,2	
			.437	11,1	3357	3307	CCL 7/16	.51	13,0	
			.500	12,7	3358	3308	CCL 1/2	.53	13,5	
Heavy Duty - 1/2" (12,7 mm) wide, .06" (1,5 mm) thick										
.203	5,2	10	.125	3,2	3372	3322	CCH 1/8	.37	9,4	
			.187	4,8	3373	3323	CCH 3/16	.41	10,4	
			.250	6,3	3374	3324	CCH 1/4	.44	11,2	
			.312	7,9	3375	3325	CCH 5/16	.48	12,2	
			.375	9,5	3376	3326	CCH 3/8	.51	13,0	
			.437	11,1	3377	3327	CCH 7/16	.54	13,7	
			.500	12,7	3378	3328	CCH 1/2	.58	14,7	
			.562	14,3	3379	3329	CCH 9/16	.61	15,5	
			.625	15,9	3380	3330	CCH 5/8	.65	16,5	
			.687	17,4	3381	3331	CCH 11/16	.68	17,3	
			.750	19,1	3382	3332	CCH 3/4	.71	18,0	
			.812	20,6	3383	3333	CCH 13/16	.75	19,1	
			.875	22,2	3384	3334	CCH 7/8	.78	19,8	
			1.000	25,4	3390	3340	CCH 1	.85	21,6	
			1.125	28,6	3392	3342	CCH 1-1/8	.92	23,4	
			1.187	30,1	3393	3343	CCH 1-3/16	.95	24,1	
			1.250	31,8	3394	3344	CCH 1-1/4	.99	25,1	
			1.375	34,9	3396	3346	CCH 1-3/8	1.05	26,7	
			1.500	38,1	3398	3348	CCH 1-1/2	1.12	28,4	
Adjustable - 1/2" (12,7 mm) wide, .065" (1,7 mm) thick										
NEW!	.203	5,2	10	1.75 - 2.00	44,5 - 50,8	-	3755	ACC 1750-2000		

Standard colors black and natural.

*Consult Heyco for V-O parts (not shown)

Quick
Specs

Material	Nylon 6/6
Flammability Rating	94V-2
Temperature Range	32°F (0°C) to 221°F (105°C) - Black 32°F (0°C) to 185°F (85°C) - Natural

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[3330](#) [3332](#) [3340](#) [3380](#) [3328](#) [3324](#) [3325](#) [3327](#) [3346](#) [3393](#) [3326](#) [3303](#) [3373](#) [3378](#) [3352](#) [3302](#) [3354](#) [3308](#)
[3316](#) [3355](#) [3334](#) [3314](#) [3375](#) [3356](#) [3379](#) [3382](#) [3342](#) [3313](#) [3317](#) [3376](#) [3362](#) [3374](#) [3306](#) [3353](#) [3364](#) [3305](#)
[3304](#) [3363](#) [3372](#) [3377](#) [3398](#) [3381](#) [3365](#) [3367](#) [3312](#) [3331](#) [3304F](#)