

## Heyco® Nytye® Mounting Platforms


### Snap Over Bolt Platforms

- Multiple sizes, strengths, and mounting options anchor Nytyes® securely.
- Five Types:
  - 1) Flat - Adhesive-Back and Screw Mounts
  - 2) Saddle - Screw Mount only
  - 3) Push Mount - Arrowhead and Blind Mounts
  - 4) Snap Over Bolt
  - 5) Stainless Steel Clip
- Rubber based adhesive effective up to 126°F (52°C).
- Apply Adhesive-Backed parts to a clean, dry surface.


	MAX. TENSILE STRENGTH		INSERT POINTS	BOLT SIZE		PART NO.	DESCRIPTION	PART DIMENSIONS					
	Lbs.	N		in.	mm.			Black	A		B		C
								in.	mm.	in.	mm.	in.	mm.
NEW!	50	222	2	#10	5,0	3706	MP S-M5*	.96	24,4	.60	15,2	.32	8,1
NEW!				1/4	6,0	3707	MP S-M6						
	120	534	2	1/2	12,0	3710	MP S-1/2	2.31	58,7	1.25	31,8	1.05	26,7
				9/16	14,0	3711	MP S-9/16						
				5/8	16,0	3754	MP S-5/8						

Standard color black.



\*3706 will also work with the PEM X-Press 5 mm stud

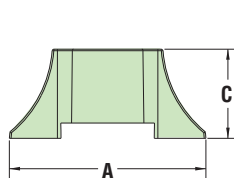

3710-3754

 

3706-3707

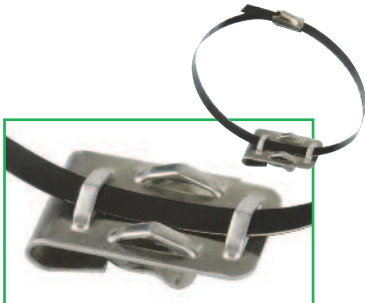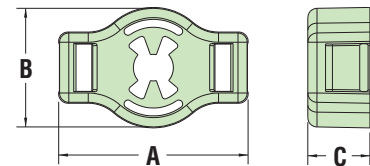


### Stainless Steel Edge Clip Platforms


ALL NEW PRODUCTS

MAX. CABLE TIE WIDTH* in. mm.	PANEL THICKNESS RANGE				INSERT POINTS	PART NO.	DESCRIPTION	PART DIMENSIONS					
	Minimum in. mm.	Maximum in. mm.	Minimum in. mm.	Maximum in. mm.				A		B		C	
.31 8,0	.06 1,5	.12 3,0	.12 3,0	.25 6,4	4	S6474	SunRunner CT	1.03	26,2	.63	16,0	.77	19,5
	.12 3,0	.25 6,4			4	S6475	SunRunner CT-EZ						

\*Edge Clip Platforms SunRunner CT and CT-EZ fit all Heyco Stainless Steel Cable Ties, see page 7-69

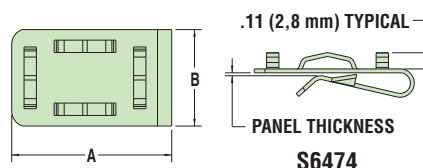

S6474

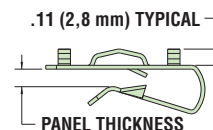

S6475

Quick  
Specs

Material	Nylon 6/6 (Snap Over Bolts) .025" Thick 304 stainless steel (CT & CT-EZ)
Certifications	UL Certified by UL for Compliance with both Canadian and US Requirements under File E54523 (CT & CT-EZ)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[3707](#) [3706](#)