



Heyco® Nytye® Mounting Platforms

Flat Platforms – Adhesive Back Mount

- Multiple sizes, strengths, and mounting options anchor Nytyes® securely.
- Five Types:
 - 1) Flat - Adhesive-Back and Screw Mounts
 - 2) Saddle - Screw Mount only
 - 3) Push Mount - Arrowhead and Blind Mounts
 - 4) Snap Over Bolt
 - 5) Stainless Steel Edge Clip "SunRunner Series"
- Rubber based adhesive effective up to 158°F (70°C).
- Acrylic based adhesive effective up to 167°F (75°C).
- Apply Adhesive-Backed parts to a clean, dry surface.
- Parts are not intended for direct exposure to harsh environments (extreme heat/sunlight, humidity, etc.) and better suited for use inside an enclosure in these types of environments.

MAX. TENSILE STRENGTH	Lbs.	N	ADHESIVE	INSERT POINTS	RELEASE TAB?	PART NO.	DESCRIPTION	PART DIMENSIONS					
								A		B		C	
						Natural		in.	mm.	in.	mm.	in.	mm.
NEW!	3	13	Rubber Acrylic	4	yes	3591	MP-050x050-ABR	.50	12,7	.50	12,7	.17	4,3
						3591A	MP-050x050-ABA						
NEW!	15	67	Rubber Acrylic	4	yes	3595	MP-075x075-ABR	.75	19,1	.75	19,1	.28	7,0
						3595A	MP-075x075-ABA						
NEW!	20	89	Rubber Acrylic	4	yes	3594	MP-080x080-ABR	.80	20,3	.80	20,3	.19	4,8
						3594A	MP-080x080-ABA						
NEW!	20	89	Rubber Acrylic	4	yes	3599	MP-100x100-ABR	1.00	25,4	1.00	25,4	.32	8,1
						3599A	MP-100x100-ABA						
	50	222	Rubber	2	yes	3590*	MP-110x110-ABR	1.10	27,9	1.10	27,9	.24	6,0
						3593*	MP-115x115-ABR	1.15	29,2	1.15	29,2	.26	6,6

Standard color natural.

*These adhesive-backed parts are also screw mountable.

Flat Platforms – Screw Mount

MAX. TENSILE STRENGTH	Lbs.	N	SCREW SIZE		INSERT POINTS	PART NO.	DESCRIPTION	PART DIMENSIONS					
			in.	mm.				A		B		C	
						Natural		in.	mm.	in.	mm.	in.	mm.
	24	105	#6	3,5	4	4264	MP-075x075-S6	.75	19,1	.75	19,1	.24	6,0
	50	222			4	4265	MP-038x075-S8	.75	19,1	.38	9,5	.20	5,0
	38	170	#8	4,0		3589	MP-100x100-S8	1.00	25,4	1.00	25,4	.28	7,1
NEW!	15	68			2	3580	MP-110x110-S8	1.10	27,9	1.10	27,9	.20	5,1
						3581	MP-115x115-S6	1.15	29,2	1.15	29,2	.22	5,6


Standard color natural.

Saddle Platforms – Screw Mount


MAX. TENSILE STRENGTH	Lbs.	N	SCREW SIZE		INSERT POINTS	PART NO.	DESCRIPTION	PART DIMENSIONS					
			in.	mm.				A		B		C	
						Natural		in.	mm.	in.	mm.	in.	mm.
	18	80	#4	3,0	2	4269	MP S-4	.51	13,0	.33	8,3	.24	6,1
	50	222	#8	4,0	2	3759	MP S-8	.60	15,2	.38	9,7	.28	7,0
	120	534	#10	5,0	2	3753	MP S-10	.87	22,2	.62	15,7	.39	9,9

Standard color natural.


Tensile	Width	
	in.	mm.
18	.10	2,5
40	.14	3,6
50	.19	4,8
120	.30	7,6

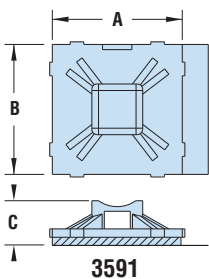


3591

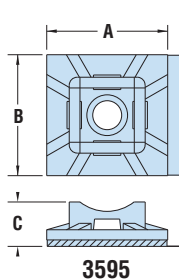


3595

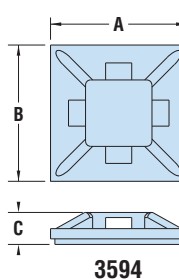


3594

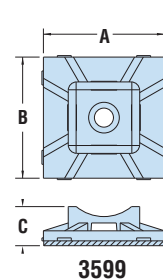


3599

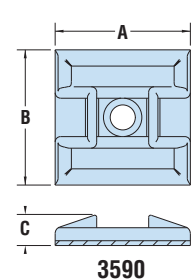


3590

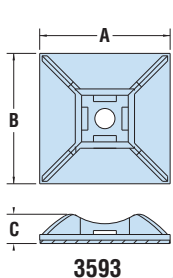


3593

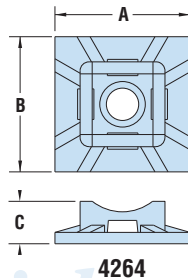


4264

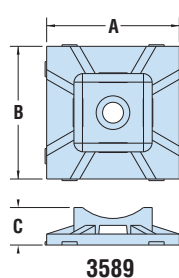

3589

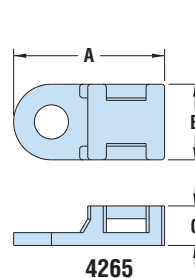

4265

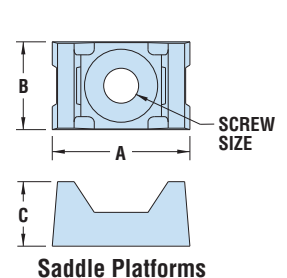

Saddle Platforms

Quick Specs

Material
Certifications



Nylon 6/6

Recognized under the Component Program of Underwriters' Laboratories
File E54523 (Adhesive-Back Mount parts only)

Flammability Rating
Temperature Range

94V-2

-32°F (0°C) to 158°F (70°C)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[3590](#) [3594](#) [3753](#) [3593](#) [3759](#) [4269](#) [4265](#) [4264](#) [3591](#) [3754](#) [3595](#) [3599](#) [3589](#) [3595A](#) [3599A](#) [3581](#) [3580](#)
[3594A](#) [3591A](#) [3593A](#) [3590A](#)