


Heyco® Shorty Window "View Port" Plugs

Single Locking Step for Panel Thickness up to .062" (1,6 mm)

Mounting Hole Diameter Range: .510" (13,0 mm) to 1.010" (25,7 mm)

MOUNTING HOLE DIAMETER		PART NO.	DESCRIPTION	PART DIMENSIONS			
in.	mm.			A Head Diameter		B Overall Height	
		Clear*		in.	mm.	in.	mm.
.510	13,0	1292	SWP 510	.56	14,3	.25	6,4
.635	16,1	1293	SWP 635	.73	18,6		
.760	19,3	1294	SWP 760	.86	21,8		
.885	22,5	1295	SWP 885	.95	24,2		
1.010	25,7	1296	SWP 1010	1.13	28,6		
		1295AA	SWP 885 Infrared*				

*Consult Heyco for Shorty Window Plugs in tinted colors.

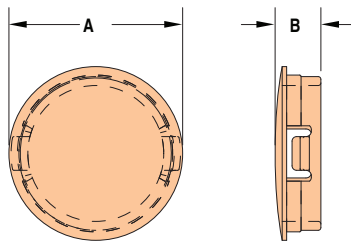


- Lock firmly into panels up to .062" (1,6 mm) thick, with **limited intrusion** inside the panel.
- Molded of transparent polycarbonate for internal viewing or light transmission.
- Snap into mounting holes with fingertip pressure—no tools required.
- Locking fingers in fractional increments up to the maximum panel thickness.
- Multiple sizes for use in .510" (13,0 mm) to 1.010" (25,7 mm) diameter holes.
- Flammability Rating 94V-2.
- **Available in a variety of tints—consult Heyco.**

Heyco® Oval Window "View Port" Plug

Multiple Locking Steps for Panel Thickness up to .125" (3,2 mm)

MOUNTING HOLE DIAMETER		PART NO.	DESCRIPTION	PART DIMENSIONS			
in.	mm.			Head Diameter		Overall Height	
		Clear*		in.	mm.	in.	mm.
see schematic		1299	OWP 875-2000	2.13 - 1.01	54,4 - 26,6	.46	11,7

*Consult Heyco for Oval Window Plugs in tinted colors.

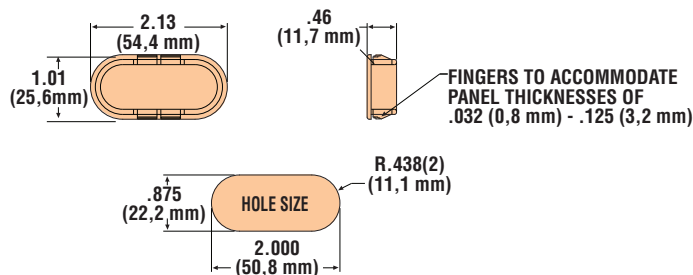

- **Large viewing window** for internal components.
- Locking fingers in fractional increments up to the maximum panel thickness.

Consult Heyco
for Window Tints
Other Than Clear

Material: Polycarbonate
Flammability Rating: 94V-2
Temperature Range: -40°F (-40°C) to 239°F (115°C)

*Quick
Specs*

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[1299JF](#)