



Heyco® Nylon PCB Supports - Adhesive-Back Mount

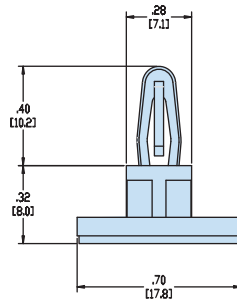

BAYONET SNAP LOCK 10,2 /
ADHESIVE-BACK BASE 17,8 sq

HCBS-Metric

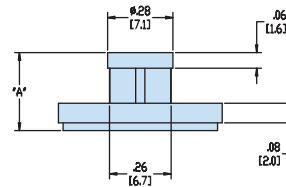

FLAT TOP REST MOUNT /
ADHESIVE-BACK BASE 17,8 sq

HPSB

	Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter	
	in.	mm.	in.	mm.	in.	mm.	in.	mm.
PCB	.062	1,6	.157	4,0	flat top rest mount			
Chassis	adhesive-back mount				adhesive-back mount			
A mm.	PART NO. Natural		DESCRIPTION		PART NO. Natural V-0		DESCRIPTION	
6,0	10771		HCBS-06M-AB		10810F		HPSB-06M-AB	
8,0	10781		HCBS-08M-AB		10811F		HPSB-08M-AB	
10,0	10782		HCBS-10M-AB		10812F		HPSB-10M-AB	
12,0	10783		HCBS-12M-AB		10813F		HPSB-12M-AB	
14,0					10814F		HPSB-14M-AB	
16,0					10815F		HPSB-16M-AB	

Standard color natural. *For special order parts in UL 94V-0 natural material, add the suffix "F" to Part No. Note: Consult Heyco for HCBS in V-0 material. V-0 material is standard for HPSB series parts.

Material: Nylon 6/6 with PE foam tape and rubber adhesive
 Flammability Rating: HCBS - 94V-2, HPSB - 94V-0
 Temperature Range: -40°F (-40°C) to 185°F (85°C)

*Quick
Specs*

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[10783](#) [10771](#)