


"Stay Connected" with



HEYware Products

a PennEngineering® Company

Heyco® Nylon PCB Supports - Imperial Spacing

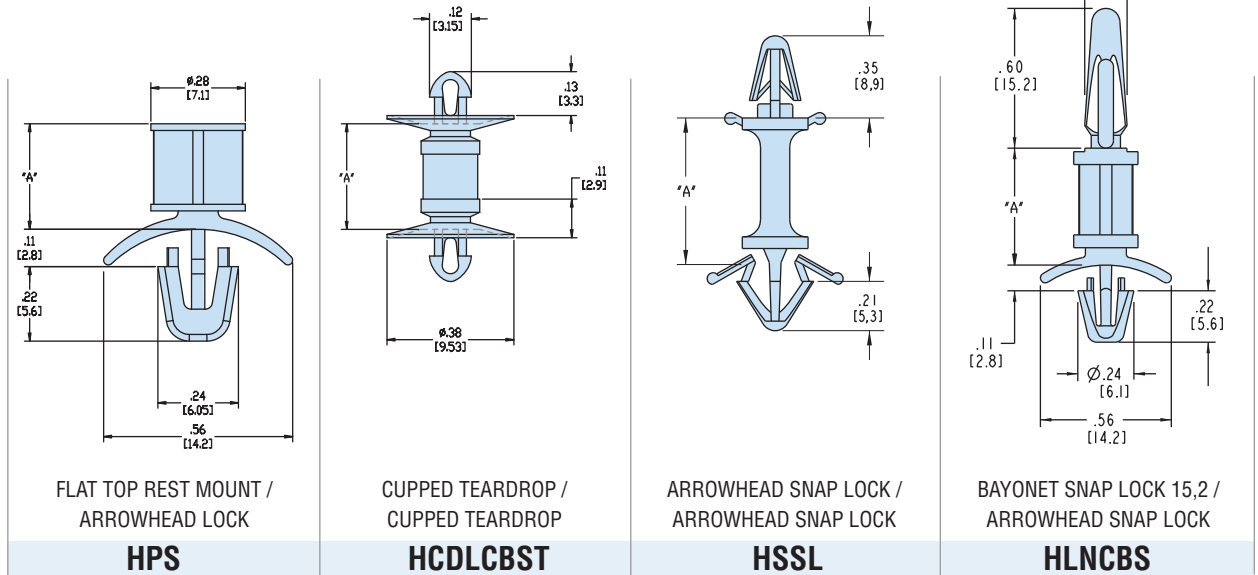

	Maximum Thickness		Mounting Hole Diameter			Maximum Thickness		Mounting Hole Diameter			Maximum Thickness		Mounting Hole Diameter			Maximum Thickness		Mounting Hole Diameter		
	in.	mm.	in.	mm.		in.	mm.	in.	mm.		in.	mm.	in.	mm.		in.	mm.	in.	mm.	
PCB	flat top rest mount					.062	1,6	.098	2,5		.062	1,6	.157	4,0		.062	1,6	.157	4,0	
Chassis	.078	2,0	.187	4,8		.062	1,6	.098	2,5		.070	1,8	.188	4,8		.078	2,0	.187	4,8	
A	PART NO.		DESCRIPTION		PART NO.		DESCRIPTION		PART NO.		DESCRIPTION		PART NO.		DESCRIPTION		PART NO.		DESCRIPTION	
in.	Natural				Natural*				Natural				Natural				Natural			
.187	4,8	10233	HPS-03		10836	HCDLCBST-03			3670	HSSL-03			10966	HLNCBS-03						
.250	6,4	10234	HPS-04		10837	HCDLCBST-04			3671	HSSL-04			10967	HLNCBS-04						
.312	7,9	10235	HPS-05		10838	HCDLCBST-05														
.375	9,5	10236	HPS-06		10839	HCDLCBST-06			3672	HSSL-06			10969	HLNCBS-06						
.437	11,1	10237	HPS-07		10840	HCDLCBST-07			3673	HSSL-07										
.500	12,7	10238	HPS-08		10841	HCDLCBST-08			3674	HSSL-08			10971	HLNCBS-08						
.562	14,3				10842	HCDLCBST-09														
.625	15,9	10239	HPS-10		10843	HCDLCBST-10			3675	HSSL-10			10973	HLNCBS-10						
.750	19,1	10240	HPS-12						3676	HSSL-12			10974	HLNCBS-12						
.875	22,2	10241	HPS-14										10975	HLNCBS-14						

Standard color natural. For special order parts in UL 94V-0 natural material, add the suffix "F" to Part No.

*Consult Heyco for HCDLCBST in V-0 material.

Material
Certifications

Nylon 6/6
Recognized under the Component Program of Underwriter's Laboratories
File E197049 (HSSL only)

Flammability Rating
Temperature Range

94V-2
-40°F (-40°C) to 185°F (85°C)

Quick
Specs

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[10966](#) [10973F](#) [10974](#) [10967F](#) [10975F](#) [10971](#) [10967](#) [10971F](#) [10966F](#) [10973](#) [10969](#) [10969F](#) [10974F](#) [10975](#)
[10241F-P](#) [10234F-P](#)