


Heyco® Nylon PCB Supports - Threaded Male

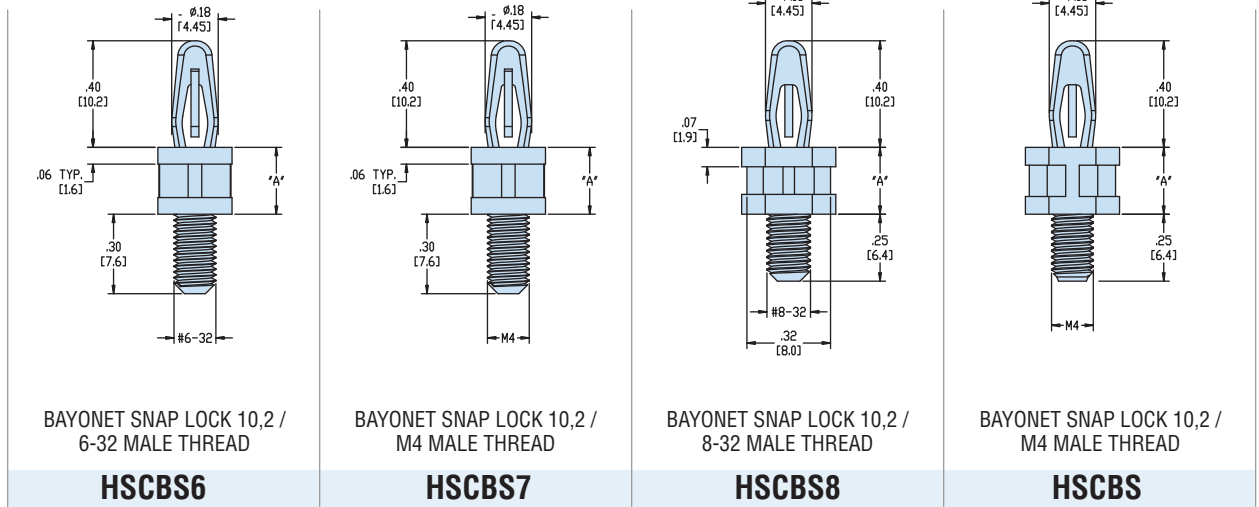

	Maximum Thickness †		Mounting Hole Diameter		Maximum Thickness †		Mounting Hole Diameter		Maximum Thickness †		Mounting Hole Diameter		Maximum Thickness †		Mounting Hole Diameter	
	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.
PCB	.062	1,6	.157	4,0	.062	1,6	.157	4,0	.062	1,6	.157	4,0	.062	1,6	.157	4,0
Chassis	.300	7,6	6-32		.300	7,6	M4		.250	6,4	8-32		.250	6,4	M4	

A		PART NO. Natural	DESCRIPTION	PART NO. Natural	DESCRIPTION	PART NO. Natural	DESCRIPTION	PART NO. Natural	DESCRIPTION
in.	mm.								
.250	6,4	10746	HSCBS6-04	10754	HSCBS7-04	10762	HSCBS8-04	10678	HSCBS-04
.375	9,5	10747	HSCBS6-06	10755	HSCBS7-06	10763	HSCBS8-06	10679	HSCBS-06
.500	12,7	10748	HSCBS6-08	10756	HSCBS7-08	10764	HSCBS8-08	10680	HSCBS-08
.625	15,9	10749	HSCBS6-10	10757	HSCBS7-10	10765	HSCBS8-10	10681	HSCBS-10
.750	19,1	10750	HSCBS6-12	10758	HSCBS7-12	10766	HSCBS8-12	10682	HSCBS-12
.812	20,6							10683	HSCBS-13
.875	22,2	10751	HSCBS6-14	10759	HSCBS7-14	10767	HSCBS8-14	10684	HSCBS-14
1.000	25,4	10752	HSCBS6-16	10760	HSCBS7-16	10768	HSCBS8-16	10685	HSCBS-16
1.125	28,6					10769	HSCBS8-18	10686	HSCBS-18
1.406	35,7					10770	HSCBS8-22.5	10687	HSCBS-22.5

Standard color natural. For special order parts in UL 94V-0 natural material, add the suffix "F" to Part No.

† Indicates thread length for Chassis end of part.

*Quick
Specs*

Material Nylon 6/6
Flammability Rating 94V-2
Temperature Range -40°F (-40°C) to 185°F (85°C)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[10764F-P](#) [10767F-P](#) [10768F-P](#) [10765F-P](#) [10766F-P](#)