


Heyco® Nylon PCB Supports - Imperial Spacing

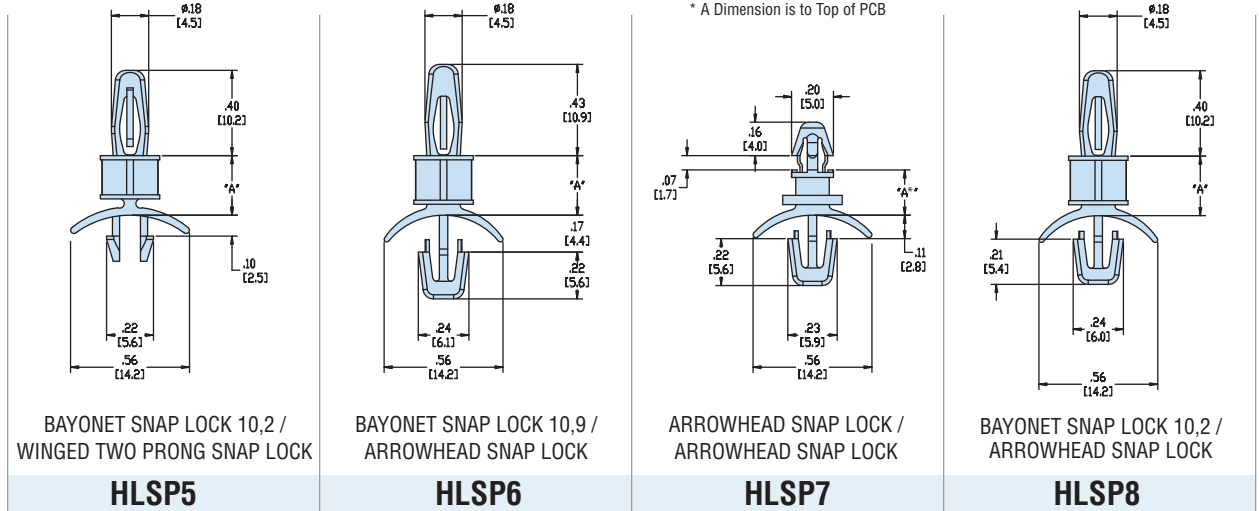

		Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter	
		in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.
PCB		.062	1,6	.157	4,0	.090	2,3	.157	4,0	.062	1,6	.157	4,0	.062	1,6	.157	4,0
Chassis		.078	2,0	.187	4,8	.141	3,6	.187	4,8	.078	2,0	.187	4,8	.055	1,4	.187	4,8
A		PART NO.		DESCRIPTION		PART NO.		DESCRIPTION		PART NO.		DESCRIPTION		PART NO.		DESCRIPTION	
in.	mm.	Natural*				Natural*				Natural				Natural			
.187	4,8	10104		HLSP5-03		10118		HLSP6-03		10132		HLSP7-03		10146		HLSP8-03	
.250	6,4	10105		HLSP5-04		10119		HLSP6-04		10133		HLSP7-04		10147		HLSP8-04	
.312	7,9	10106		HLSP5-05		10120		HLSP6-05		10134		HLSP7-05		10148		HLSP8-05	
.375	9,5	10107		HLSP5-06		10121		HLSP6-06		10135		HLSP7-06		10149		HLSP8-06	
.437	11,1	10108		HLSP5-07		10122		HLSP6-07		10136		HLSP7-07		10150		HLSP8-07	
.500	12,7	10109		HLSP5-08		10123		HLSP6-08		10137		HLSP7-08		10151		HLSP8-08	
.625	15,9	10110		HLSP5-10		10124		HLSP6-10		10138		HLSP7-10		10152		HLSP8-10	
.750	19,1	10111		HLSP5-12		10125		HLSP6-12		10139		HLSP7-12		10153		HLSP8-12	
.875	22,2	10112		HLSP5-14		10126		HLSP6-14		10140		HLSP7-14		10154		HLSP8-14	
1.000	25,4	10113		HLSP5-16		10127		HLSP6-16		10141		HLSP7-16		10155		HLSP8-16	
1.125	28,6	10114		HLSP5-18		10128		HLSP6-18		10142		HLSP7-18		10156		HLSP8-18	
1.250	31,8	10115		HLSP5-20		10129		HLSP6-20		10143		HLSP7-20		10157		HLSP8-20	
1.375	34,9	10116		HLSP5-22		10130		HLSP6-22		10144		HLSP7-22		10158		HLSP8-22	

Standard color natural. For special order parts in UL 94V-0 natural material, add the suffix "F" to Part No.

*Consult Heyco for HLSP5 & HLSP6 in V-0 material.



*Quick
Specs*

Material: Nylon 6/6
Flammability Rating: 94V-2
Temperature Range: -40°F (-40°C) to 185°F (85°C)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[10155F-P](#) [10151F-P](#) [10146F-P](#) [10154F-P](#) [10152F-P](#) [10147F-P](#) [10153F-P](#) [10149F-P](#)