



Heyco® Nylon PCB Supports - Stackable Self-Retaining Spacers

- May be stacked for multi-level PCB applications.
- Self aligning.
- One end locks into PCB.
- Clear hole variations for #4, #6 or #8 screw.

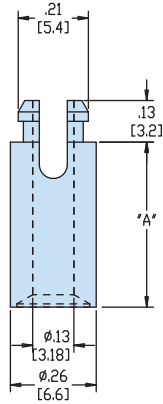


TWO PRONG SNAP LOCK /
#4 SELF-TAPPING SCREW

HSSRS4

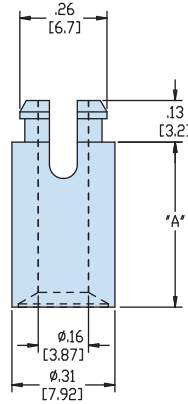

TWO PRONG SNAP LOCK /
#6 SELF-TAPPING SCREW

HSSRS6

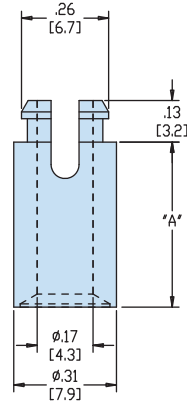

TWO PRONG SNAP LOCK /
#8 SELF-TAPPING SCREW

HSSRS8



		Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter		Maximum Thickness		Mounting Hole Diameter	
		in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.
PCB		.062	1,6	.187	4,7	.062	1,6	.232	5,9	.062	1,6	.232	5,9
Chassis		self-tapping		#4		self-tapping		#6		self-tapping		#8	M4
A		PART NO.		DESCRIPTION		PART NO.		DESCRIPTION		PART NO.		DESCRIPTION	
in.	mm.	FR Natural				FR Natural				Natural*			
.125	3,2	3681		HSSRS4-02									
.187	4,8	3683		HSSRS4-03									
.250	6,4	3684		HSSRS4-04		3689		HSSRS6-04		10857		HSSRS8-04	
.312	7,9	10926		HSSRS4-05						10858		HSSRS8-05	
.375	9,5	3685		HSSRS4-06		3690		HSSRS6-06		10859		HSSRS8-06	
.413	10,5	3686		HSSRS4-413								NEW!	
.437	11,1	10928		HSSRS4-07						10860		HSSRS8-07	
.500	12,7	3687		HSSRS4-08		3691		HSSRS6-08		10861		HSSRS8-08	
.625	15,9	3688		HSSRS4-10		3692		HSSRS6-10		10862		HSSRS8-10	
.750	19,1	10931		HSSRS4-12						10863		HSSRS8-12	
.875	22,2	10932		HSSRS4-14						10864		HSSRS8-14	
1.000	25.4	10933		HSSRS4-16						10865		HSSRS8-16	

Standard material is FR natural.

*HSSRS8 standard material is UL 94V-2 natural.

*Quick
Specs*

Material
Flammability Rating
Temperature Range

Nylon 6/6
HSSRS4 & HSSRS6 - 94V-0; HSSRS8 - 94V-2
-40°F (-40°C) to 185°F (85°C)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[3685-P](#) [3684-P](#) [3681-P](#) [3683-P](#) [3688-P](#) [3687-P](#) [3691-P](#)