




HEYClip™ Countersunk Type H Rivets

- Flat, **chamfered rivet head** for **easier disassembly** when required.
- Accommodate countersunk hole specification DIN ISO 7721.
- The "H" type rivet is designed with a flat head for fast and easy installation, without any tools.
- Simply place rivet into the hole and press down on the head to fasten.
- Part Description Key: PRH X-Y where X = Mounting Hole Diameter (inches) and Y = minimum Panel Thickness (inches).
- Standard Material: Nylon 6. Nylon 6/6 UL 94V-0 available by special order, consult Heyco.
- Standard Pack - 1,000/bag.

WILL FIT THESE PANELS						PART NO.			DESCRIPTION	PART DIMENSIONS						EXTRACTION FORCE	
MOUNTING HOLE DIA.		ASSEMBLED PANEL THICKNESS				Black	White	V-0 Black *		A Length		B Head Height		C Head Diameter		N	Style
		Min.	Max.														
in.	mm.	in.	mm.	in.	mm.								in.	mm.	in.		
PRH Series																	
.102	2,6	.22	5,5	.26	6,5	9118	9119	9118F	PRH 102-217	.33	8,5	.03	0,7	.18	4,6	49	1
.122	3,1	.04	1,0	.08	2,0	9156	9157	9156F	PRH 122-039	.14	3,5					78	1
		.08	2,0	.12	3,0	9158	9159	9158F	PRH 122-079	.18	4,5	.04	1,0	.25	6,4		
		.12	3,0	.16	4,0	9160	9161	9160F	PRH 122-118	.22	5,5						
		.16	4,0	.19	5,0	9162	9163	9162F	PRH 122-157	.26	6,5						
		.20	5,0	.24	6,0	9164	9165	9164F	PRH 122-197	.31	7,5	.04	1,0	.24	6,0		
		.22	5,5	.26	6,5	9166	9167	9166F	PRH 122-217	.32	8,0						
		.26	6,5	.30	7,5	9168	9169	9168F	PRH 122-256	.35	9,0						
		.30	7,5	.34	8,5	9170	9171	9170F	PRH 122-295	.39	10,0	.04	1,0	.25	6,4		
.142	3,6	.04	1,0	.08	2,0	9172	9173	9172F	PRH 142-039	.14	3,5	.04	1,0	.25	6,4	118	2
		.08	2,0	.12	3,0	9174	9175	9174F	PRH 142-079	.19	4,5						
		.12	3,0	.16	4,0	9176	9177	9176F	PRH 142-118	.22	5,5						
		.14	3,5	.18	4,5	9178	9179	9178F	PRH 142-138	.24	6,0						
		.18	4,5	.22	5,5	9180	9181	9180F	PRH 142-177	.28	7,0	.04	1,0	.24	6,0		
		.22	5,5	.26	6,5	9182	9183	—	PRH 142-217	.32	8,0						


Standard colors black and white.

*Black nylon 6/6 UL 94V-0.

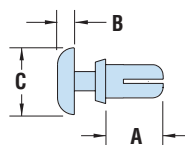

STYLE 1

STYLE 2

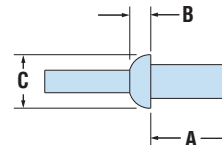

DR Series

HEYClip™ Drive Rivets

- Install by placing rivet into hole and pushing the drive pin into the rivet to expand legs and lock in place.
- No tools required.
- Part Description Key: DR X-Y where X = Mounting Hole Diameter (inches) and Y = minimum Panel Thickness (inches).
- Standard Pack - 1,000/bag.

WILL FIT THESE PANELS						PART NO.		DESCRIPTION	PART DIMENSIONS						
MOUNTING HOLE DIA.		ASSEMBLED PANEL THICKNESS				Black	Natural		A Length		B Head Height		C Head Diameter		
in.	mm.	Min.	mm.	Max.	mm.				in.	mm.	in.	mm.	in.	mm.	
.161	4,1	.16	4,0	.26	6,5	9331	9332	DR 161-157	.32	8,1	.06	1,5	.30	7,5	NEW!
.187	4,8	.04	1,0	.38	9,5	9184	9185	DR 189-039	.42	10,7	.06	1,5	.28	7,1	
		.16	4,0	.28	7,1	9186	9187	DR 189-158	.38	9,7	.06	1,5	.43	10,9	
.201	5,1	.06	1,5	.28	7,0	9336	-	DR 201-059	.36	9,1	.07	1,8	.33	8,5	NEW!
.218	5,5	.09	2,4	.16	4,0	9188	9189	DR 217-094	.45	11,4	.08	2,0	.37	9,4	
.236	6,0	.12	3,0	.28	7,0	9337	-	DR 236-118	.39	10,0	.08	2,0	.43	10,9	NEW!
		.06	1,5	.25	6,4	9190	9191	DR 252-059	.37	9,3	.10	2,5	.44	11,1	
.250	6,4	.12	3,0	.28	7,0	9341	-	DR 252-118	.49	12,5					NEW!
		.28	7,1	.50	12,7	9192	9193	DR 252-280	.62	15,8	.08	2,0	.47	11,9	

Standard colors black and natural.

*Standard color white.

Quick Specs

Material	PRH - Nylon 6	DR - Nylon 6/6
Flammability Rating	94V-2	
Temperature Range	-40°F (-40°C) to 185°F (85°C)	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[9161](#) [9166F](#) [9156](#) [9165](#) [9160F](#) [9165F](#) [9180F](#) [9171](#) [9160](#) [9158](#) [9162F](#) [9172F](#) [9178F](#) [9118](#) [9181](#) [9162](#) [9175](#)
[9173](#) [9176](#) [9179](#) [9170](#) [9170F](#) [9164](#) [9168](#) [9167](#) [9174](#) [9174F](#) [9166](#) [9183](#) [9177](#) [9163](#) [9172](#) [9158F](#) [9157](#)
[9168F](#) [9176F](#) [9169](#) [9182](#) [9156F](#) [9119](#) [9180](#) [9159](#) [9118F](#) [9178](#) [9185-P](#) [9186-P](#) [9187-P](#) [9188-P](#) [9193-P](#) [9184-](#)
[P](#) [9189-P](#) [9336-P](#) [9191-P](#) [9190-P](#) [9337-P](#) [9332-P](#) [9331-P](#) [9341-P](#) [9192-P](#)