

## Heyco® Quick Connect Terminals

See pages 8-13 & 8-14 for mating Quick Connect Females.  
For Heyco Applicators, see page 8-59

### Male Terminal Tabs - .020 gauge

PART DATA					PART NO.	APPLICATION TOOLING*			
Crimp?	Ref Dwg	Overall Length in.	AWG Range	Material		Die**	Feeds	Crimp Punch	Anvil
Solder Connection Tabs									
No	4700	.61	Solder	Brass	4700	-	Bulk	-	-
Crimp Connection Tabs									
Yes	4710	.61	18	Brass	4710	-	Bulk	-	-
				Brass	4750	4750UXX5	Left to Right	C458	C463
	8301	.61	18	Brass	8301	8301UXX5	Right to Left	C460	C465
Dual Connection Tabs									
No	4720	.69	Dual	Brass	4720	-	Bulk	-	-

\* Heyco high volume Application Tooling, designed for 3-5 ton presses - see page 8-59.


Heyco Mini Applicators, designed for 1.5-3 ton bench top presses, are available for Part Nos. 4750 and 4751 only. See page 8-59.

\*\* "XX" represents Wire Gauge. Please specify Wire Gauge when ordering.




- All terminals feature a **rectangular "locking tab"** in center for added **strain relief** and **support** when inserted into Female Connector.
- Heyco Terminals meet all your application needs with **solder**, **crimp**, and **dual male** connections.
- DFARS Compliant


**4700**

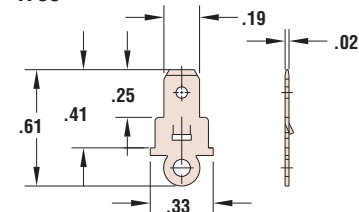


**4720**

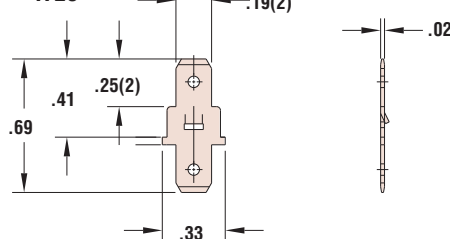

**4710**

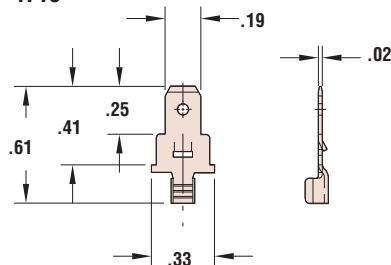

**8301**

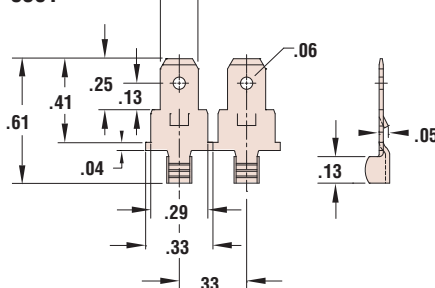

Materials

Alloy 260 Brass (70% Cu, 30% Zn. Higher Cu content resists dezincification)

*Quick  
Specs*

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[4750](#) [4700](#) [4710](#) [4720](#) [8301](#)