



- One-piece solution with smooth internal surfaces provides for easier wire routing, protection, and installation.
- Easy, permanent assembly: the installer twists the tubing over the connector ferrule.
- Unique locking fingers accommodate various panel thicknesses.
- All nylon construction is resistant to salt water, weak acids, gasoline, alcohol, oil, grease, and common solvents. (This feature is not assessed by UL certification and testing.)
- Suitable for a wide array of electrical applications:
 - Commercial and Industrial HVAC Systems
 - Motorized Equipment
 - Enclosed Power Sources
 - Garage Door Openers
 - Major Appliances
- Finishing collars available to neaten rough cut tubing ends.
- Assembly Tool available for assembling Quick Twist Fittings into HF1 and HF2 Conduit and Tubing (see page 2-14)

Snap-In Hubs

- Snap-in Fittings are UL recognized for use with Heyco-Flex II Tubing.
- Suitable for dry location only.

NPT Hubs

- NPT threaded fittings are UL approved for use with Heyco-Flex I & II Conduit and Tubing.
- If using a tapped hole, Teflon® tape is needed on the threads of the connector, for all other applications an O-ring and Locknut are needed to attain liquid tight.
- **Locknuts not included.** To order nylon or metal locknuts separately, see pages 2-17 and 2-18.
- See page 2-20 for O-Rings.

Heyco-Flex™ Quick Twist Conduit Fittings

For use with Heyco-Flex™ I and II Conduit and Tubing

Straight-Thru, Snap-In and NPT Hubs

FITS TUBING TRADE SIZE	PART NO.			PART DIMENSIONS									
	Black	Black w/ Finishing Collar*	Gray	A Mounting Hole Dia.		B Overall Length		C Body Length		D Wrenching Nut Thickness		E Flat Size	
				in.	mm.	in.	mm.	in.	mm.	in.	mm.	in.	mm.

Snap-In Hubs - For use with Heyco-Flex™ II Tubing


1/4	8515	—	8516	HFC 1/4-S-Twist	.540	13,7	1.33	33,8	.34	8,7	.09	2,3	.75	19,1
3/8	8485	8485FC	8486	HFC 3/8-S-Twist	.875	22,2	1.38	35,0	.39	9,9	.09	2,3	1.00	25,4
1/2	8490	8490FC	8491	HFC 1/2-S-Twist	1.109	28,2	1.50	38,0	.39	9,9	.09	2,3	1.25	31,8
3/4	8495	8495FC	8496	HFC 3/4-S-Twist	1.109	28,2	1.50	38,0	.39	9,9	.09	2,3	1.25	31,8

NPT Hubs - For use with Heyco-Flex™ I and II Conduit and Tubing

1/4	8517	—	8518	HFC 1/4-Twist	.540	13,7	1.56	39,6	.47	11,8	.20	5,1	.75	19,1
3/8	8487	8487FC	8488	HFC 3/8-Twist	.875	22,2	1.72	43,7	.63	15,9	.20	5,1	1.18	30,0
1/2	8493	8493FC	8494	HFC 1/2-Twist	1.109	28,2	1.84	46,7	.63	15,9	.20	5,1	1.37	34,8
3/4	8497	8497FC	8498	HFC 3/4-Twist	1.109	28,2	1.84	46,7	.63	15,9	.20	5,1	1.37	34,8

Standard colors black and gray.

*Collar not assembled.

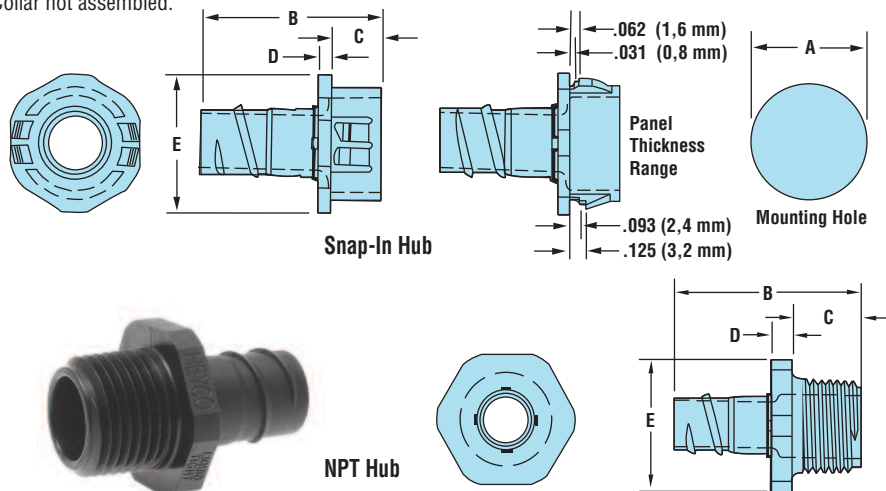

Heyco-Flex™ Quick Twist Finishing Collars

For use with Heyco-Flex™ I and II Conduit

FITS CONDUIT/ TRADE SIZE	PART NO.		DESCRIPTION
	Black	Gray	
3/8	8474	8482	HFC TWIST 3/8 COLLAR
1/2	8475	8483	HFC TWIST 1/2 COLLAR
3/4	8476	8484	HFC TWIST 3/4 COLLAR

Standard colors black and gray. Consult Heyco for other colors. (Not available in 1/4").

Material Nylon 6/6

Certifications



Recognized under the Component Program of Underwriters' Laboratories File E121095 (Snap-in Hubs)



UL Listed under Underwriters' Laboratories File E28430 (NPT Hubs)

Flammability Rating

94V-2

Temperature Range

-22°F (-30°C) to 221°F (105°C)



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[8494](#) [8485](#) [8486](#) [8490](#) [8491](#) [8495](#) [8496](#) [8515](#) [8516](#) [8493](#) [8497FC](#) [8518](#) [8487](#) [8487FC](#) [8493FC](#) [8517](#)
[8495FC](#) [8485FC](#) [8490FC](#) [8488](#) [8497](#) [8498](#)