



HEYClip™ Unscrewing Snap Rivets

 
WILL FIT THESE PANELS						PART NO.	DESCRIPTION	PART DIMENSIONS						STYLE
MOUNTING HOLE DIA.		ASSEMBLED PANEL THICKNESS						A Length		B Head Height		C Head Diameter		
		Min.		Max.										
in.	mm.	in.	mm.	in.	mm.			Black	in.	mm.	in.	mm.	in.	
HUSR Series														
.197	5,0	.059	1,5	.236	6,0	4330	HUSR 197-059							
.236	6,0					4331	HUSR 236-059	.43	11,0	.15	3,9	.63	16,0	1
.250	6,4	.125	3,2	.173	4,4	4392	HUSR 250-125	.50	12,7	.12	3,0	.59	15,1	4
.315	8,0	.118	3,0	.394	10,0	4332	HUSR 315-118	.55	14,0	.16	4,0	.79	20,0	2
		.125	3,2	.217	5,5	4333	HUSR 315-276	.80	20,3	.14	3,6			3

Standard color black.


HEYClip™ Tough Rivets

WILL FIT THESE PANELS								PART NO.	DESCRIPTION	PART DIMENSIONS						
MOUNTING				ASSEMBLED						A		B		C		
HOLE DIAMETER				PANEL THICKNESS						Length		Head		Head		
Minimum		Maximum		Minimum		Maximum				Below Panel		Height		Diameter		
in.	mm.	in.	mm.	in.	mm.	in.	mm.	Black		in.	mm.	in.	mm.	in.	mm.	
Mini - MTR Series																
.122	3,1	.128	3,3	.155	3,9	.180	4,6	12475	MTR 180-125	.37	9,4	.05	1,3	.22	5,5	
.144	3,7	.154	3,9	.265	6,7	.290	7,4	12477	MTR 290-150	.47	11,9	.05	1,3	.30	7,6	
Standard - TR Series																
.193	4,9	.205	5,2	.059	1,5	.181	4,6	12466	TR 181-199	.45	11,3	.08	2,1	.28	7,2	
.250	6,4	.276	7,0	.098	2,5	.315	8,0	12468	TR 315-263	.90	22,8	.11	2,8			
.315	8,0	.325	8,3	.118	3,0	.315	8,0	12469	TR 315-320	.83	21,1	.09	2,3	.59	15,0	

Standard color black.



MTR Series

 

TR Series

HEYClip™ Removable Rivets

ALL NEW PRODUCTS

WLL FIT THESE PANELS				PART NO.	DESCRIPTION	PART DIMENSION					
Mounting Hole Diameter		Assembled Panel Thickness				A Length Below Panel		B Head Height		C Head Diameter	
in.	mm.	in.	mm.			in.	mm.	in.	mm.	in.	mm.
.188	4,8	.062	1,6	12220	HRR 062-188	.50	12,7	.07	1,8	.38	9,5
		.125	3,2	12221	HRR 125-188						
.250	6,4	.062	1,6	12222*	HRR 062-250	.50	12,7	.07	1,8	.44	11,1
		.125	3,2	12223	HRR 125-250						
		.187	4,7	12224	HRR 187-250						


Standard color natural.

*Will also fit .210"/.218" square hole (for Darling Shelves).

	HUSR (Style 1,2)	HUSR (Style 3)	HUSR (Style 4)	MTR	TR	HRR
Material	Nylon 6/6	Base: Nylon 6, UL 94 V-2	Nylon 6, UL 94 V-2	Nylon 6	Nylon 6/6	Nylon 6/6
Flammability Rating	UL 94 V-2	Drive Pin: Acetal (POM) UL 94 HB	UL 94 V-2	UL 94 V-2	UL 94 V-2	UL 94 V-2
Temperature Range	-40°F (-40°C) to 185°F (85°C)	-40°F (-40°C) to 185°F (85°C)	-22°F (-30°C) to 167°F (75°C)	-22°F (-30°C) to 167°F (75°C)	-40°F (-40°C) to 185°F (85°C)	-40°F (-40°C) to 185°F (85°C)




- Phillips head screw driver required for removal.

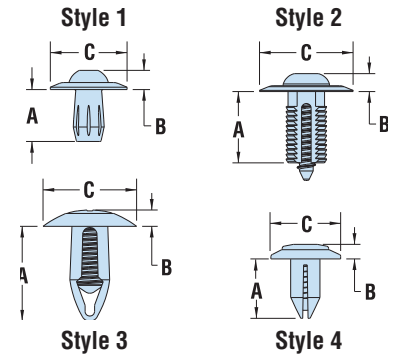

- Molded from impact modified nylon for vibration resistance.
- One-piece design requires no tools for installation.
- Provide solid, vibration-resistant connections by means of front mount, blind side fixing.
- Provide neat and smooth finishes for fastening applications.
- Removable by pulling the pin out of the grommet; reusable.



 - Two-piece rivet can be removed by retracting the pin then the body.
- Slot in line with pin for pin removal with small screw driver, fingernail or other sharp edge underneath the head of the pin.



HRR Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[12223B](#) [12220B](#) [12222B](#) [12221B](#) [12224B](#)