



Heyco® Retaining Sealing Washers

Will Fit These Electrical Fitting Threaded Hubs	PART NO. Black	DESCRIPTION	PART DIMENSIONS					
			A Inside Diameter		B Outside Diameter		C Thickness	
			in.	mm.	in.	mm.	in.	mm.

NPT Hubs

	1/4	G6000	RSW 1/4 NPT	.540	13,7	.740	18,8	.076	1,9
	3/8	G6001	RSW 3/8 NPT	.680	17,3	.865	22,0		
	1/2	G6002	RSW 1/2 NPT	.875	22,2	1.050	26,7		
	3/4	G6003	RSW 3/4 NPT	1.109	28,2	1.300	33,0		
	1	G6004	RSW 1 NPT	1.375	34,9	1.725	43,8		
NEW!	1-1/4	G6005	RSW 1-1/4 NPT	1.735	44,1	2.094	53,2		
NEW!	1-1/2	G6006	RSW 1-1/2 NPT	1.984	50,4	2.375	60,3		
NEW!	2	G6007	RSW 2 NPT	2.469	62,7	2.740	69,6		


Pg Hubs

Pg 7	G6010	RSW PG 7	.495	12,6	.740	18,8	.076	1,9
Pg 9	G6011	RSW PG 9	.600	15,2	.865	22,0		
Pg 13	G6013	RSW PG 13.5	.810	20,6	1.050	26,7		
Pg 16	G6014	RSW PG 16	.890	22,6	1.187	30,1		
Pg 21	G6015	RSW PG 21	1.120	28,4	1.300	33,0		
Pg 29	G6016	RSW PG 29	1.475	37,5	1.725	43,8		

Metric Hubs

M12	G6020	RSW M12	.475	12,1	.740	18,8	.076	1,9
M16	G6021	RSW M16	.635	16,1	.865	22,0		
M20	G6022	RSW M20	.790	20,1	1.050	26,7		
M25	G6023	RSW M25	.990	25,1	1.300	33,0		
M32	G6024	RSW M32	1.270	32,3	1.725	43,8		

Standard color black.

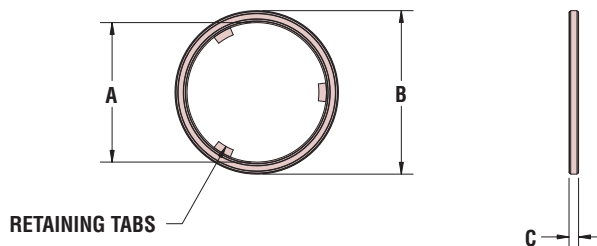

- Retaining tabs hold washer on threads for easier assembly.
- Liquid tight, dust tight, and oil tight at enclosure.
- Suitable for wet locations requiring a separate gasket between the box and fitting.
- Also suitable for other panel sealing applications.
- Easy to install since washers seal off on the perimeter, not on the connector threads.
- Special double sealing ridges compensate for minor unevenness at enclosure.

Material SBR (Styrene Butadiene)
 Flammability Rating HB
 Temperature Range -4°F (-20°C) to 212°F (100°C)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[G6011](#) [G6010](#) [G6014](#) [G6016](#) [G6021](#) [G6015](#) [G6013](#) [G6023](#) [G6003](#) [G6022](#) [G6024](#) [G6000](#) [G6002](#) [G6020](#)
[G6001](#) [G6004](#) [G6007](#) [G6006](#) [G6005](#)