



Heyco® Snap Bushings

Mounting Hole Diameter Range: 1.000" (25,4 mm) to 2.500" (63,5 mm)

MOUNTING HOLE DIAMETER		PART NO.		DESCRIPTION	PART DIMENSIONS					
		Black	White		A Inside Diameter		B Head Diameter		C Overall Height	
in.	mm.				in.	mm.	in.	mm.	in.	mm.
Multiple Locking Steps for Panel Thickness up to .125" (3,2 mm)										
1.000	25,4	2140	2141	SB 1000-12	.77	19,4	1.13	28,6	.45	11,5
1.093 - 1.125	27,8 - 28,6	2160	2161	SB 1093-13	.81	20,6	1.22	30,9		
		2163	2164	SB 1093-14	.88	22,2				
		2166	2167	SB 1093-15	.94	23,8				
1.187	30,2	2182	2183	SB 1187-15	.94	23,8	1.32	33,5		
1.250	31,8	2198	2199	SB 1250-15	.94	23,8	1.36	34,5		
		2201	2202	SB 1250-16	1.00	25,4	1.31	33,3		
1.375	34,9	2207	2208	SB 1375-14	.88	22,2	1.49	37,9		
		2210	2211	SB 1375-16	1.01	25,8				
1.500	38,1	2233	2234	SB 1500-17	1.06	27,0	1.61	40,9		
		2236	2237	SB 1500-18	1.13	28,6				
		2240	2241	SB 1500-21	1.31	33,3				
1.625	41,3	2273	2274	SB 1625-21	1.31	33,3	1.74	44,2		
1.750	44,5	2300	2301	SB 1750-22	1.38	34,9	1.88	47,6		
1.875	47,6	2287	2288	SB 1875-24	1.50	38,1	2.00	50,8		
2.000	50,8	2400	2401	SB 2000-26	1.64	41,6	2.13	54,0		
		2406	2414	SB 2000-28	1.75	44,5				
Multiple Locking Steps for Panel Thickness up to .250" (6,4 mm)										
2.093	53,1	2415	2416	SB 2.093-29	1.81	46,0	2.35	59,7	.72	18,3
2.250	57,2	2419	-	SB 2.250-29-180	1.80	45,7	2.48	63,1		
		2417	2418	SB 2.250-29	1.86	47,1				
2.500	63,5	2420	2421	SB 2.500-31	1.97	50,0	2.66	67,5		

- Convert raw-edged holes to smooth, neat, insulated holes.
- Insulate and mechanically protect electrical and telecommunications cables, tubing, hose, rope, and utility lines.
- Locking fingers snap into holes with fingertip pressure.
- Locking fingers in fractional increments up to the maximum panel thickness.
- Withstand a push back force of 35 pounds.
- Available in multiple sizes for use in .250" (6,4 mm) to 6.00" (152,4 mm) diameter holes.
- We offer the following brass-colored parts for lamp and lighting applications:
Part No. 2012, SB 312-3 Brass
Part No. 2033, SB 375-4 Brass
Part No. 2041, SB 437-4 Brass

Standard colors black and white. Consult Heyco for other colors.

Larger 3.000" (76,2 mm) to 6.000" (152,4 mm) Diameter Parts

Small Packs Available

MOUNTING HOLE DIAMETER		PART NO.		DESCRIPTION	PACKAGING		PART DIMENSIONS					
in.	mm.	Black	White		BULK (Std)	SMALL PACK*	A Inside Diameter		B Head Diameter		C Overall Height	
							in.	mm.	in.	mm.	in.	mm.
Multiple Locking Steps for Panel Thickness up to .250" (6,4 mm)												
3.000	76,2	2461	2462	SB 3.000-39	300	5	2.47	62,7	3.15	80,0	.75	19,1
		2424	2425	SB 3.000-44	300	5	2.75	69,9	3.16	80,2	.72	18,3
3.375	85,7	2407	2408	SB 3.375-45	400	5	2.81	71,4	3.66	93,0	.72	18,3
3.500	88,9	2470	2471	SB 3.500-47	200	5	2.94	74,7				
4.000	101,6	2479	2480	SB 4.000-55	300	5	3.47	88,1	4.15	105,4	.74	18,8
5.000	127,0	2409	2410	SB 5.000-70	150	1	4.38	113,8	5.22	132,6		
6.000	152,4	2484	2485	SB 6.000-86	130	1	5.38	139,2	6.22	157,9		

Standard colors black and white. Consult Heyco for other colors.

*Small Pack available in Black color only. To order, please add the suffix -P to Part No., e.g., 2461-P

Material

Nylon 6/6

Certifications



Recognized under the Component Program of Underwriters' Laboratories, File E15331




Certified by Canadian Standards Association, File 8919

Flammability Rating

94V-2

Temperature Range

-4°F (-18°C) to 221°F (105°C)

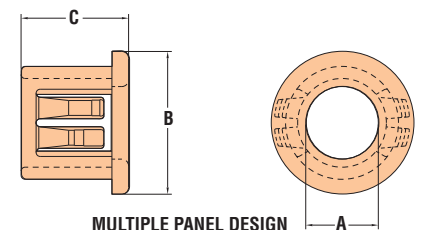

MULTIPLE PANEL DESIGN

Quick
Specs

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[2300](#) [2198](#) [2182](#) [2140](#) [2166](#) [2160](#) [2163](#) [2240](#) [2201](#) [2210](#) [2236](#) [2164](#) [2400](#) [2406](#) [2461](#) [2420](#) [2417](#) [2470](#)
[2479](#) [2161](#) [2233](#) [2401](#) [2415](#) [2424](#) [2273](#) [2274](#) [2400-P](#) [2240-Q](#)