

Heyco® Snap-In Cordgrip Strain Reliefs – Straight-Thru and Pigtail™


The Ultimate in Snap-In Strain Relief Protection

For Panels from .062" (1,6 mm) to .125" (3,2 mm) Thick

WILL FIT THESE CABLES				PART NO.	DESCRIPTION		PANEL DIMENSIONS						Mounting Hole Plug
Minimum Diameter		Maximum Diameter					A Mounting Hole	B To Prevent Rotation		C Max O.A. Length			
in.	mm.	in.	mm.	Black		in.		mm.	in.	mm.	in.	mm.	Part No.
Straight-Thru													
.210	5,3	.210	5,3	M4802	RSCG 500		.500	12,7	.450	11,4	1.21	30,7	2491
.240	6,1	.250	6,4	M4800	SCG 500								
.210	5,3	.230	5,8	M4808	RSCG 625		.625	15,9	.550	14,0	1.30	33,0	2497
.210	5,3	.315	8,0	M4806	SCG 625								
.230	5,8	.260	6,6	M4814	RSCG 750		.750	19,1	.660	16,8	1.48	37,6	2503
.230	5,8	.400	10,2	M4812	SCG 750								
.255	6,5	.290	7,4	M4820	RSCG 875		.875	22,2	.770	19,6	1.46	37,1	2509
.250	6,4	.450	11,4	M4818	SCG 875								
.300	7,6	.400	10,2	M4826	RSCG 1000		1.000	25,4	.875	22,2	1.62	41,1	2713*
.350	8,9	.545	13,8	M4824	SCG 1000								
.385	9,8	.490	12,4	M4832	RSCG 1093		1.093	27,8	.970	24,6	1.75	44,5	2723*
.435	11,0	.705	17,9	M4830	SCG 1093								
.385	9,8	.490	12,4	M4838	RSCG 1125		1.125	28,6	1.000	25,4	1.75	44,5	2717
.435	11,0	.705	17,9	M4836	SCG 1125								
.490	12,4	.785	19,9	M4844	RSCG 1250		1.250	31,8	1.125	28,6	2.05	52,1	2740*
.590	15,0	1.000	25,4	M4842	SCG 1250								
.490	12,4	.785	19,9	M4850	RSCG 1375		1.375	34,9	1.250	31,8	2.05	52,1	2753*
.590	15,0	1.000	25,4	M4848	SCG 1375								
.787	20,0	1.020	25,9	M4856	RSCG 1500		1.500	38,1	1.375	34,9	2.23	56,6	2763*
.875	22,2	1.260	32,0	M4854	SCG 1500								
.787	20,0	1.020	25,9	M4862	RSCG 1750		1.750	44,5	1.625	41,3	2.28	57,9	2773*
.875	22,2	1.260	32,0	M4860	SCG 1750								
Pigtail													
.210	5,3	.210	5,3	M4902	RSCG 500-7		.500	12,7	.450	11,4	2.50	63,5	2491
.240	6,1	.250	6,4	M4900	SCG 500-7								
.210	5,3	.230	5,8	M4908	RSCG 625-7		.625	15,9	.550	14,0	2.83	71,9	2497
.210	5,3	.315	8,0	M4906	SCG 625-7								

Standard color black.

*For round Mounting Hole only. For DD Mounting Hole Plug, consult Heyco.

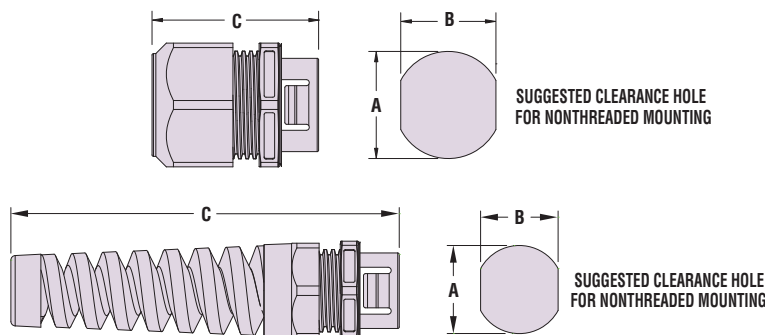

Material
Certifications

Nylon 6/6 w/Buna N Sealing Gland
Recognized under Underwriters' Laboratories File E51579
Certified by Canadian Standards Association File 093876

Flammability Rating
Temperature Range

94V-2
-04°F (-18°C) to 221°F (105°C)

Quick Specs

- Unique fingers securely lock into a range of panel sizes without use of locknut.
- Pigtail: Integral nylon spring eases the cable into a lazy bend; prevents kinking and assures longest cable and product life.
- Smooth, rounded interior edges for ease of installation.
- Limited intrusion into enclosure where access is tight.
- Rotation prevented when used in Double D mounting holes.
- Easy to install—no tools required.
- Ratchet design of sealing nut assembly provides superior anti-vibration and ensures a firm grip on the cable.
- Available in multiple sizes for cable diameters ranging from .210" (5,3 mm) to 1.260" (32,0 mm).
- We recommend using the fitting with the smallest maximum diameter that will fit your application.
- Meet UL strain relief requirements without kinking the cable.
- For Foam Washers, see page 2-20.
- Though similar in appearance and function to Heyco-Tite Liquid Tight Cordgrips, Snap-in Cordgrip Strain Reliefs may not be liquid tight at the panel interface. For our complete range of **Liquid Tight** Cordgrips with Integral Sealing Ring, see Section 3.
- Use Heyco **Mounting Hole Plugs** for DD Mounting Holes, or **Heyco Dome Plugs** for round Mounting Holes, to fill blank/unused Mounting Holes and thus allow for a single panel design across multiple applications. See section 6.
- For Double D Mounting Hole Punches, see page 4-30.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[M4812](#) [M4814](#) [M4836](#) [M4848](#) [M4830](#) [M4824](#) [M4818](#) [M4820](#) [M4844](#) [M4854](#) [M4800](#) [M4850](#) [M4856](#) [M4842](#)
[M4806](#) [M4808](#) [M4802](#) [M4874](#) [M4838](#) [M4866](#) [M4872](#) [M4832](#) [M4862](#) [M4868](#) [M4860](#) [M4826](#)