

Now Available
in Single Reel
Order Quantities!



Heyco® Specialty Female Connectors

For mating Male Pins, see pages 8-45 & 8-46

For Female Ground Pins, see pages 8-41 & 8-44

1330 Series

- **D-Shape Barrel** for better contact.
- .125" (3,2 mm) mating Male Pin diameter for all Part Nos. in Series 1330
 - Available in (3) different lengths: .33" (8,4 mm), .45" (11,4 mm) and .61" (15,5 mm).
 - Assembly dies available for crimping 1, 2 or 3 conductors simultaneously.
- 1/4" (6,4 mm) spacing between connectors for quick, easy attachment.
- Conductor crimp ears only.
- Available only in continuous strip form, regular (left to right) wind and reverse (right to left) wind.
- DFARS Compliant

JH & JHB Series

- .87" (22,1 mm) Overall Length.
- .50" (12,7 mm) **Round Barrel** Length.
- Conductor crimp ears only.
- Available only in continuous strip form, regular (left to right) wind.
- DFARS Compliant

Heater Cord Connector

- 3 wiping legs assure excellent **electrical continuity**.
- Features flaps below crimp for added **strain relief** when placed in a housing.
- Mates with a .156" (4,0 mm) diameter Male Pin.
- DFARS Compliant

Inside Dia. in.	Barrel Length in.	PART DATA			PART NO.	APPLICATION TOOLING*				
		Overall Length in.	AWG Range	Material		Die**	Feeds	Tool Packs	Crimp Punch	Anvil
1330 Series										
.122	.610	.950	24-18	Brass	7357	7357UXX5	Right to Left or	B580R/B581R B578R/B579R	C792 C737	C793 C738
					7359†	7359UXX5	Left to Right or	B582L/B583L B584L/B585L	C026 C030	C035 C037
					7358†	7358UXX5	Right to Left or	B582R/B583R B584R/B585R	C026 C030	C035 C037
	.610	.950	18-16	Brass	7366	7366UXX5	Left to Right or	B572L/B573L B574L/B575L	C020 C024	C034 C036
					7364	7364UXX5				
					7360	7360UXX5	Right to Left or	B572R/B573R B574R/B575R	C020 C024	C034 C036
7361	7361UXX5									

JH Series - 3-Finger Crimp

.105	.500	.870	18-16	Brass	7535	7535UXX5	Left to Right	B524L/B525L	C362	C367
.122	.500	.870	18-16	Brass	7540	7540UXX5				
.153	.500	.870	18-16	Brass	7545	7545UXX5				

JHB Series - Swedged Crimp

.105	.500	.870	18-16	Brass	7610	7610UXX5	Left to Right	B526L/B527L	C580	C581
.122	.500	.870	18-16	Brass	7615	7615UXX5				
.153	.500	.870	18-16	Brass	7620	7620UXX5				

Heater Cord Connector

.156	-	-	18-14	Brass	7530	7530UXX5	Left to Right	B970L/B971L	C701	C697
------	---	---	-------	-------	------	----------	---------------	-------------	------	------


* Heyco high volume Application Tooling, designed for 3-5 ton presses - see page 8-59.

Heyco Mini Applicators, designed for 1.5-3 ton bench top presses, are available - see page 8-59.


** "XX" represents Wire Gauge. Please specify Wire Gauge when ordering.

† With Insulation Crimp for strain relief and wire support for insertion into the housing.


1330 Series

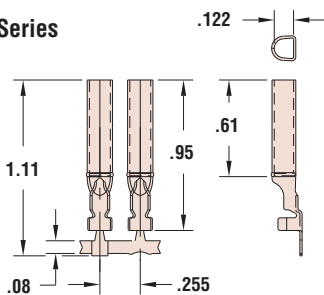


JH Series

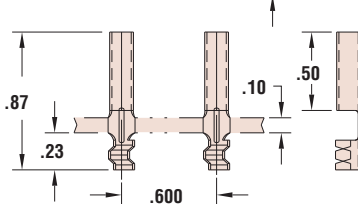

JHB Series

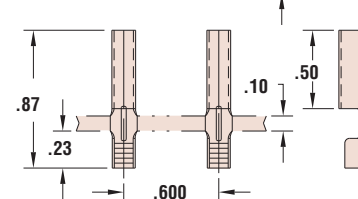

Heater Cord Connector

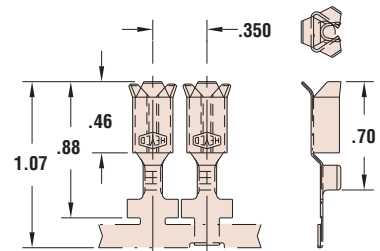

Quick
Specs

Material

Alloy 260 Brass (70% Cu, 30% Zn. Higher Cu content resists dezincification)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[7360](#) [7358](#) [7364](#) [7610](#) [7540](#) [7530](#) [7615](#) [7620](#) [7357](#) [7545](#) [7359](#) [7361](#) [7366](#)