



Heyco® SunClamp™ Stainless Steel Cable Clamps

 
MOUNTING HOLE DIAMETER		SCREW SIZE	PART DIMENSION A		PART NO.	DESCRIPTION
in.	mm.		in.	mm.		

Standard – "P Clamp" Design

.203	5,2	10	.19	4,7	S3373	CC H 3/16 SS
			.25	6,3	S3374	CC H 1/4 SS
			.38	9,5	S3376	CC H 3/8 SS
			.50	12,7	S3378	CC H 1/2 SS
			.63	15,9	S3380	CC H 5/8 SS
			.75	19,1	S3382	CC H 3/4 SS
			.88	22,2	S3384	CC H 7/8 SS

Standard – Coated

.203	5,2	10	.19	4,7	S3323	CC H 3/16 SSC
			.25	6,3	S3324	CC H 1/4 SSC
			.38	9,5	S3326	CC H 3/8 SSC
			.50	12,7	S3328	CC H 1/2 SSC
			.63	15,9	S3330	CC H 5/8 SSC
			.75	19,1	S3332	CC H 3/4 SSC
			.88	22,2	S3334	CC H 7/8 SSC



Heyco® Steel Cushion Clamps

MOUNTING HOLE DIA.		SCREW SIZE	PART DIMENSION A		PART NO.	DESCRIPTION
in.	mm.		in.	mm.		

.650 (16,5 mm) Overall Width, .031 (0,8 mm) Steel Thickness

.265	6,7	1/4	.187	4,7	12300	CCSC L 3/16
			.250	6,3	12301	CCSC L 1/4
			.312	7,9	12302	CCSC L 5/16
			.375	9,5	12303	CCSC L 3/8
			.437	11,1	12304	CCSC L 7/16
			.500	12,7	12305	CCSC L 1/2
			.562	14,3	12306	CCSC L 9/16
			.625	15,9	12307	CCSC L 5/8
			.687	17,4	12308	CCSC L 11/16
			.750	19,1	12309	CCSC L 3/4
			.875	22,2	12310	CCSC L 7/8
			1.000	25,4	12311	CCSC L 1
			1.125	28,6	12312	CCSC L 1-1/8
			1.250	31,8	12313	CCSC L 1-1/4

.750 (19,1 mm) Overall Width, .047 (1,2 mm) Steel Thickness


.406	10,3	7/16	.250	6,3	12331	CCSC H 1/4
			.312	7,9	12332	CCSC H 5/16
			.375	9,5	12333	CCSC H 3/8
			.437	11,1	12334	CCSC H 7/16
			.500	12,7	12335	CCSC H 1/2
			.625	15,9	12337	CCSC H 5/8
			.687	17,4	12338	CCSC H 11/16
			.875	22,2	12340	CCSC H 7/8
			1.000	25,4	12341	CCSC H 1
			1.250	31,8	12343	CCSC H 1-1/4

Material 304 Stainless Steel (Stainless Steel Cable Clamps)
Zinc Plated Steel with an EPDM Sleeve (Steel Cushion Clamps)

- For clamping cable or tubing securely into place, especially in **harsh environments**.
- Smooth "coined" clamp edges prevent damage to cable insulation.
- Constructed from corrosion resistant 304 stainless steel.
- Insulated parts are constructed from 304 stainless steel and coated with polyolefin, a thermoplastic co-polymer that provides a durable non-toxic, odorless coating that has very good low temperature flexibility and excellent electrical properties. This coating also has FDA food contact approval.
- Consult Heyco for larger sizes.
- Not for use in a marine salt water environment. Contact Heyco for alternative materials.
- All parts require a .203" (5,2 mm) mounting hole suitable for a #10 screw.
- DFARS Compliant.



- Light to heavy duty steel clamp.
- E.P.D.M. cushion for electrical insulation and vibration absorption.
- Steel clamps are zinc electroplated for corrosion resistance.
- Color - Silver with durable black cushion.

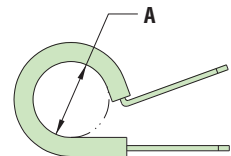

Quick Specs

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[S3324](#) [S3326](#) [S3328](#) [S3330](#) [S3332](#) [S3334](#) [S3374](#) [S3376](#) [S3378](#) [S3380](#) [S3382](#) [S3384](#) [S3373](#) [S3323](#)