

HEYClip™ Tension Wire Clips - Vinyl U Style

Adhesive-Back Mount

MAXIMUM BUNDLE DIAMETER A		PART NO. Gray	DESCRIPTION	PACKAGING		OVERALL HEIGHT D*		FOOTPRINT** B x C	
in.	mm.			Std. Pack	Small Pack †	in.	mm.	in.	mm.
WCUA Series									
.13	3,2	3335	WCUA 125	5000	25	.29	7,4	.75 x .75	19,1 x 19,1
.25	6,4	3336	WCUA 250	5000	25	.47	11,9		
.38	9,5	3337	WCUA 375	5000	25	.59	15,1		
.50	12,7	3338	WCUA 500	5000	10	.61	15,5	1.00 x 1.00	25,4 x 25,4
.56	14,3	3339	WCUA 562	1000	10	.64	16,3		
.75	19,1	3341	WCUA 750	1000	10	.89	22,6		
WCDA Series									
NEW PRODUCT!									
.25	6,4	3821	WCDA 250	5000	25	.40	10,2	.50 x .50	12,7 x 12,7
.50	12,7	3822	WCDA 500	3000	25	.73	18,5	.75 x .75	19,1 x 19,1
.75	19,1	3823	WCDA 750	3000	10	1.02	25,9	1.13 x 1.00	28,7 x 25,4
1.00	25,4	3824	WCDA 1000	1000	10	1.30	33,0	1.50 x 1.25	38,1 x 31,8


NEW PRODUCT!

Standard color gray.



* At maximum wire capacity.

** Custom lengths available by special order, consult Heyco.


† To order Small Packs, please add the suffix -P to Part No.; e.g., 3335-P.

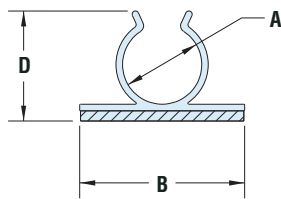

WCUA

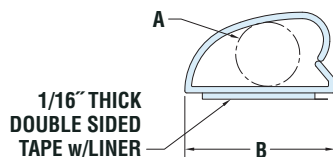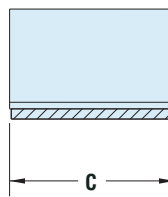

WCDA

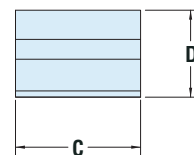

Material	PVC
Flammability Rating	94V-0
Temperature Range	-20°F (-29°C) to 150°F (66°C)

*Quick
Specs*

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[3336](#)