



Heyco® Thick Panel Snap Bushings

Mounting Hole Diameter Range: .375" (9,5 mm) to 2.0" (50,8 mm)


MOUNTING HOLE DIAMETER		PART NO.		DESCRIPTION	PART DIMENSIONS					
		Black	White		A Inside Diameter		B Head Diameter		C Overall Height	
in.	mm.				in.	mm.	in.	mm.	in.	mm.
Single Locking Step for Panel Thickness up to .170" (4,3 mm)										
.375	9,5	2017	2018	SB 375-281	.28	7,1	.47	11,9	.41	10,3
1.000	25,4	3085	3088	SBT 1000-790*	.80	20,3	1.13	28,8	.45	11,4
Multiple Locking Steps for Panel Thickness up to .250" (6,4 mm)										
.500	12,7	3126	3127	SBT 500-6	.39	9,9	.58	14,7	.56	14,3
.625	15,9	2830	2831	SB 625-500**	.50	12,7	.70	17,9	.53	13,5
.750	19,1	2840	2841	SB 750-625**	.63	15,9	.83	21,0		
.875	22,2	3104	3105	SBT 875-11	.69	17,5	.95	24,2	.56	14,3
1.000	25,4	3108	3109	SBT 1000-12	.77	19,4	1.13	28,6		
1.093-1.125	27,8-28,6	3128	3129	SBT 1093-15	.94	23,8	1.22	30,9		
1.187	30,2	3130	3131	SBT 1187-15	.94	23,8	1.31	33,3		
1.250	31,8	3132	3133	SBT 1250-16	1.00	25,4	1.31	33,2		
1.375	34,9	3110	3111	SBT 1375-16	1.00	25,4	1.50	38,1		
1.500	38,1	3112	3113	SBT 1500-21	1.31	33,3	1.62	41,2		
1.750	44,5	3114	3115	SBT 1750-22	1.38	34,9	1.88	47,6		
2.000	50,8	3116	3117	SBT 2000-26	1.63	41,3	2.13	54,0		

Standard colors black and white. Consult Heyco for other colors.

*Notched head, triple locking finger design.

**Single Locking Step for Panel Thickness up to .250" (6,4 mm).

- For use in mounting panels up to 1/4" thick.
- Convert raw-edged holes to smooth, neat, insulated holes.
- Insulate and mechanically protect electrical and telecommunications cables, tubing, hose, rope, and utility lines.
- Locking fingers snap into holes with fingertip pressure.
- Locking fingers in fractional increments up to the maximum panel thickness.
- Withstand a push back force of >35 pounds.
- Available in multiple sizes for use in .375" (9,5 mm) to 2.000" (50,8 mm) diameter holes.

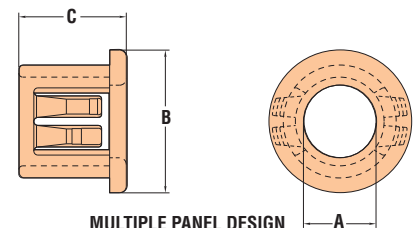

MULTIPLE PANEL DESIGN

Heyco® Knock-Out Snap Bushings

For use in electrical boxes and enclosures up to thicknesses shown.

BOX HOLE DIAMETER		TRADE SIZE	PART NO. Black	DESCRIPTION	A Inside Diameter		PART DIMENSIONS B Head Diameter		C Overall Height		
in.	mm.				in.	mm.	in.	mm.	in.	mm.	
Multiple Locking Steps for Box Thickness up to .125" (3,2 mm)											
.875	22,2	1/2	2126	SB 875-11	.69	17,5	.95	24,2	.45	11,5	
1.093-1.125	27,8-28,6	3/4	2166	SB 1093-15	.94	23,8	1.22	30,9			
1.375	34,9	1	2210	SB 1375-16	1.01	25,8	1.49	37,3			
1.750	44,5	1-1/4	2300	SB 1750-22	1.38	34,9	1.88	47,6			
2.000	50,8	1-1/2	2406	SB 2000-28	1.75	44,5	2.13	54,0			
Multiple Locking Steps for Box Thickness up to .250" (6,4 mm)											
2.500	63,5	2	2420	SB 2.500-31	1.97	50.0	2.66	67,5	.72	8,3	

Standard color black. Consult Heyco for white and other colors. For thicker boxes, see below.

Material

Nylon 6/6

Certifications

Recognized under the Component Program of Underwriters' Laboratories, File E15331

Certified by Canadian Standards Association, File 8919

Flammability Rating

94V-2

Temperature Range

-4°F (-18°C) to 221°F (105°C)

Quick Specs

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[3126](#) [2840](#) [2830](#) [2017](#) [3104](#) [3108](#) [3110](#) [3112](#) [3114](#) [3116](#) [3128](#) [3132](#)