

Heyco® PVC and Nylon LED Spacers

Fits T-1 (3 mm) HLEDs2	Fits T-1 3/4 (5 mm) HLEDs3	Fits T-1 (3 mm) HLEDs1E	Fits T-1 3/4 (5 mm) HLEDs2E
---	---	--	--

in.	A mm.	PART NO. Black PVC*	DESCRIPTION	PART NO. Black PVC	DESCRIPTION	PART NO. Natural	DESCRIPTION	PART NO. Natural	DESCRIPTION
.187	4,8			11025	HLEDs3-03	11032	HLEDs1E-03	11041	HLEDs2E-03
.250	6,4	11019	HLEDs2-04	11026	HLEDs3-04	11033	HLEDs1E-04	11042	HLEDs2E-04
.375	9,5	11020	HLEDs2-06	11027	HLEDs3-06	11034	HLEDs1E-06	11043	HLEDs2E-06
.500	12,7			11028	HLEDs3-08	11035	HLEDs1E-08	11044	HLEDs2E-08
.625	15,9			11029	HLEDs3-10	11036	HLEDs1E-10	11045	HLEDs2E-10
.750	19,1			11030	HLEDs3-12	11037	HLEDs1E-12	11046	HLEDs2E-12
.875	22,2					11038	HLEDs1E-14	11047	HLEDs2E-14
1.000	25,4					11039	HLEDs1E-16	11048	HLEDs2E-16





Standard as color noted.

*V-0 material available, consult Heyco.

For Heyco PCB Surface Mount Miniature Connectors for LED PCB's, contact Heyco.

Heyco® Transistor Insulators

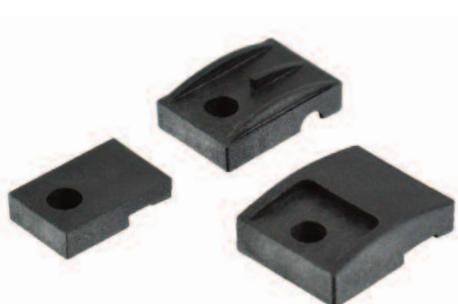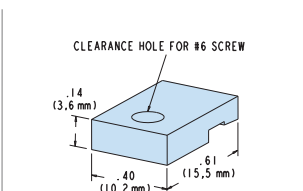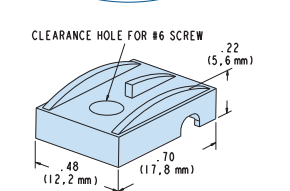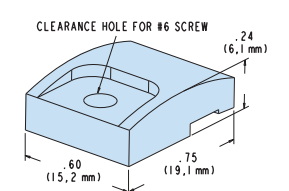

							
PART NO. Black	DESCRIPTION	PART NO. Black	DESCRIPTION	PART NO. Black	DESCRIPTION		
12015	IEC-220-18 GF	12016	IEC-220V-18 GF	12017	IEC-218-18 GF		

Material	HLEDs2 PVC	HLEDs3 PVC	HLEDs1E & HLEDs2E Nylon 6/6	Transistor Insulators Nylon Glass-filled 6/6
Flammability Rating	94HB	94HB	94V-2	94HB
Temperature Range	32°F (0°C) to 185°F (85°C) (All)	see HLEDs2	see HLEDs2	-22°F (-30°C) to 284°F (140°C)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Heyco:](#)

[12015](#) [12017](#) [12016](#)