


THIS DRAWING COVERS A PROPRIETARY ITEM AND IS THE PROPERTY OF MICRO SWITCH, A DIVISION OF HONEYWELL. THIS DRAWING IS NOT TO BE COPIED OR USED WITHOUT THE APPROVAL OF MICRO SWITCH			
CHARACTERISTICS		ELECTRICAL DATA	
ACTUATING FORCE ----- 7 - 11 LBS		CONTACT ARRANGEMENT	
FULL OVERTRAVEL FORCE----- 20 LBS MAX		D P S T - N O	
RELEASE FORCE ----- .5 LB MIN		28 VDC	
PRETRAVEL ----- .090 MIN		RATED LOAD OVERLOAD	
DIFFERENTIAL TRAVEL ----- .050 MIN		INDUCTIVE	.75 1.75
OVERTRAVEL ----- .050 MIN			
TOTAL TRAVEL ----- .165 MIN			

THIRD ANGLE PROJECTION	
SCALE NONE	
DO NOT SCALE PRINT	
UNLESS OTHERWISE SPECIFIED TOLERANCES ARE	
ONE PLACE	(.0) ±.030
TWO PLACE	(.00) ±.015
THREE PLACE	(.000) ±.005
ANGLES	±
WEIGHT	.25 LB MAX

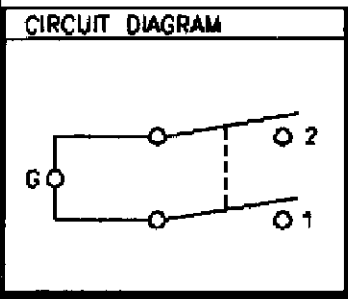

- NOTES
- 1 - SWITCH SEALED PER MIL-PRF-8805, SYMBOL 3
 - 2 - TERMINAL HARDWARE PACKET FURNISHED UNASSEMBLED:
15PA308-JS INCLUDES BUSS BRACKET AND TERMINAL SCREWS
 - 3 - MICRO SWITCH, MANUFACTURER'S CAGE CODE, CATALOG LISTING,
MILITARY PART NUMBER AND DATE CODE IDENTIFIED ON SIDE OF SWITCH
 - 4 - OPERATING TEMPERATURE RANGE: -40°C TO +85°C

ANSI Y14.5M-1982 APPLIES

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Honeywell:](#)

[JS-555](#)