

**MICRO SWITCH**FREEPORT, ILLINOIS, U.S.A.
A DIVISION OF HONEYWELL

FED. MFG. CODE 91929

SWITCH—BASIC

CATALOG LISTING

BZ-2RQ66

ALH4500 / JG08420

BZ-2RQ66

PAGE 1 OF 1

MDRAWING
NUMBER

8

ISSUE

REPLACES

RELEASE NO.

CHECK

REVISIONS

A	COI7410	LLD	27 MAR 64
B	CO34353	BEN	1 NOV 74
C	CO36099	P	6 JUN 77
D	CO-73287-8	DHD	17 MAY 93
E	CO-77592	CO	77592
F	CO93346	DAW	15 AUG 94
G	0015138	DLT	1 SEP 98
		SPK	29 AUG 05

29 AUG 05

RJ

CHECK

64

2, APR 64

DAW

CHECK


64

DAW

CHECK

LLD

27 MAR 64

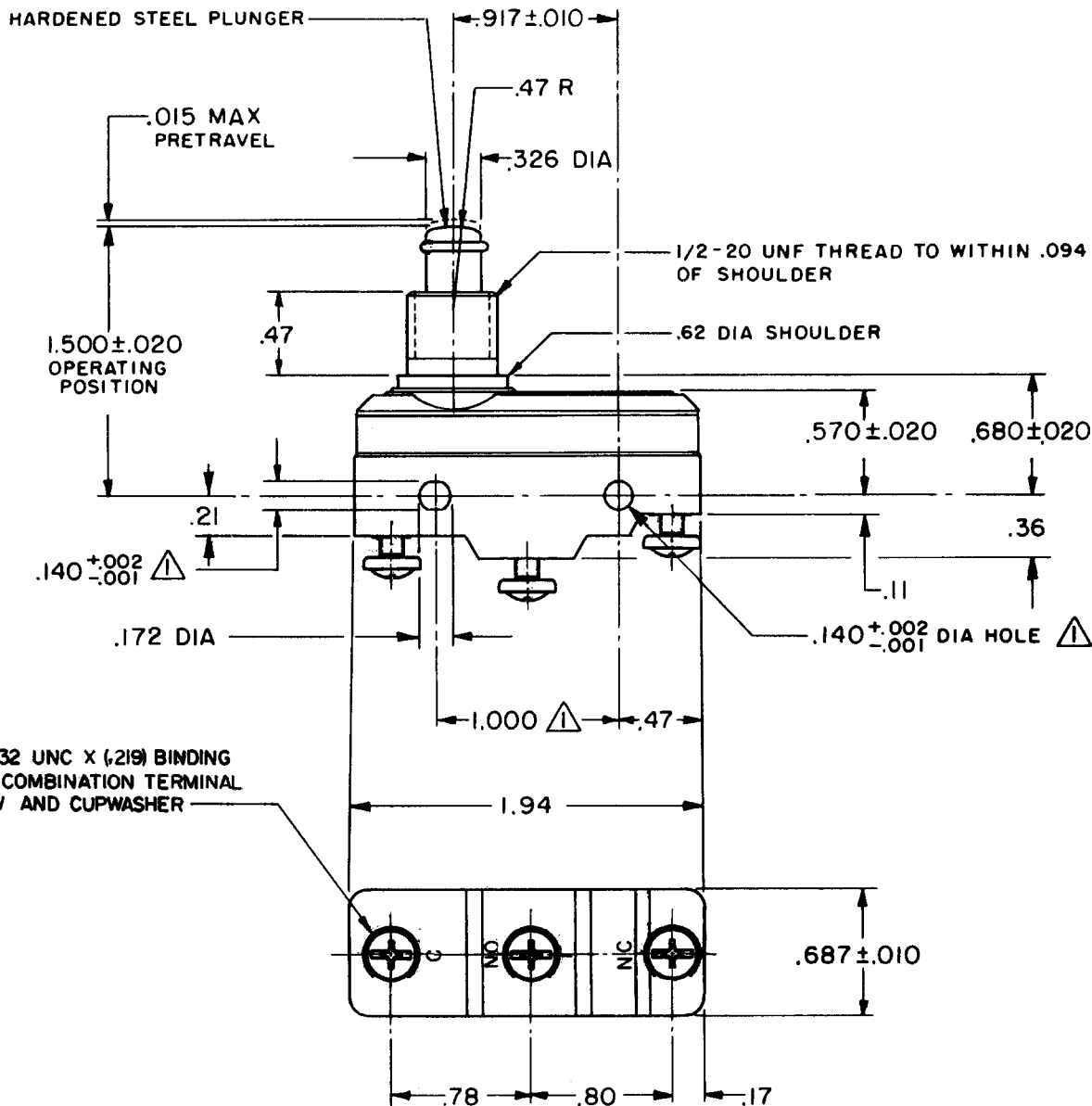

NOTE

 Δ - MOUNTING HOLES WILL ACCEPT PINS OR SCREWS OF .139 MAX DIA ON $1.000 \pm .002$ CENTERS

THIS DRAWING COVERS A PROPRIETARY ITEM AND IS THE PROPERTY OF MICRO SWITCH, A DIVISION OF MINNEAPOLIS-HONEYWELL REGULATOR CO. THIS DRAWING IS NOT TO BE COPIED OR USED WITHOUT THE APPROVAL OF MICRO SWITCH.

CHARACTERISTICS

OPERATING FORCE ----- 9-13 OZ

RELEASE FORCE ----- 4 OZ MIN

DIFFERENTIAL TRAVEL-- .0004 - .0020

OVERTRAVEL ----- .219 MIN

ELECTRICAL DATA

CONTACT ARRANGEMENT
S P D T15A-125, 250 OR 480 VAC, 2A-600 VAC
1/8HP-125 VAC; 1/4HP-250 VAC
CODE L74 1/2A-125 VDC; 1/4A-250 VDC-L288-
-L306-
-L315-16A 250V \sim T85 5E4

SCALE FULL

DO NOT SCALE PRINT

UNLESS OTHERWISE NOTED

DIMENSIONS ARE IN INCHES

TOLERANCES ARE:

ONE PLACE	(.0)	$\pm .030$
TWO PLACE	(.00)	$\pm .015$
THREE PLACE	(.000)	$\pm .005$
ANGLES		\pm

WEIGHT .120 LB

FORMTEK

FO-50378

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Honeywell:](#)

[BZ-2RQ66](#)