


FED MFG CODE 91929

CATALOG LISTING
1TP19 SERIES

THIS DRAWING COVERS A PROPRIETARY ITEM AND IS THE PROPERTY OF MICRO SWITCH A DIVISION OF HONEYWELL THIS DRAWING IS NOT TO BE COPIED OR USED WITHOUT THE APPROVAL OF MICRO SWITCH

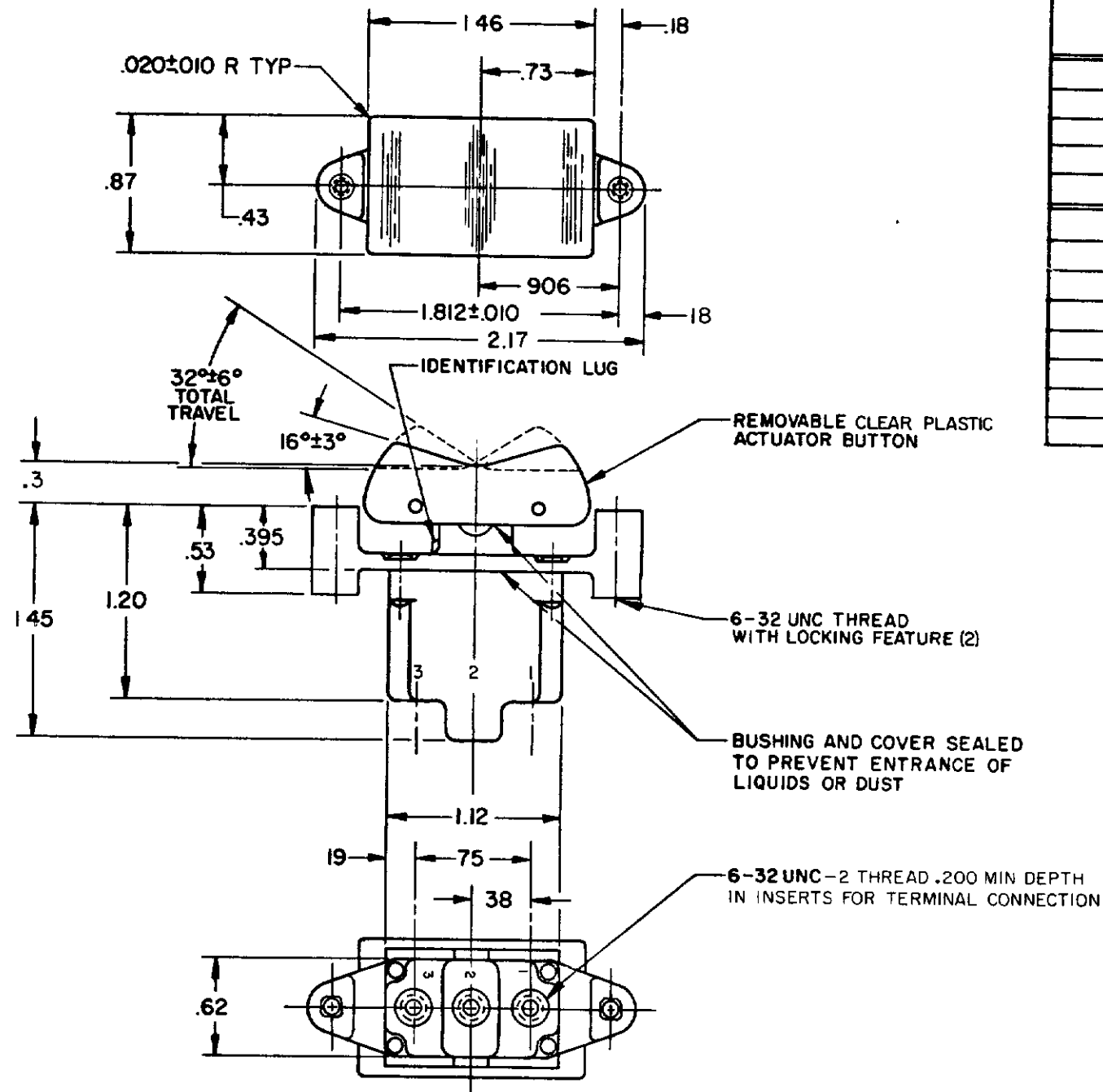

CATALOG LISTING	③ CIRCUIT MADE WITH BUTTON DEPRESSED ON			CURRENT CAPACITY (AMPS)									
	LUG SIDE (1-2)	CENTER (1-2)	OPPOSITE LUG (2-3)	RESISTIVE LOAD					LAMP LOAD		INDUCTIVE LOAD		
				DC VOLTS			AC VOLTS						
				28	125	250	125	250	28 VDC	125 VAC	28 VDC	125 VAC	
	ITP19-1	ON	OFF	ON	20	.75	.5	15	6	5	3	15	10
	ITP19-2	OFF	NONE	ON									
	ITP19-3	ON	NONE	ON									
	ITP19-21	NONE	OFF	ON									
	ITP19-31	NONE	ON	ON									
	ITP19-4	MOM OFF	NONE	ON	15	75	5	15	6	4	2	10	7
	ITP19-5	MOM ON	OFF	ON									
	ITP19-6	MOM ON	NONE	OFF									
	ITP19-7	MOM ON	OFF	MOM ON									
	ITP19-8	MOM ON	NONE	ON									
	ITP19-51	NONE	ON	MOM ON									
	ITP19-61	MOM ON	OFF	NONE									

4 - 6-32 UNC - 2 X .280 REF STEEL PAN HEAD TERMINAL SCREWS, SPRING LOCKWASHERS, AND WASHERS (SEMS) FURNISHED UNASSEMBLED ONE PER TERMINAL

WEIGHT

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Honeywell:](#)

[1TP19-1](#) [1TP19-2](#) [1TP19-3](#)