

MICRO SWITCH


FREEPORT ILLINOIS, U.S.A
A DIVISION OF HONEYWELL

FED. MFG. CODE 91929

ASSEMBLY - TOGGLE SWITCH

CATALOG LISTING

13AT418-T2

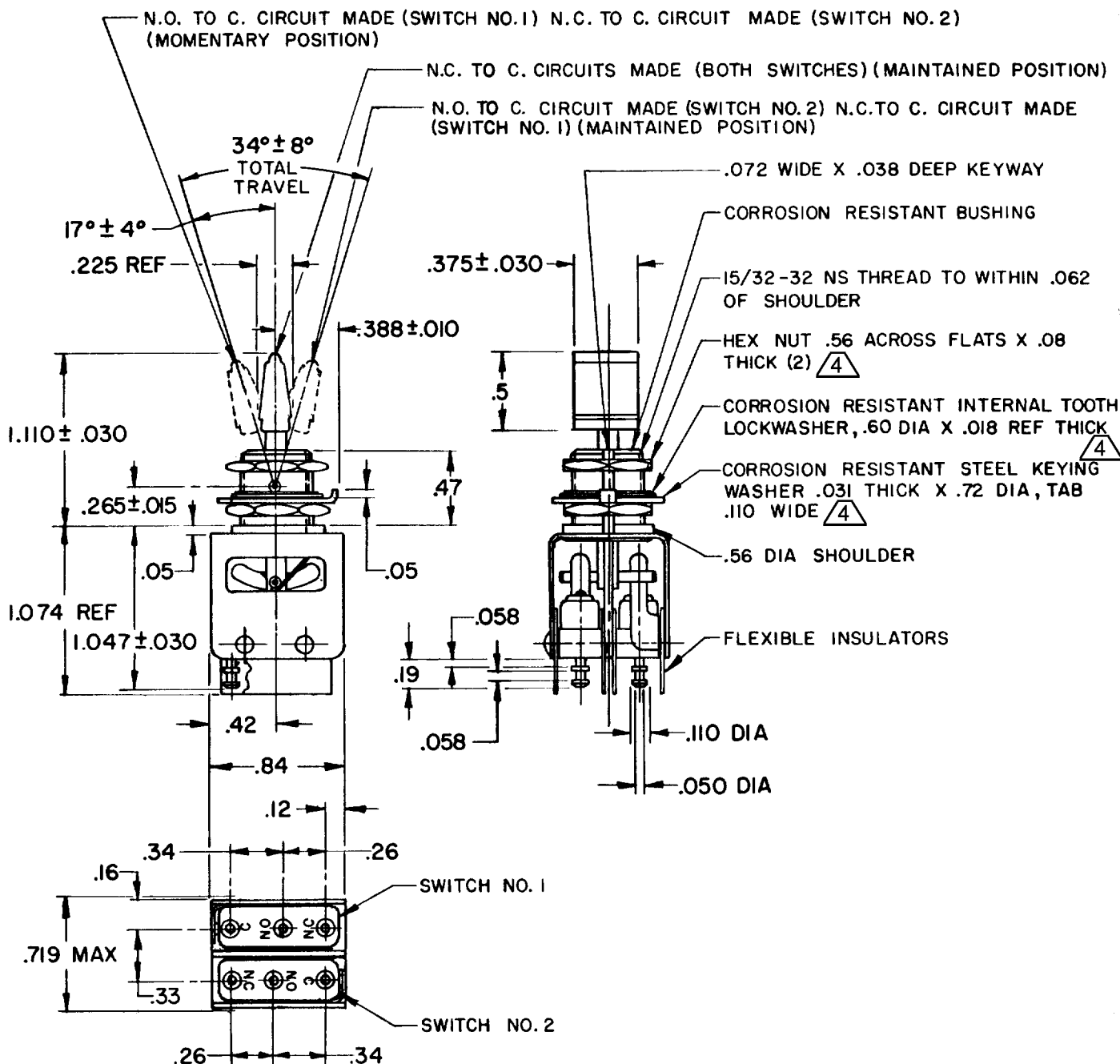

NOTE

- 1-UNIT INCLUDES CAT. LIST. 2ISM284-T2 TYPE BASIC SWITCH (MS25085-2) (2)
- 2-TERMINALS ARE PLATED FOR SOLDERING
- 3-KNOB PORTION OF TOGGLE LEVER BRIGHT ANODIZED
- 4-HARDWARE FURNISHED UNASSEMBLED WITH SWITCH OR IN PACKET PER MIL-PRF-8805
- 5-REPLACEMENT MOUNTING HARDWARE PACKET 15PA312-AT

THIS DRAWING COVERS A PROPRIETARY ITEM AND IS THE PROPERTY OF MICRO SWITCH, A DIVISION OF HONEYWELL. THIS DRAWING IS NOT TO BE COPIED OR USED WITHOUT THE APPROVAL OF MICRO SWITCH.

CHARACTERISTICS

ELECTRICAL DATA

SCALE FULL

CONTACT ARRANGEMENT
SPDT (2)

DO NOT SCALE PRINT

SEA LEVEL

50,000 FT

LOAD	28 VDC	115 VAC 60 CPS	28 VDC
RESISTIVE	5.0 AMP	5.0 AMP	5.0 AMP
INDUCTIVE	3.0 AMP	5.0 AMP	2.5 AMP
LAMP	2.4 AMP	1.5 AMP	2.4 AMP

UNLESS OTHERWISE
NOTED

DIMENSIONS ARE IN INCHES

TOLERANCES ARE:

ONE PLACE	(.0)	±.030
TWO PLACE	(.00)	±.015
THREE PLACE	(.000)	±.005
ANGLES		±

WEIGHT .06 LB APPROX

CATALOG LISTING
13AT418-T2

PAGE 1 OF 1

ISSUE
7

REPLACES

RELEASE NO. PR-1796

CHECK

10 DEC 67

CHECK

10 DEC 69

CHECK

10 DEC 69

CHECK

10 DEC 69

SRH 9 DEC 69

DRAWN

FO-50378-1A

MASTER

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Honeywell:](#)

[13AT418-T2](#)