



**MICRO SWITCH**  
FREEPORT ILLINOIS  
A DIVISION OF HONEYWELL  
FED. MFG. CODE 91929

# ACTUATOR-SWITCH

CATALOG LISTING  
**JS-245**

JS-245

M

DRAWING  
NUMBER

8

ISSUE

84

REPLACES

RELEASE NO. SR 10880

CHECK

NOV '62

DES

CHECK

NOV '62

DAW

CHECK


NOV 62

LMH



NOV

FO-50378

 .09 WIDE X .031 THICK LEVER



CORROSION RESISTANT STEEL ACTUATOR  
AND BRACKET (TYPE 302)

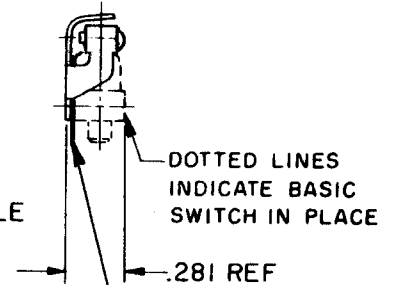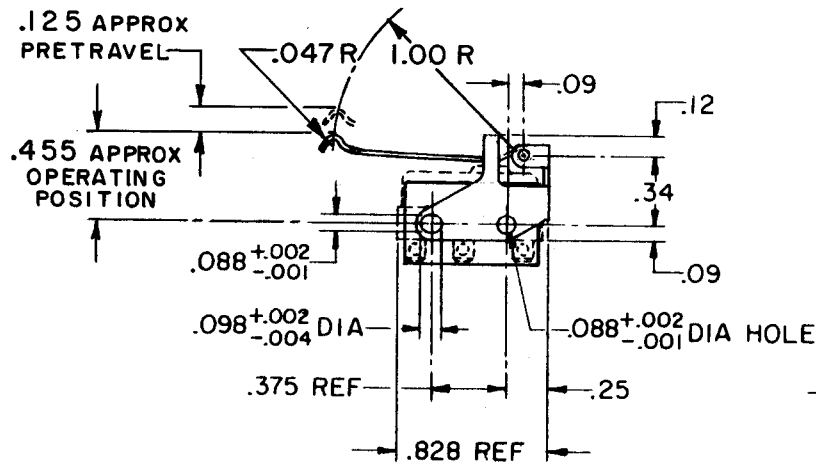

FLEXIBLE INSULATOR

NOTE -  
 FURNISHED UNASSEMBLED

THIS DRAWING COVERS A PROPRIETARY ITEM AND IS THE PROPERTY OF MICRO SWITCH, A DIVISION OF MINNEAPOLIS-HONEYWELL REGULATOR CO. THIS DRAWING IS NOT TO BE COPIED OR USED WITHOUT THE APPROVAL OF MICRO SWITCH.

## CHARACTERISTICS WITH ISMI BASIC SWITCH INSTALLED

OPERATING FORCE-----1 OZ MAX  
RELEASE FORCE-----4 GRAM MIN  
DIFFERENTIAL TRAVEL-----.030 MAX  
OVERTRAVEL-----.030 MIN

## ELECTRICAL DATA

CONTACT ARRANGEMENT

SCALE FULL

DO NOT SCALE PRINT

UNLESS OTHERWISE  
SPECIFIED  
DIMENSIONS ARE IN INCHES

## TOLERANCES ARE:

ONE PLACE (.0)  $\pm .030$   
TWO PLACE (.00)  $\pm .015$   
THREE PLACE (.000)  $\pm .005$   
ANGLES  $\pm$

WEIGHT

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Honeywell:](#)

[JS-245](#)