

# MICRO SWITCH

A DIVISION OF MINNEAPOLIS-HONEYWELL REGULATOR COMPANY  
FREEPORT, ILLINOIS

FED. MFR. CODE 91929

## ACTUATOR - SWITCH

CATALOG LISTING

JS-40

(M) JS-40  
ISSUE 2

REPLACES

RELEASE NO.

JS-40

DRAWING  
NUMBER

ISSUE

86

### REVISIONS

A	CO12901	RER	1 JUN 59
B	CO29487	SRH	13 JAN 72
C	CO47771	CJH	17 MAY 80
D	CO79303	DLT	7 MAR 95

CHECK

1 JUNE 59

R L

CHECK

1 JUNE 59




CHECK

1 JUN 59

RER

FO-50378

DRAWN

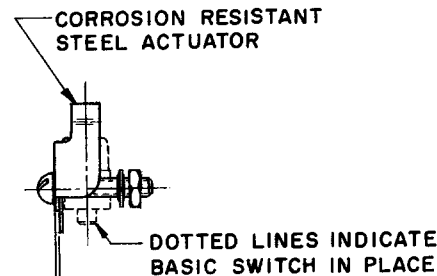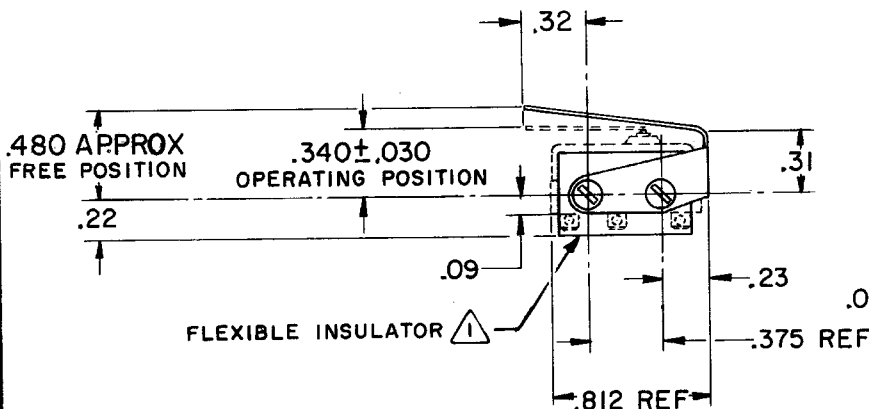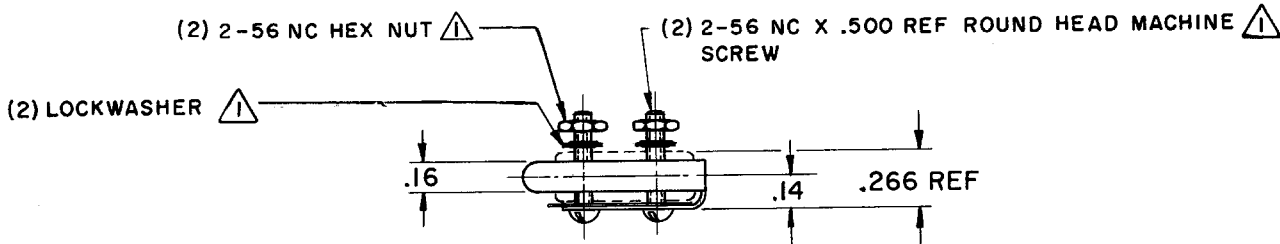

NOTE -  
 $\triangle$  - FURNISHED UNASSEMBLED

THIS DRAWING COVERS A PROPRIETARY ITEM AND IS THE PROPERTY OF MICRO SWITCH, A DIVISION OF MINNEAPOLIS-HONEYWELL REGULATOR CO. THIS DRAWING IS NOT TO BE COPIED OR USED WITHOUT THE APPROVAL OF MICRO SWITCH.

### CHARACTERISTICS WITH ISMI BASIC SWITCH INSTALLED

OPERATING FORCE	-----7 OZ MAX
RELEASE FORCE	-----2 OZ MIN
PRETRAVEL	-----.218 MAX
OVERTRAVEL	-----.030 MIN
DIFFERENTIAL TRAVEL	-----.020 MAX

### ELECTRICAL DATA

CONTACT ARRANGEMENT

BREAK DISTANCE

### SCALE FULL

DO NOT SCALE PRINT

UNLESS OTHERWISE SPECIFIED

DIMENSIONS ARE IN INCHES

TOLERANCES ARE:

ONE PLACE	(.0)	$\pm$ .030
TWO PLACE	(.00)	$\pm$ .015
THREE PLACE	(.000)	$\pm$ .005
ANGLES		$\pm$

WEIGHT

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Honeywell:](#)

[JS-40](#)