

FED MFG CODE 91929

# SWITCH - BASIC

**(M) BZ-3YST  
ISSUE 6**

REPLACES

RELEASE NO.

--	--

CHECK

CHECK

22 NOV 02

SAV

CHEN

2 NOV 02

[illegible]

# BZ-3YST

## CATALOG LISTING


13  
ISSUE

## REVISIONS

A	206922
C S L	
22 NOV 02	


## RASTER

ORAWN

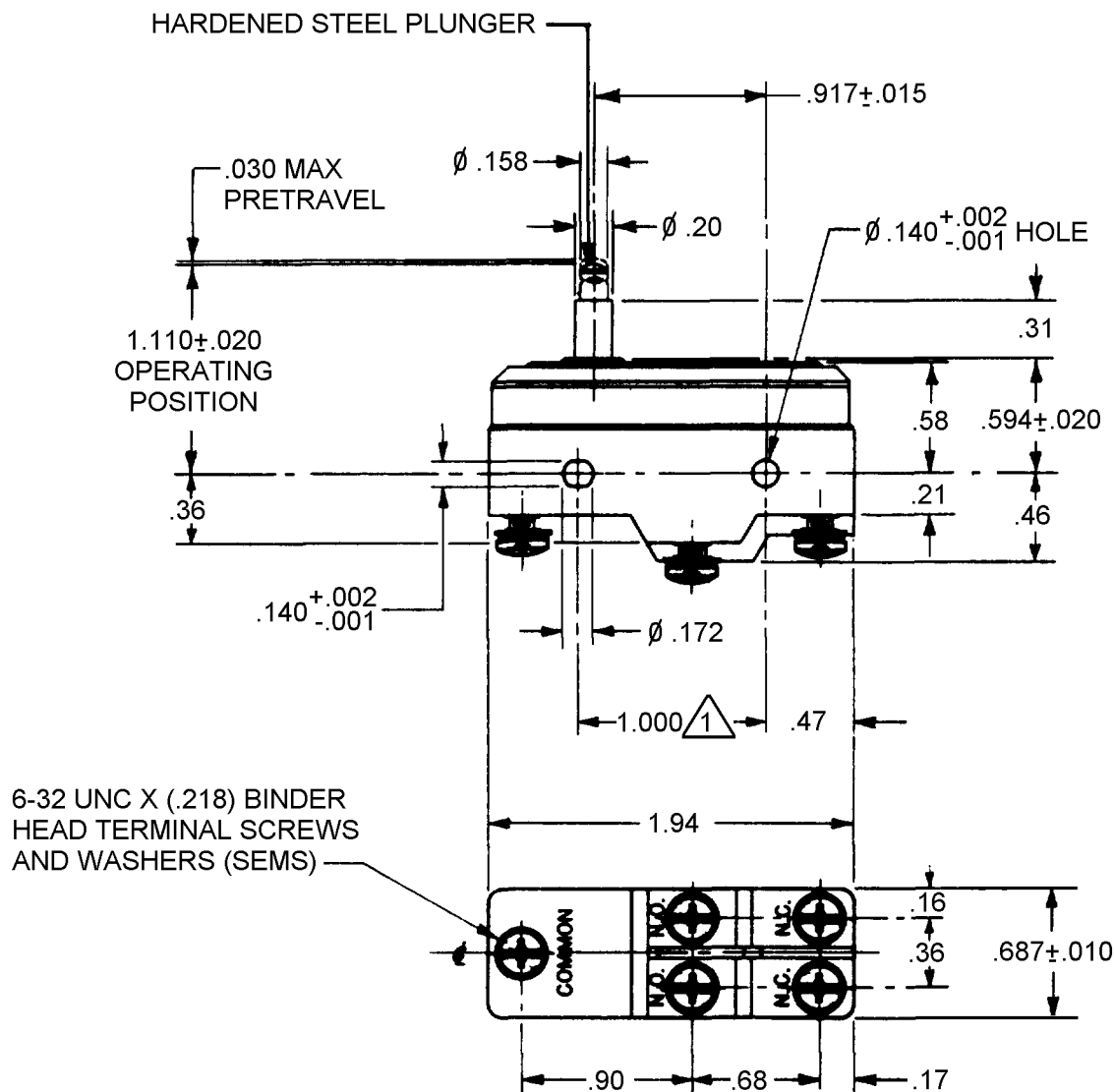

① MOUNTING HOLES WILL ACCEPT PINS OR SCREWS OF  $\phi .139$  MAX ON  $1.000 \pm .002$  CENTERS  
2 - SWITCH WILL PERFORM SATISFACTORILY IN TEMPERATURE TO  $-65^{\circ}$

THIS DRAWING COVERS A PROPRIETARY ITEM AND IS THE PROPERTY OF MICRO SWITCH, A DIVISION OF HONEYWELL. THIS DRAWING IS NOT TO BE COPIED OR USED WITHOUT THE APPROVAL OF MICRO SWITCH.

CHARACTERISTICS		ELECTRICAL DATA	SCALE FULL	DO NOT SCALE PRINT
OPERATING FORCE	16-26 OZ	CONTACT ARRANGEMENT	UNLESS OTHERWISE SPECIFIED TOLERANCES ARE	
RELEASE FORCE	4 OZ MIN	S P D T SPLIT CONTACT	ONE PLACE ( .0 )	± .030
DIFFERENTIAL TRAVEL	.001-.004	L4 5A <u>250</u> VAC 	TWO PLACE ( .00 )	± .015
OVERTRAVEL	.062 MIN		THREE PLACE ( .000 )	± .005
			ANGLES	±
			WEIGHT	.065 LB.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Honeywell:](#)

[BZ-3YST](#)