


SZL-WL-C-LE

([Home](#) : [Products](#) : [Sw itches](#) : [MICRO SWITCH™ Limit Sw itches](#) : [MICRO SWITCH™ Global Limit Sw itches](#) : [SZL-WL](#))

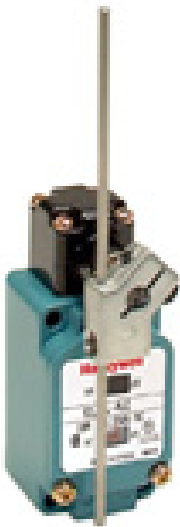

General Purpose Limit Switch, Series WL; Rod - Adjustable; Single Pole Double Throw ,Double Break; Standard; Neon lamp(AC type)

[click here to download Hi-Res image](#)

Actual product appearance may vary.

Product Specifications

Availability	Asia-Pacific
Operating Force (OF)	1,39 N [5 oz] max.
Release Force	0,27 N [0.06 lb] min.
Pretravel (PT)	10° to 20°
Overtravel (OT)	30° min.
Differential Travel (DT)	12° max.
Product Type	General Purpose Limit Sw itch
Actuator	Side Rotary - Rod Adjustable
Lever Type	Rod - Adjustable
Circuitry	SPDT-DB (1 CKT DB)
Ampere Rating	10 A 125/250 Vac
Supply Voltage	250 Vac max.
Housing Material	Aluminum Die-Cast
Termination Type	PF1/2
Series Name	SZL-WL
Shock	30 g max.
Vibration	10 Hz to 50 Hz at double amplitude of 1,5 mm
Sealing	IP67
UL File #	E150950
Expected Mechanical Life	15 Million
Operating Temperature	-10 °C to 80 °C [14 °F to 176 °F]
Comment	Neon lamp (ac type)
Agency Approvals and Standards	UL, CE, CSA

Product Specifications

UNSPSC Code	39122213
UNSPSC Commodity	39122213 Limit Sw itches
Sealed	Industrial

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Honeywell:](#)

[SZL-WL-C-LE](#)